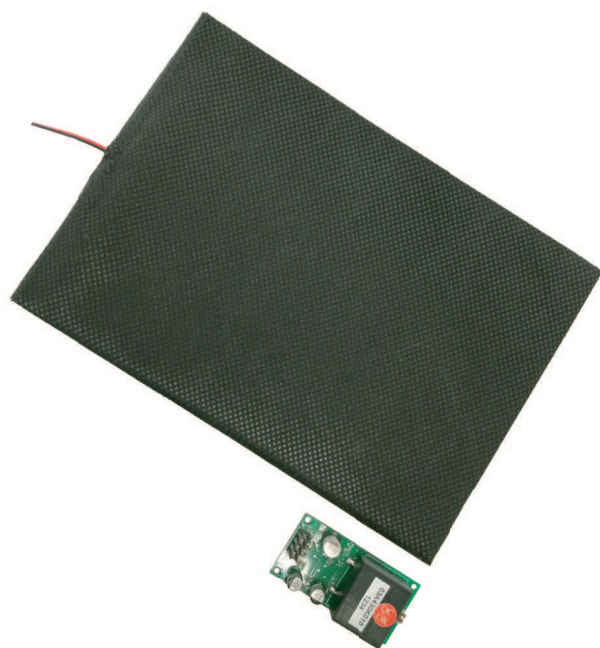


Complete with Amplifier

Features

Thin
Flexible
Wearable
Low Power

Standard Capabilities

Amp


Electrical

Input: 3.0 - 5.5 VDC
Standby Current Draw: 33mA
Normal Current Draw: 100mA
Maximum Current Draw: 250mA
Vo: 800Vpp (Max)
HPF(-3dB)=500Hz
LPF(-3dB)=6.6KHz

Dimensions

4.862cm x 2.286cm [1.9" x 0.9"]

Frequency Response

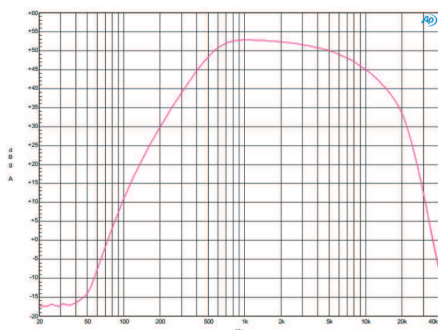

Speaker

Electrical

Power Consumption: Less than 0.2W (at 1kHz with 100Vrms input voltage)
Maximum Input Voltage: 300 Vrms at 1kHz
Polarity: Red cord is positive.


Dimensions


12.8cm x 18.3cm x 0.205cm [5.03" x 7.20" x 0.08"]

Audio Specifications

Effective Frequency Range: 650Hz~18kHz
Mean SPL: >82 dB
THD: <11% at 1.5kHz

Frequency Response

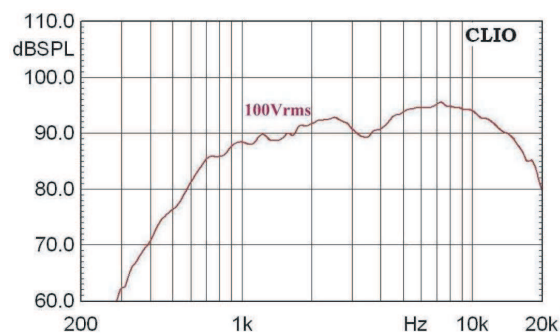

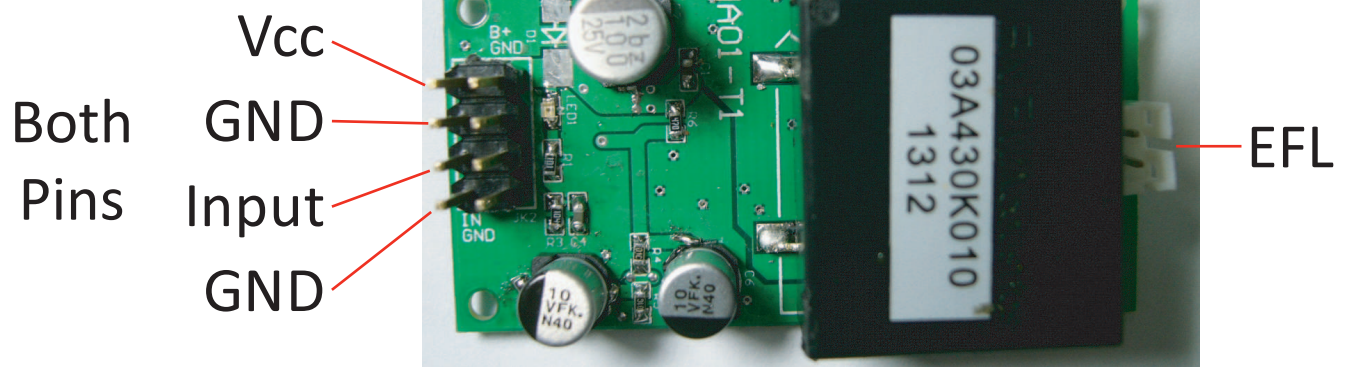

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Spectra Symbol:](#)

[EFL-AMP-13X18CM](#)