
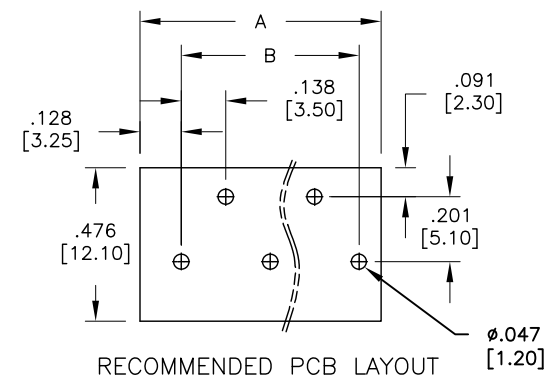
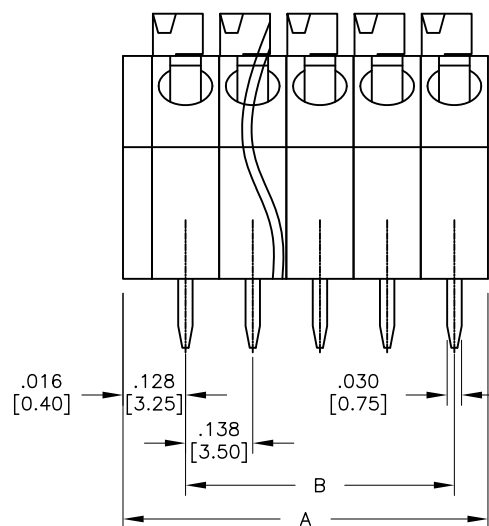
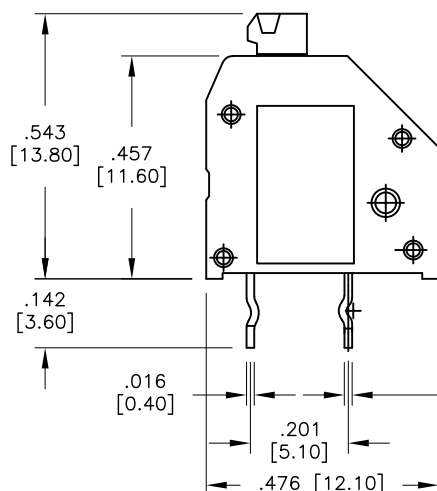


APPROVED: _____
 DATE: _____ TITLE: _____

Rev	AWO #	Description	Date	Appr
-		RELEASED	8/4/14	
A		UPDATE DRAWING	9/3/20	AY/EY

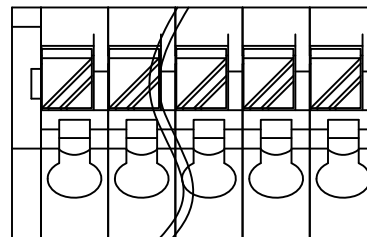

SPECIFICATIONS:

Material:

Insulator: PA66, rated UL 94V-0

Insulator color: Grey

Contact: Copper Alloy, Tin plated

Electrical:

Voltage rating: 300V

Current rating: 5A

Dielectric withstanding voltage: 1600V for 1 minute

Mechanical:

Wire range: 22~18 AWG

Strip length: 8-9 mm

Temperature Rating:

Operating temperature: -40°C to +105°C

Environmental:

Lead free, RoHS compliant.



Poles: 01 thru 30P

A= .138 [3.50] x No. of Poles + .059 [1.50]

B= .138 [3.50] x No. of Spaces

UNLESS OTHERWISE SPECIFIED
 ALL DIMENSIONS ARE INCHES [MM]
 TOLERANCES: EXCEPT AS NOTED
 INCHES HOLES
 .X ± .10 Ø.X ± .10
 .XX ± .020 Ø.XX ± .015
 .XXX ± .015 Ø.XXX ± .010

APPROVALS		DATE
DRAWN	AY	8/4/14
CHECKED	SY	8/4/14
APPROVED		

ADAM
TECH
INTERCONNECTS

909 Rahway Avenue,
 Union, NJ 07083
 Phone: 908-687-5000
 Fax: 908-687-5710

TITLE MINI TYPE, SIMPLE TYPE CAGE CLAMP TERMINAL BLOCKS, 3.50MM PITCH		
SIZE X	PART NO. EB59A-XX-A	REV. A
REF: S00067C	SCALE: NTS	SHEET 1 OF 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[EB59A-04-A](#) [EB59A-03-A](#) [EB59A-05-A](#) [EB59A-02-A](#)