
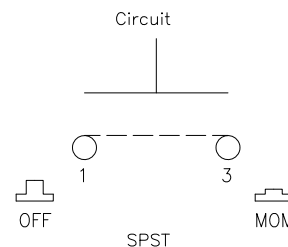
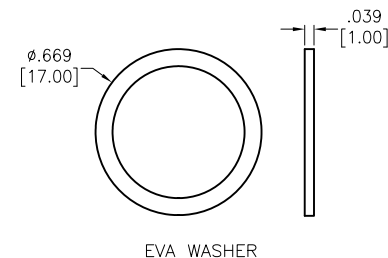
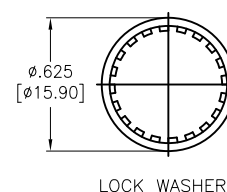
 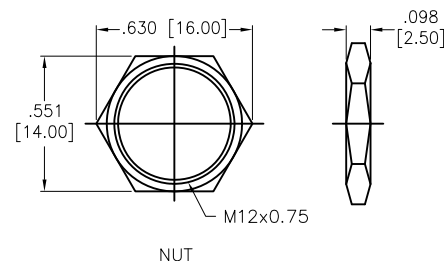

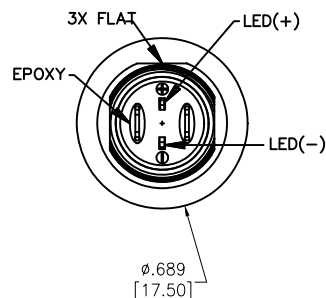
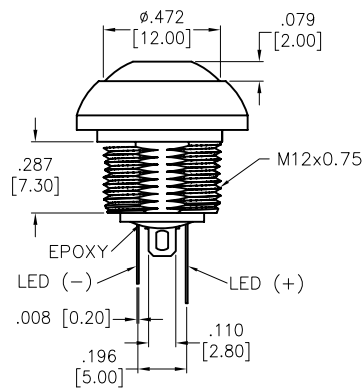
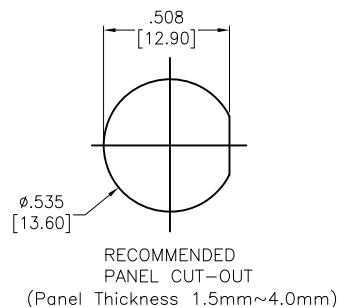


APPROVED: _____

DATE: _____ TITLE: _____

Rev	AWO #	Description	Date	Appr
-		RELEASED	2/18/21	

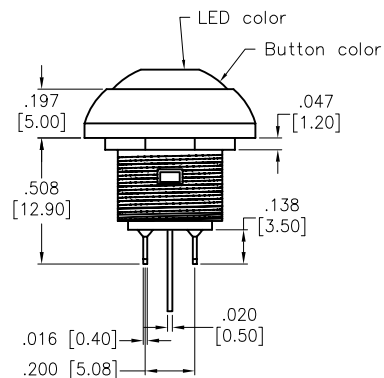

SW-PB11-2CSXX-10

Button Color		LED Color	
R	Red	R	Red
G	Green	G	Green
Y	Yellow	Y	Yellow
O	Orange	B	Blue
B	Blue	W	White
W	White		
K	Black		

SPECIFICATIONS:

Material:

Case: Dially Phthalate, rated UL 94V-0

Cap: Polyamide66, Color: See Chart

Bushing: Polyamide 66

Terminal/Contact: Gold over Silver Plated

Electrical:

Switch Rating: 400mA @ 32V AC

100mA @ 50V DC

125mA @ 125V AC

Contact resistance: 50 mΩ max.

Insulation resistance: 1G ohms min @ 500V DC.

Dielectric withstanding voltage: 1000V RMS, 50Hz.

Electrical Life: 500,000 cycles min at full load.

Temperature Rating:

Operating temperature: -30°C to +85°C

Environmental:

Sealed IP67 Rated (Front Panel)

Lead free, RoHS compliant



UNLESS OTHERWISE SPECIFIED
ALL DIMENSIONS ARE INCHES [MM]
TOLERANCES: EXCEPT AS NOTED
INCHES HOLES
.X ±.10 Ø.X ±.10
.XX ±.020 Ø.XX ±.015
.XXX ±.015 Ø.XXX ±.010

APPROVALS		DATE
DRAWN	LH	2/18/21
CHECKED	AC	2/18/21
APPROVED		

ADAM
TECH

909 Rahway Avenue,
Union, NJ 07083
Phone: 908-687-5000
Fax: 908-687-5710

TITLE			
IP67 PUSH BUTTON SWITCH, SOLDER TYPE, LIGHTED, SPST, OFF-MOMENTARY, GOLD OVER SILVER PLATED			
SIZE	PART NO.	REV.	
X	SW-PB11-2CSXX-10	-	
REF:	S00198T	SCALE:	NTS
SHEET 1 OF 1			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adam Tech:](#)

[SW-PB11-2CSKG-10](#) [SW-PB11-2CSKR-10](#)