


COIL: @ +25 °C
 RESISTANCE 675 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 13.5 VDC
 MUST RELEASE _____

CUSTOMER DATA SHEET

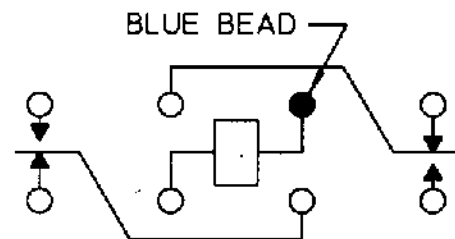

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 50 g's 11 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

CONTACT RATING: LOW LEVEL TO
3 AMPS 28 VDC, 1 AMP 115 VAC RESISTIVE
100,000 OPERATIONS

NOTES: OPERATE & RELEASE 6 MS MAX.
BOUNCE 2 MS MAX.

DR. R.B. 5/29/97 CK. 5/29/97

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. C. I. I. STD.
 CUST. NO. _____

TYPE 'RP' RELAY

RP7640G1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[RP7640G1](#)