

REV. 0

DCO 141542

COIL: @ 25°C	
RESISTANCE	400 OHMS ± 10%
NOMINAL VOLTAGE	9.0 VDC
MUST OPERATE	4.85 VDC
MUST RELEASE	3.0 VDC MAX, 0.55 VDC MIN.

ENVIRONMENT:


VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
 SHOCK 75 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX

RELEASE TIME 7.5 MS MAX

CONTACT STABILIZATION 2.5 MS MAX.

CUSTOMER DATA SHEET

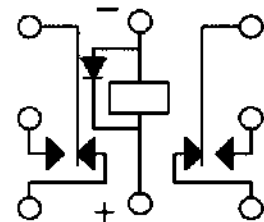

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP  
 28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. B.D. 11/24/99

CK *[Signature]* 11/24/99

COMMUNICATIONS  
 INSTRUMENTS, INC.

CUST. QPL  
 CUST. NO. M39016/42-047M REV.

JMGSD RELAY

JMGSPD-9M

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMGSPD-9M](#)