
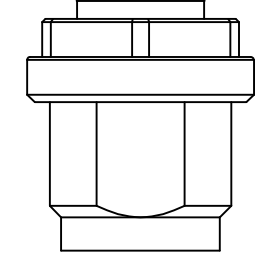
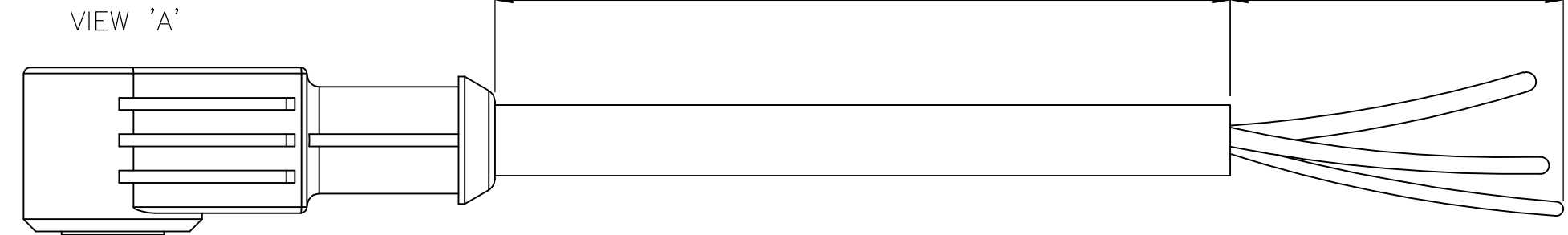



THIS DRAWING IS UNPUBLISHED. RELEASED FOR PUBLICATION
 © COPYRIGHT - By - ALL RIGHTS RESERVED.

P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	INITIAL RELEASE	26NOV2013	GSK	BvH
	A1	ECR-14-011671	20AUG2014	GSK	BvH
	A2	ECR-16-003945	16MAR2016	GSK	BvH

NOTES:
 Tolerances cable lengths:
 0m to 0.5m +30mm
 0.5m to 1.0m +50mm
 1.0m to 3.0m +100mm
 < 3.0m +1.5%

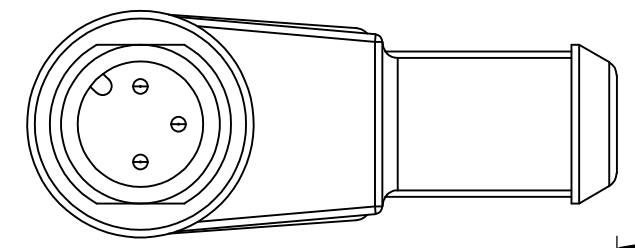

PVC CABLE	
No./diameter of wires	3 x 0.34 mm ²
Wire isolation	PVC (br, bl, bk)
C-track properties	
Jacket	PVC (UL/CSA)
Outer diameter	approx. 4.6 mm
Bend radius (moving)	10 x outer diameter
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-5...+80 °C

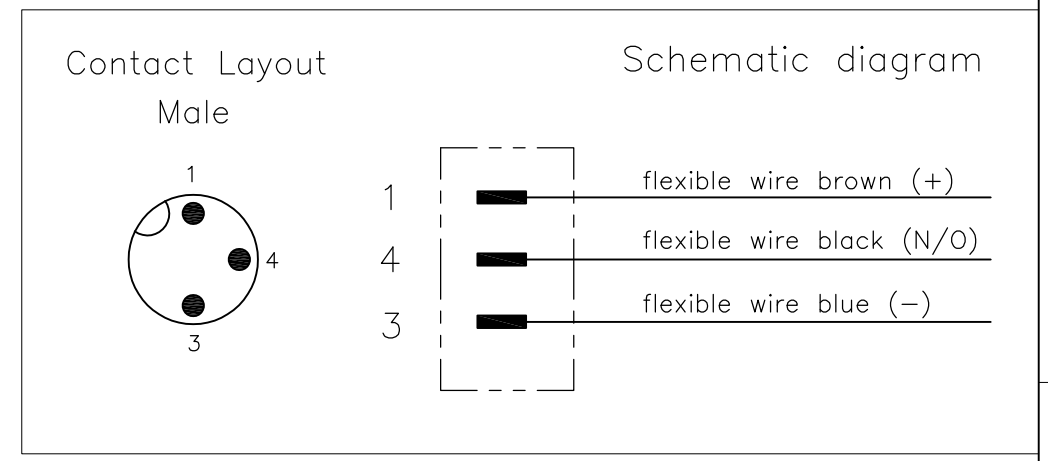

TECHNICAL DATA	
Operating voltage	max. 250 V AC/DC
Operating current per contact	max. 4 A
Locking of ports	Screw thread M12 x 1 mm (recommended torque 0.6 Nm) self-securing
Protection	IP65 and IP67 when plugged and screwed down (EN 60529)

LENGTH "L"	MATERIAL	JACKET COLOR	TE PN	DESCRIPTION	ITEM
3 pos	PVC	Black	1-2273076-4	3x22AWG PVC 10.0m	8
			1-2273076-3	3x22AWG PVC 5.0m	7
			1-2273076-2	3x22AWG PVC 3.0m	6
3 pos	PUR	Black	1-2273076-1	3x22AWG PVC 1.5m	5
			2273076-4	3x22AWG PUR 10.0m	4
			2273076-3	3x22AWG PUR 5.0m	3
2273076-2	3x22AWG PUR 3.0m	2			
2273076-1	3x22AWG PUR 1.5m	1			

PUR CABLE	
No./diameter of wires	3 x 0.34 mm ²
Wire isolation	PP (br, bl, bk)
C-track properties	5 million
Jacket	PUR (UL/CSA)
Outer diameter	approx. 4.3 mm
Bend radius (moving)	10 x outer diameter
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-25...+80 °C

THIS DRAWING IS A CONTROLLED DOCUMENT.		DWN 26NOV2013 SATHISH KUMAR.G		STE TE Connectivity	
		CHK 26NOV2013 B.VELDHOVEN			
DIMENSIONS: mm 		APVD 26NOV2013 A.VAN ZANDVOORT		M12 X 1.0 ANGLED PLUG PIGT A	
		PRODUCT SPEC 108-19483			
MATERIAL - FINISH -		APPLICATION SPEC 114-32127		SIZE	RESTRICTED TO
		WEIGHT		A3	
CUSTOMER DRAWING		SCALE NTS		SHEET 1 OF 1	REV A2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[2273076-3](#)