


## CABLE BREAKOUT BOOT, FOUR ENTRY

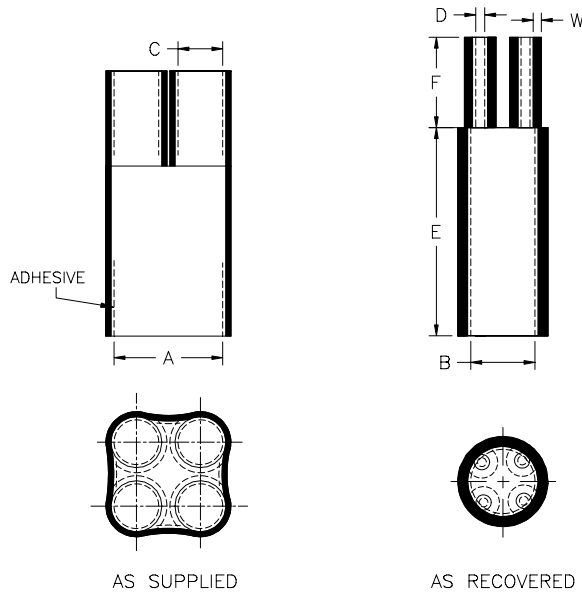


### Table of Dimensions, inch (mm):

| PART NUMBER<br>(See Note*) | Body ID       |                | Leg ID        |                | Length Recovered Min. |          | Rec'd. Wall Ref. (W) |
|----------------------------|---------------|----------------|---------------|----------------|-----------------------|----------|----------------------|
|                            | Min. Exp. (A) | Max. Rec'd (B) | Min. Exp. (C) | Max. Rec'd (D) | (E), Body             | (F), Leg |                      |
| F3-9FR                     | 0.90 (23)     | 0.43 (11)      | 0.28 (7)      | 0.11 (3)       | 2.0 (51)              | 0.8 (20) | 0.05 (1.2)           |
| F-23FR                     | 1.25 (32)     | 0.80 (20)      | 0.50 (13)     | 0.19 (5)       | 2.3 (58)              | 1.0 (25) | 0.09 (2.3)           |
| F42-60FR                   | 1.75 (44)     | 0.98 (25)      | 0.79 (20)     | 0.26 (7)       | 2.3 (58)              | 1.2 (30) | 0.14 (3.6)           |
| F75-100FR                  | 2.35 (60)     | 1.00 (25)      | 1.00 (25)     | 0.35 (9)       | 2.8 (71)              | 1.7 (43) | 0.14 (3.6)           |
| F133-200FR                 | 2.65 (67)     | 1.40 (36)      | 1.20 (30)     | 0.53 (13)      | 3.5 (89)              | 1.5 (38) | 0.14 (3.6)           |
| F150-400FR                 | 5.25 (133)    | 3.00 (76)      | 1.35 (34)     | 0.55 (14)      | 5.0 (127)             | 3.0 (76) | 0.13 (3.3)           |

**Note\*:** Add "NA" to the end of Part Number if no adhesive is required.

**Material:** Heat shrinkable boot material in accordance with -3 polyolefin

**Factory applied sealant:** Factory applied hot melt adhesive is standard.

|  |                        |  |                    |                                   |                         |                  |
|--|------------------------|--|--------------------|-----------------------------------|-------------------------|------------------|
|  Raychem Products, North America<br>Tyco Electronics Corporation<br>300 Constitution Drive<br>Menlo Park, CA 94025 USA |                        | Product Brand:<br><div style="text-align: center; font-weight: bold; font-size: 1.2em;">Raychem</div>  |                    |                                   |                         |                  |
| <b>Specification Control Drawing</b>   |                        | Title:<br><div style="text-align: center; font-weight: bold;">CABLE BREAKOUT BOOT, FOUR ENTRY</div>  |                    |                                   |                         |                  |
|  |                        | Size<br>A  | Cage Code<br>06090 | Document No.<br><b>FXXX-XXXFR</b> |                         |                  |
| UNLESS OTHERWISE SPECIFIED<br>DIMENSIONS ARE IN INCHES.<br>METRIC DIMENSIONS ARE SHOWN IN<br>BRACKETS  |                        | Tyco Electronics reserves the right to amend this drawing at<br>any time. Users should evaluate the suitability of the<br>product for their application. |                    | Rev.:<br>B                        | Rev. Date:<br>25-Mar-03 |                  |
| Drawn By:<br>A.Ng  | Org. Date:<br>03/17/03 | Original file:   |                    | File :<br>R030156.doc             | Scale:<br>None          | Sheet:<br>1 of 1 |

If this document is printed it becomes uncontrolled. Check for the latest revision.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[511808-001](#)