


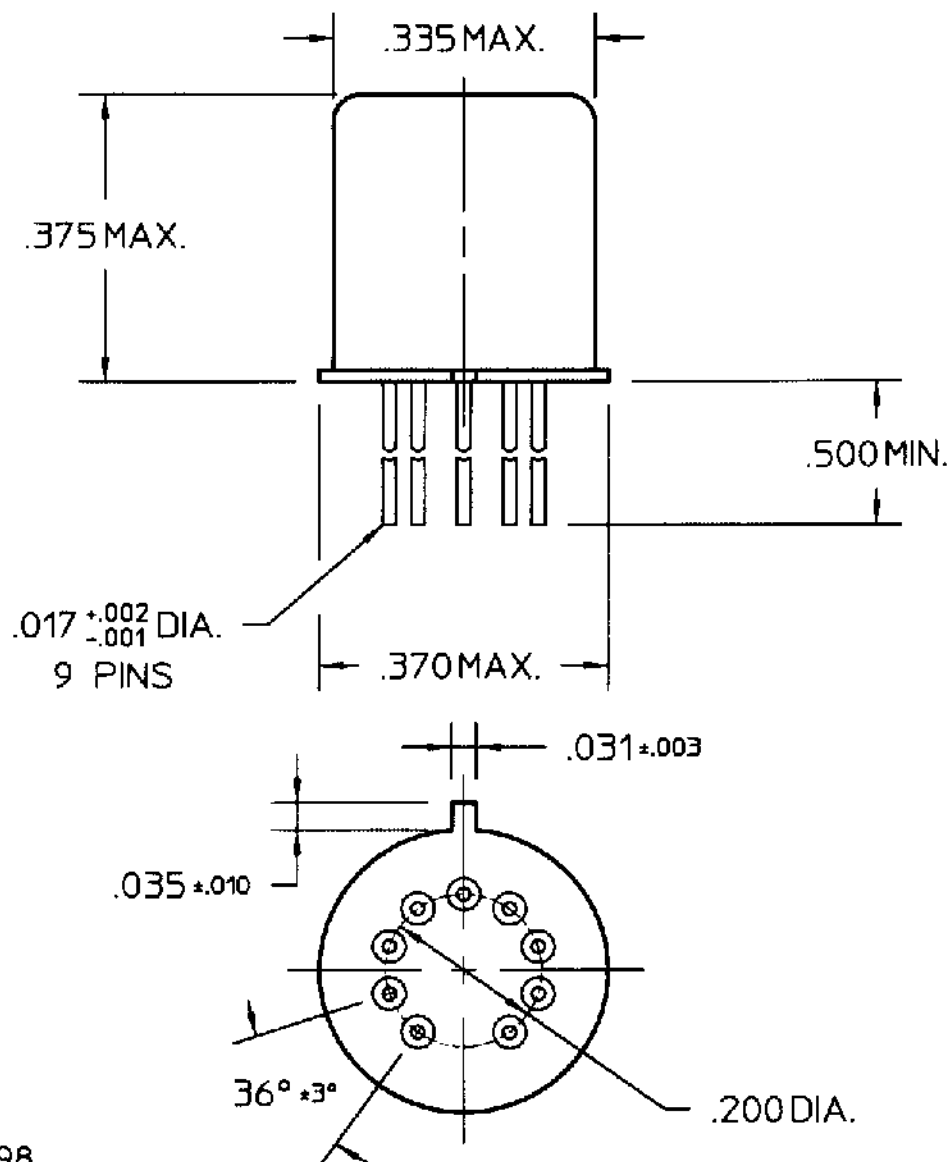


REV. 1 9/25/98

COIL: @ 25°C
 RESISTANCE 100 OHMS $\pm$ 10%
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE VOLTAGE 2.8 VDC
 TURN-ON BASE CURRENT 0.37 mADC
 MUST RELEASE 0.22 VDC

ENVIRONMENT:
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: TURN-ON TIME 4.0 MS MAX
 TURN-OFF TIME 7.5 MS MAX
 CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

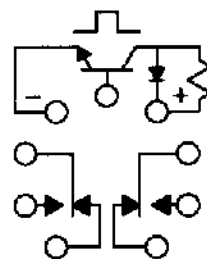

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 12/4/97 *OK* *ERRY* 9/28/98

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I. STD.
 CUST. NO.

TYPE 'MST' RELAY

MSCT-5

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[6-1617547-9](#)