





## 1-331880-0 Product Details

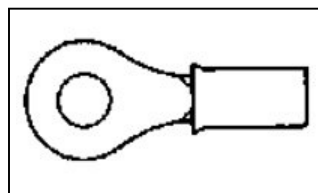

**1-331880-0**

TE Part Number: 1-331880-0



[Add to Part List](#)

### Ring and Spade Tongue Terminals

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- Terminal Shape = Ring Tongue
- Receptacle Style = Straight
- Body Style = SOLISTRAND
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire

[View all Features](#) | [Find Similar Products](#)

[Previous 1 \[2\] 3 4 5 ... 20 Next](#)

#### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Compare Products](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#) **NEW!**

### Documentation & Additional Information

#### Product Drawings:

- [WIRE TERMINAL SOLISTRAND, RING TONGUE, WIRE SIZE : 1...](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- [SOLISTRAND BUDGET AND DIAMOND GRIP UNINSULATED TERMI...](#) (PDF, English)

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

**Product Type Features:**

- [Terminal Shape](#) = Ring Tongue
- [Receptacle Style](#) = Straight
- [Body Style](#) = SOLISTRAND
- [Barrel Type](#) = Closed Barrel
- [Wire/Cable Type](#) = Regular Wire
- [Insulation](#) = No
- [Insulation Support](#) = Non-Insulation Support
- Stud Size = 3/8 [9.53]
- [Stud Diameter \(mm \[in\]\)](#) = 9.53 [0.375]
- [Shape](#) = RING-051
- [Heavy Duty](#) = Yes
- [Material](#) = Copper
- [Finish](#) = Tin

**Body Related Features:**

- [Wire Range \(mm \[AWG\]\)](#) = 41.00-60.00; [1-1/0]
- Wire Range (CMA) = 83,700 - 119,500
- Barrel I.D. Min. (mm [in]) = 11.15 [0.439]
- Stock Thickness (mm [in]) = 2.41 [0.095]

**Industry Standards:**

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

**Packaging Related Features:**

- [Packaging Method](#) = Loose Piece

**Other:**

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)

[Home](#) | [Customer Support](#) | [Suppliers](#) | [Site Map](#) | [Privacy Policy](#) | [Browser Support](#)  
© 2008 Tyco Electronics Corporation All Rights Reserved

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[1-331880-0](#)