


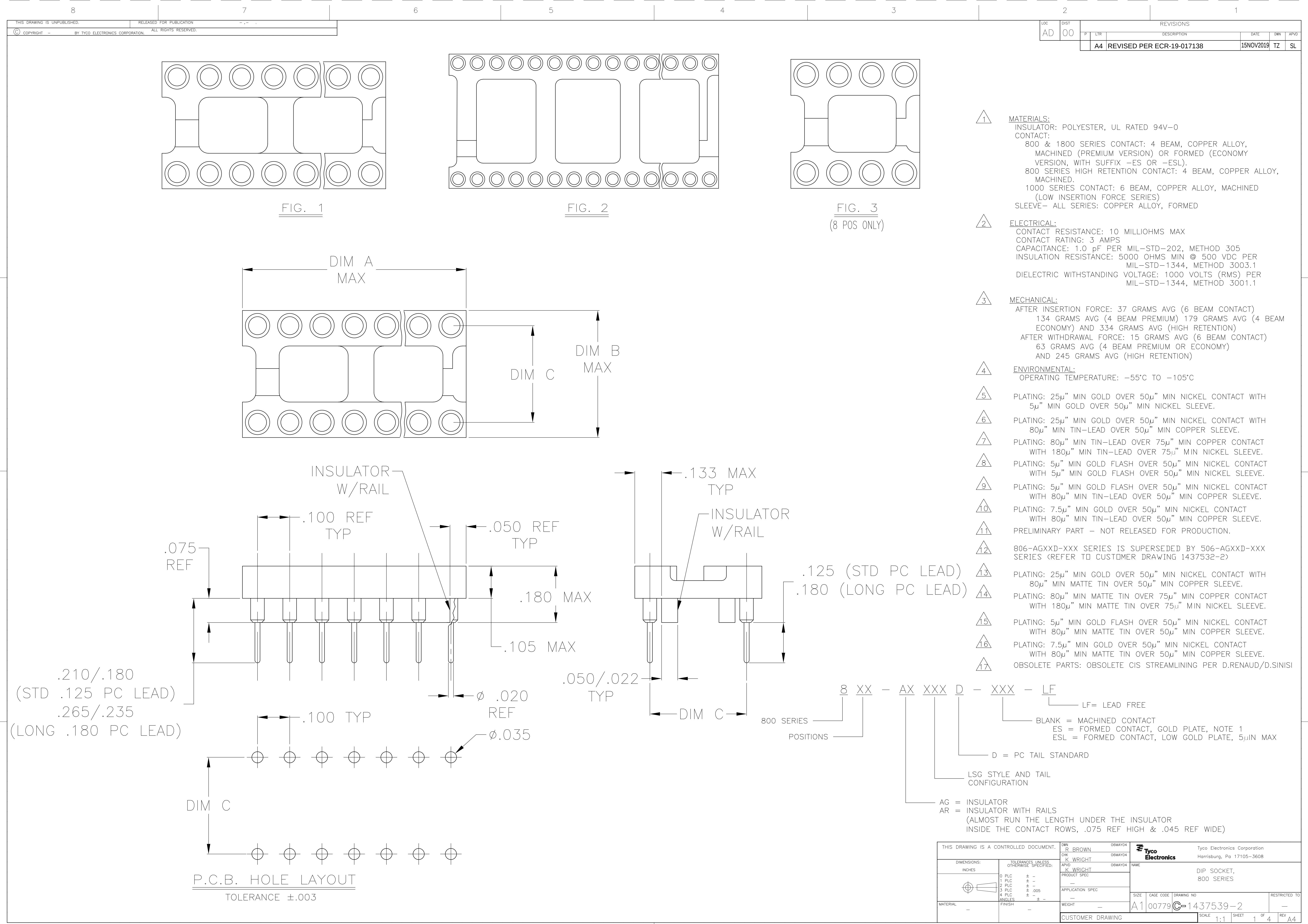

8

7

6

5

4

3

2

1

THIS DRAWING IS UNPUBLISHED.

RELEASED FOR PUBLICATION

© COPYRIGHT

BY TYCO ELECTRONICS CORPORATION. ALL RIGHTS RESERVED.

LOC

DIST

REV

DATE

BY

APPROVED

AD

00

DESCRIPTION

DATE

BY

APPROVED

SEE SHEET 1

-

-

-

800 SERIES MACHINED PREMIUM
CONTACT LEAD FREE PART NUMBER TABLE

	HIGH RETENTION		.895/.905	1.000	3.200	2	864-AG34D-LF	5-6437538-4
	HIGH RETENTION		.595/.605	.700	2.400	2	848-AG34D-LF	9-1437538-5
OBSOLETE	W/RAILS						840-AR11D-LF	8-1437538-6
	.180 PC LEAD		.595/.605	.700	2.000	2	840-AG43D-LF	8-1437538-4
	HIGH RETENTION						840-AG34D-LF	8-1437538-3
	HIGH RETENTION						832-AG38D-LF	9-6437533-4
	HIGH RETENTION		.595/.605	.700	1.600	2	832-AG34D-LF	2-6437538-5
OBSOLETE	W/RAILS						828-AR12D-LF	6-6437538-9
OBSOLETE	W/RAILS		.595/.605	.700	1.400	1	828-AR11D-LF	1-6437538-6
	.180 PC LEAD						828-AG43D-LF	6437538-4
OBSOLETE	HIGH RETENTION						828-AG34D-LF	1-6437538-3
OBSOLETE	W/RAILS		.295/.305	.400	1.200	1	824-AR31D-LF	5-6437538-1
OBSOLETE	W/RAILS		.595/.605	.700	1.200	1	824-AR11D-LF	9-6437537-9
	.180 PC LEAD		.295/.305	.400	1.200	1	824-AG47D-LF	9-6437537-7
OBSOLETE	.180 PC LEAD		.395/.405	.500	1.200	1	824-AG446D-LF	9-6437537-6
	HIGH RETENTION		.595/.605	.700	1.200	1	824-AG34D-LF	9-6437537-5
	HIGH RETENTION						824-AG38D-LF	9-6437537-4
	HIGH RETENTION		.295/.305	.400	1.200	1	824-AG334D-LF	9-6437537-3
	.180 PC LEAD		.295/.305	.400	1.000	1	820-AG43D-LF	7-6437537-3
	HIGH RETENTION						820-AG34D-LF	7-6437537-2
OBSOLETE	.180 PC LEAD W/RAILS		.295/.305	.400	.900	1	818-AR44D-LF	4-6437539-9
OBSOLETE	W/RAILS						818-AR11D-LF	6-6437537-2
OBSOLETE	W/RAILS						816-AR11D-LF	5-6437537-4
	HIGH RETENTION		.295/.305	.400	.800	1	816-AG34D-LF	5-6437537-1
OBSOLETE	W/RAILS						814-AR11D-LF	3-6437537-5
	.180 PC LEAD		.295/.305	.400	.700	1	814-AG43D-LF	3-6437537-2
	HIGH RETENTION						814-AG34D-LF	3-6437537-1
OBSOLETE	W/RAILS		.295/.305	.400	.400	3	808-AR11D-LF	1-6437537-9
	.180 PC LEAD						808-AG43D-LF	6437537-5
	HIGH RETENTION						808-AG34D-LF	6437537-4
	COMMENTS	PLATING	C	B	A	FIG	AUGAT PART NO.	TE PART NO.

800 SERIES MACHINED PREMIUM
CONTACT PART NUMBER TABLE

OBSOLETE	W/RAILS		.295/.305	.400	1.200	1	824-AR31D	0-1437538-1
OBSOLETE	W/RAILS		.595/.605	.700	1.200	1	824-AR11D	9-1437537-9
	-		.395/.405	.500	1.200	1	824-AG66D	9-1437537-8
	.180 PC LEAD		.295/.305	.400	1.200	1	824-AG47D	9-1437537-7
	.180 PC LEAD		.595/.605	.700	1.200	1	824-AG45D	6-1437538-6
	.180 PC LEAD		.395/.405	.500	1.200	1	824-AG446D	9-1437537-6
	HIGH RETENTION		.595/.605	.700	1.200	1	824-AG34D	9-1437537-5
	HIGH RETENTION						824-AG33D	8-1437539-2
	HIGH RETENTION						824-AG338D	9-1437537-4
	HIGH RETENTION						824-AG334D	9-1437537-3
	-		.295/.305	.400	1.200	1	824-AG32D	9-1437537-2
	-						824-AG31D	8-1437537-9
	-						824-AG30D	8-1437537-7
	-		.395/.405	.500	1.200	1	824-AG14D	8-1437537-6
	-						824-AG12D	8-1437537-5
	-		.595/.605	.700	1.200	1	824-AG11D	8-1437537-2
	-						824-AG10D	8-1437537-1
A4	-		.395/.405	.500	1.100	1	822-AG11D	7-1437537-8
	-						822-AG10D	7-1437537-7
	W/RAILS						820-AR11D	7-1437537-6
	.180 PC LEAD						820-AG45D	7-1437537-5
	.180 PC LEAD						820-AG44D	7-1437537-4
	.180 PC LEAD		.295/.305	.400	1.000	1	820-AG43D	7-1437537-3
	HIGH RETENTION						820-AG34D	7-1437537-2
	-						820-AG12D	6-1437537-9
	-						820-AG11D	6-1437537-6
	-						820-AG10D	6-1437537-4
	.180 PC LEAD W/RAILS						818-AR44D	4-1437539-9
	W/RAILS						818-AR11D	6-1437537-2
	.180 PC LEAD		.295/.305	.400	.900	1	818-AG44D	6-1437537-1
	HIGH RETENTION S/B 5-1437537-7						818-AG34D	5-1437538-8
	-						818-AG12D	6-1437537-0
	-						818-AG11D	5-1437537-7
	-						818-AG10D	5-1437537-6
	W/RAILS						816-AR11D	5-1437537-4
	.180 PC LEAD		.295/.305	.400	.800	1	816-AG45D	5-1437537-3
	.180 PC LEAD						816-AG44D	5-1437537-2
	HIGH RETENTION						816-AG34D	5-1437537-1
	HIGH RETENTION						816-AG33D	5-1437537-0
OBSOLETE	-						816-AG12D	4-1437537-6
	-						816-AG11D	4-1437537-0
	-						816-AG10D	3-1437537-7
	.180 PC LEAD, W/RAILS S/B 3-1437537-3						814-AR44D	5-1437533-2
	W/RAILS						814-AR11D	3-1437537-5
	.180 PC LEAD		.295/.305	.400	.700	1	814-AG45D	3-1437537-4
	.180 PC LEAD						814-AG44D	3-1437537-3
	.180 PC LEAD						814-AG43D	3-1437537-2
	HIGH RETENTION						814-AG34D	3-1437537-1
	-						814-AG12D	2-1437537-9
	-						814-AG11D	2-1437537-4
	-						814-AG10D	2-1437537-1
OBSOLETE	W/RAILS						808-AR11D	1-1437537-9
	.180 PC LEAD		.295/.305	.400	.400	3	808-AG45D	1-1437537-8
	.180 PC LEAD						808-AG44D	1-1437537-7
	.180 PC LEAD						808-AG43D	1-1437537-5
	HIGH RETENTION						808-AG34D	1-1437537-4
	-						808-AG12D	1-1437537-2
	-						808-AG11D	0-1437537-8
	-						808-AG10D	0-1437537-5
	S/B 6-1437529-8		.295/.305	.400	.300	-	806-AG11D	2-1437533-5
	SUPERSEDED BY 6-1437529-5						806-AG10D	2-1437533-3
	COMMENTS	PLATING	C	B	A	FIG	AUGAT PART NO.	TE PART NO.

THIS DRAWING IS A CONTROLLED DOCUMENT.

DWN R BROWN 06MAY04

CHK K WRIGHT 06MAY04

APVD K WRIGHT 06MAY04

NAME

THIS DRAWING IS A CONTROLLED DOCUMENT.

DIMENSIONS: INCHES

TOLERANCES UNLESS OTHERWISE SPECIFIED:

0 PLC ± -

1 PLC ± -

2 PLC ± -

3 PLC ± .005

4 PLC ± -

ANGLES ± -

MATERIAL -

FINISH -

WEIGHT -

SIZE

CAGE CODE

DRAWING NO

RESTRICTED TO

CUSTOMER DRAWING

SCALE 1:1

SHEET 2 OF 4

REV A4

Tyco Electronics Corporation

Harrisburg, Pa 17105-3608

DIP SOCKET, 800 SERIES

00779

1437539-2

AMP 4805 REV 31MAR2000

800 SERIES STAMPED ECONOMY
CONTACT LEAD FREE PART NUMBER TABLE

OBSOLETE	W/RAILS		.595/.605	.700	2.400	2	848-AR11D-ES-LF	8-1437540-0
OBSOLETE	W/RAILS						840-AR12D-ES-LF	6-6447099-8
OBSOLETE	W/RAILS						840-AR11D-ESL-LF	7-1437540-2
OBSOLETE	W/RAILS		.595/.605	.700	2.000	2	840-AR11D-ES-LF	7-1437540-1
	.180 PC LEAD						840-AG44D-ESL-LF	7-1437540-0
OBSOLETE	W/RAILS						832-AR11D-ESL-LF	0-6437540-9
OBSOLETE	W/RAILS						832-AR11D-ES-LF	0-6437540-8
	.180 PC LEAD		.595/.605	.700	1.600	2	832-AG44D-ES-LF	0-6437540-7
	.180 PC LEAD						832-AG43D-ES-LF	0-6437540-6
OBSOLETE	.180 PC LEAD W/RAILS						828-AR44D-ESL-LF	9-6437539-8
OBSOLETE	W/RAILS						828-AR12D-ES-LF	6-6447099-7
OBSOLETE	W/RAILS		.595/.605	.700	1.400	1	828-AR11D-ES-LF	9-6437539-6
	.180 PC LEAD						828-AG44D-ES-LF	9-6437539-5
OBSOLETE	.180 PC LEAD W/RAILS		.295/.305	.400	1.200	1	824-AR47D-ESL-LF	8-6437533-3
OBSOLETE	W/RAILS		.295/.305	.400	1.200	1	824-AR31D-ES-LF	8-6437539-7
OBSOLETE	W/RAILS		.595/.605	.700	1.200	1	824-AR12D-ES-LF	6-6447099-6
	.180 PC LEAD		.595/.605	.700	1.200	1	824-AG44D-ESL-LF	8-6437539-3
	.180 PC LEAD		.395/.405	.500	1.100	1	822-AG44D-ES-LF	6-6437539-5
OBSOLETE	W/RAILS		.295/.305	.400	1.000	1	820-AR11D-ESL-LF	5-6437539-8
OBSOLETE	W/RAILS						820-AR11D-ES-LF	5-6437539-7
OBSOLETE	W/RAILS						816-AR11D-ESL-LF	3-6437539-5
OBSOLETE	W/RAILS						816-AR11D-ES-LF	3-6437539-4
	.180 PC LEAD		.295/.305	.400	.800	1	816-AG44D-ESL-LF	3-6437539-2
OBSOLETE	W/RAILS		.295/.305	.400	.700	1	814-AR11D-ES-LF	2-6437539-2
OBSOLETE	W/RAILS						808-AR11D-ES-LF	1-6437539-0
	.180 PC LEAD		.295/.305	.400	.400	1	808-AG43D-ES-LF	6437537-6
	COMMENTS	PLATING	C	B	A	FIG	AUGAT PART NO.	TE PART NO.

800 SERIES STAMPED ECONOMY
CONTACT PART NUMBER TABLE

OBSOLETE	.180 PC LEAD W/RAILS		.295/.305	.400	1.200	1	824-AR47D-ESL	8-1437533-3
SUPERSEDED	.180 PC LEAD W/RAILS S/B 8-1437539-3		.595/.605	.700	1.200	1	824-AR44D-ESL	8-1437533-2
OBSOLETE	W/RAILS		.295/.305	.400	1.200	1	824-AR31D-ESL	3-1437540-9
OBSOLETE	W/RAILS						824-AR31D-ES	8-1437539-7
OBSOLETE	W/RAILS						824-AR12D-ES	6-1447099-6
OBSOLETE	W/RAILS		.595/.605	.700	1.200	1	824-AR11D-ESL	8-1437539-6
OBSOLETE	W/RAILS						824-AR11D-ES	8-1437539-5
	-		.395/.405	.500	1.200	1	824-AG66D-ESL	8-1437539-4
	-						824-AG65D-ES	0-1571180-1
OBSOLETE	.180 PC LEAD		.595/.605	.700	1.200	1	824-AG44D-ESL	8-1437539-3
	-						824-AG32D-ES	8-1437539-1
	-						824-AG31D-ESL	7-1437539-7
	-		.295/.305	.400	1.200	1	824-AG31D-ES	7-1437539-6
	-						824-AG30D-ESL	7-1437539-4
	-						824-AG30D-ES	7-1437539-3
	-						824-AG12D-ES	7-1437539-2
	-		.595/.605	.700	1.200	1	824-AG11D-ESL	7-1437539-0
	-						824-AG11D-ES	6-1437539-9
	-						824-AG10D-ES	6-1437539-7
OBSOLETE	.180 PC LEAD						822-AG44D-ES	6-1437539-5
	-						822-AG12D-ES	6-1437539-4
	-		.395/.405	.500	1.100	1	822-AG11D-ESL	6-1437539-3
	-						822-AG11D-ES	6-1437539-2
OBSOLETE	-						822-AG10D-ES	6-1437539-0
SUPERSEDED	.180 PC LEAD W/RAILS S/B 7-1437537-4						820-AR44D-ESL	7-1437533-1
OBSOLETE	W/RAILS						820-AR11D-ESL	5-1437539-8
OBSOLETE	W/RAILS		.295/.305	.400	1.000	1	820-AR11D-ES	5-1437539-7
	.180 PC LEAD S/B 7-1437537-4						820-AG44D-ES	7-1437533-0
	-						820-AG12D-ES	5-1437539-6
	-						820-AG11D-ESL	5-1437539-3
	-						820-AG11D-ES	5-1437539-2
	-						820-AG10D-ES	5-1437539-0
	.180 PC LEAD W/RAILS S/B 4-1437539-9						818-AR44D-ESL	6-1437533-4
OBSOLETE	W/RAILS						818-AR11D-ESL	4-1437539-8
OBSOLETE	W/RAILS						818-AR11D-ES	4-1437539-7
	.180 PC LEAD S/B 6-1437537-1		.295/.305	.400	.900	1	818-AG44D-ESL	6-1437533-3
SUP. BY 1571552-5	-						818-AG12D-ES	4-1437539-6
	-						818-AG11D-ESL	4-1437539-4
	-						818-AG11D-ES	4-1437539-3
	-						818-AG10D-ES	4-1437539-1
OBSOLETE	W/RAILS						816-AR11D-ESL	3-1437539-5
OBSOLETE	W/RAILS						816-AR11D-ES	3-1437539-4
OBSOLETE	.180 PC LEAD		.295/.305	.400	.800	1	816-AG45D-ES	3-1437539-3
	.180 PC LEAD						816-AG44D-ESL	3-1437539-2
	-						816-AG12D-ES	3-1437539-1
	-						816-AG11D-ESL	2-1437539-9
	-						816-AG11D-ES	2-1437539-8
	-						816-AG10D-ES	2-1437539-6
	.180 PC LEAD, W/RAILS S/B 3-1437537-3						814-AR44D-ESL	5-1437533-3
OBSOLETE	W/RAILS						814-AR11D-ESL	2-1437539-3
OBSOLETE	W/RAILS						814-AR11D-ES	2-1437539-2
SUPERSEDED	.180 PC LEAD		.295/.305	.400	.700	1	814-AG45D-ES	2-1437539-1
	.180 PC LEAD S/B 3-1437537-3						814-AG44D-ESL	4-1437540-5
	-						814-AG12D-ES	2-1437539-0
	-						814-AG11D-ESL	1-1437539-7
	-						814-AG11D-ES	1-1437539-6
	-						814-AG10D-ES	1-1437539-4
	.180 PC W/RAILS, S/B 1437539-9						808-AR44D-ESL	3-1437533-1
OBSOLETE	W/RAILS						808-AR11D-ESL	1-1437539-1
	W/RAILS						808-AR11D-ES	1-1437539-0
OBSOLETE	.180 PC LEAD		.295/.305	.400	.400	1	808-AG44D-ESL	0-1437539-9
OBSOLETE	.180 PC LEAD						808-AG43D-ES	1-1437537-6
	-						808-AG12D-ES	0-1437539-8
	-						808-AG11D-ESL	0-1437539-6
	-						808-AG11D-ES	0-1437539-5
	-						808-AG10D-ES	0-1437539-2
	S/B 7-1437529-1		.295/.305	.400	.300	1	806-AG12D-ES	2-1437533-8
	S/B 1437535-8						806-AG11D-ESL	8-1437536-5
	S/B 1437535-7						806-AG11D-ES	2-1437533-7
	COMMENTS	PLATING	C	B	A	FIG	AUGAT PART NO.	TE PART NO.

OBSOLETE	-						864-AG12D-ES	5-1437538-3
	-		.895/.905	1.000	3.200	2	864-AG11D-ESL	5-1437538-0
	-						864-AG11D-ES	4-1437538-9
OBSOLETE	-						864-AG10D-ES	3-1437540-2
OBSOLETE	W/RAILS						848-AR11D-ESL	6-1437540-2
OBSOLETE	W/RAILS						848-AR11D-ES	3-1437540-0
	-		.595/.605	.700	2.400	2	848-AG12D-ES	2-1437540-8
	-						848-AG11D-ESL	4-1437538-2
OBSOLETE	-						848-AG11D-ES	2-1437540-6
	-						848-AG10D-ES	2-1437540-5
	-		.595/.605	.700	2.100	2	842-AG11D-ESL	2-1437540-4
	-						842-AG11D-ES	2-1437540-3
OBSOLETE	.180 PC LEAD W/RAILS S/B 2-1437540-0						840-AR44D-ESL	0-1437534-7
OBSOLETE	W/RAILS						840-AR12D-ES	6-1447099-8
OBSOLETE	W/RAILS						840-AR11D-ESL	2-1437540-2
OBSOLETE	W/RAILS		.595/.605	.700	2.000	2	840-AR11D-ES	2-1437540-1
	.180 PC LEAD						840-AG44D-ESL	2-1437540-0
	-						840-AG12D-ES	1-1437540-9
	-						840-AG11D-ESL	1-1437540-7
	-						840-AG11D-ES	1-1437540-6
	-						840-AG10D-ES	1-1437540-4
OBSOLETE	-		.595/.605	.700	1.800	2	836-AG12D-ES	1-1437540-2
	-						836-AG11D-ESL	1-1437540-1
	-						836-AG11D-ES	1-1437540-0
OBSOLETE	W/RAILS						832-AR11D-ESL	0-1437540-9
OBSOLETE	W/RAILS						832-AR11D-ES	0-1437540-8
	.180 PC LEAD S/B 1437540-1						832-AG45D-ESL	6-1437538-0
	.180 PC LEAD S/B 1437540-7		.595/.605	.700	1.600	2	832-AG44D-ESL	9-1437533-5
OBSOLETE	.180 PC LEAD						832-AG44D-ES	0-1437540-7
OBSOLETE	.180 PC LEAD						832-AG43D-ES	0-1437540-6
	-						832-AG12D-ES	0-1437540-5
	-						832-AG11D-ESL	0-1437540-3
	-						832-AG11D-ES	0-1437540-2
	-						832-AG10D-ES	0-1437540-1
OBSOLETE	.180 PC LEAD W/RAILS						828-AR44D-ESL	9-1437539-8
OBSOLETE	W/RAILS						828-AR12D-ES	6-1447099-7
OBSOLETE	W/RAILS						828-AR11D-ESL	9-1437539-7
OBSOLETE	W/RAILS						828-AR11D-ES	9-1437539-6
OBSOLETE	.180 PC LEAD		.595/.605	.700	1.400	1	828-AG44D-ES	9-1437539-5
	-						828-AG12D-ES	9-1437539-4
	-						828-AG11D-ESL	9-1437539-2
	-						828-AG11D-ES	9-1437539-1
	-						828-AG10D-ES	8-1437539-9
	COMMENTS	PLATING	C	B	A	FIG	AUGAT PART NO.	TE PART NO.

8

7

6

5

4

3

2

1

THIS DRAWING IS UNPUBLISHED.

RELEASED FOR PUBLICATION

BY TYCO ELECTRONICS CORPORATION.

ALL RIGHTS RESERVED.

LOCAD

DIST00

REV

LT

LT

DESCRIPTION

DATE

DWN

APVD

1000 SERIES MACHINED PREMIUM CONTACT, LOW INSERTION FORCE PART NUMBER TABLE

S/B 4-1437538-8		.895/.905	1.000	3.200	2	1064-AG11D	2-1437529-4
S/B 3-1437540-1		.895/.905	1.000	3.200	2	1064-AG10D	2-1437529-3
S/B 3-1437538-0		.595/.605	.700	2.000	2	1040-AG11D	2-1437529-2
S/B 2-1437538-2		.595/.605	.700	1.600	2	1032-AG11D	2-1437529-1
S/B 1437538-4		.595/.605	.700	1.400	1	1028-AG11D	1-1437529-9
S/B 8-1437537-9		.295/.305	.400	1.200	1	1024-AG31D	1-1437529-8
S/B 8-1437537-2		.595/.605	.700	1.200	1	1024-AG11D	1-1437529-6
S/B 8-1437537-1		.595/.605	.700	1.200	1	1024-AG10D	1-1437529-5
S/B 6-1437537-6		.295/.305	.400	1.000	1	1020-AG11D	1-1437529-4
S/B 6-1437537-4		.295/.305	.400	.900	1	1020-AG10D	1-1437529-3
S/B 5-1437537-7		.295/.305	.400	.900	1	1018-AG11D	1-1437529-2
S/B 5-1437537-6		.295/.305	.400	.900	1	1018-AG10D	1-1437529-1
S/B 4-1437537-0		.295/.305	.400	.800	1	1016-AG11D	1-1437529-0
S/B 3-1437537-7		.295/.305	.400	.800	1	1016-AG10D	0-1437529-9
S/B 2-1437537-4		.295/.305	.400	.700	1	1014-AG11D	0-1437529-7
S/B 2-1437537-1		.295/.305	.400	.700	1	1014-AG10D	0-1437529-6
S/B 1437537-8		.295/.305	.400	.400	3	1008-AG11D	0-1437529-5
S/B 1437537-5		.295/.305	.400	.400	3	1008-AG10D	0-1437529-4
COMMENTS	PLATING	C	B	A	FIG	AUGAT PART NO.	TE PART NO.

1800 SERIES MACHINED PREMIUM CONTACT, LOW GOLD PART NUMBER TABLE

S/B 5-1437538-0		.895/.905	1.000	3.200	2	1864-AG111D	5-1437529-1
S/B 6-1437540-2 W/RAILS		.595/.605	.700	2.400	2	1848-AR111D	5-1437529-0
S/B 4-1437538-2		.595/.605	.700	2.400	2	1848-AG111D	4-1437529-9
S/B 2-1437540-4		.595/.605	.700	2.100	2	1842-AG111D	4-1437529-8
S/B 2-1437540-2 W/RAILS		.595/.605	.700	2.000	2	1840-AR111D	4-1437529-7
S/B 1-1437540-7		.595/.605	.700	2.000	2	1840-AG111D	4-1437529-6
S/B 1437540-3		.595/.605	.700	1.600	2	1832-AG111D	4-1437529-5
S/B 9-1437539-7 W/RAILS		.595/.605	.700	1.400	1	1828-AR111D	4-1437529-4
S/B 9-1437539-2		.595/.605	.700	1.400	1	1828-AG111D	4-1437529-3
S/B 3-1437540-9 W/RAILS		.295/.305	.400	1.200	1	1824-AR131D	4-1437529-2
S/B 8-1437539-6 W/RAILS		.595/.605	.700	1.200	1	1824-AR111D	4-1437529-1
S/B 8-1437539-4		.395/.405	.500	1.200	1	1824-AG141D	4-1437529-0
S/B 7-1437539-7		.295/.305	.400	1.200	1	1824-AG131D	3-1437529-9
S/B 7-1437539-0		.595/.605	.700	1.200	1	1824-AG111D	3-1437529-8
S/B 6-1437539-3		.395/.405	.500	1.100	1	1822-AG111D	3-1437529-7
S/B 5-1437539-8 W/RAILS		.295/.305	.400	1.000	1	1820-AR111D	3-1437529-6
S/B 5-1437539-3		.295/.305	.400	1.000	1	1820-AG111D	3-1437529-5
S/B 4-1437539-8 W/RAILS		.295/.305	.400	.900	1	1818-AR111D	3-1437529-4
S/B 4-1437539-4		.295/.305	.400	.900	1	1818-AG111D	3-1437529-3
S/B 3-1437539-5 W/RAILS		.295/.305	.400	.800	1	1816-AR111D	3-1437529-2
S/B 2-1437539-9		.295/.305	.400	.800	1	1816-AG111D	3-1437529-1
S/B 2-1437539-3 W/RAILS		.295/.305	.400	.700	1	1814-AR111D	3-1437529-0
S/B 1-1437539-7		.295/.305	.400	.700	1	1814-AG111D	2-1437529-9
S/B 1-1437539-1 W/RAILS		.295/.305	.400	.400	3	1808-AR111D	2-1437529-6
S/B 1437539-6		.295/.305	.400	.400	3	1808-AG111D	2-1437529-5
S/B 1437535-8		.295/.305	.400	.300		1806-AG111D	0-1437535-2
COMMENTS	PLATING	C	B	A	FIG	AUGAT PART NO.	TE PART NO.

AMP 4805 REV 31MAR2000

THIS DRAWING IS A CONTROLLED DOCUMENT.

DIMENSIONS: INCHES

TOLERANCES UNLESS OTHERWISE SPECIFIED:

0 PLC ± .005

1 PLC ± .005

2 PLC ± .005

3 PLC ± .005

4 PLC ± .005

ANGLES ± .005

FINISH

MATERIAL

-

DWN R BROWN 06MAY04

CHK K WRIGHT 06MAY04

APVD K WRIGHT 06MAY04

PRODUCT SPEC

APPLICATION SPEC

WEIGHT

CUSTOMER DRAWING

Tyco Electronics Corporation

Harriaburg, Pa 17105-3608

DIP SOCKET, 800 SERIES

SIZE A1

CAGE CODE 00779

DRAWING NO 1437539-2

RESTRICTED TO

SCALE 1:1

SHEET 4 OF 4

REV A4

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[820-AG11D-ES-LF](#) [820-AG11D-LF](#) [820-AG11F-ES](#) [820-AG11D](#) [820-AG11D-ESL](#)