


Thermofit[®] Molded Parts
 Specification Control Drawing
 Limited Distribution

Part Number : 234A121-XS
 Description : Boot, Rectangular
 D-Subminiature, 90°, Side Entry,
 with Heat Recoverable Screen

NOTES

- All dimensions are in $\frac{\text{inches}}{\text{[millimeters]}}$
- Dimensions appearing in table are as follows:
 a - As Supplied
 b - After Unrestricted Recovery
- Coating is optional. As supplied dimensions appearing in table are for uncoated parts. When coating is added entry diameters will be reduced by .06 max.
 a- Conductive thermoplastic adhesive
 b- Structural thermoplastic adhesive

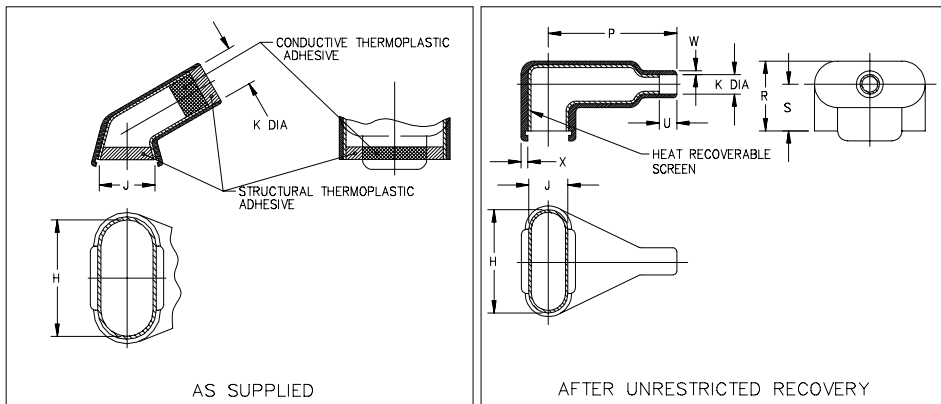

PART NUMBER	H		J		K		P Ref b	R Ref b	S Ref b	U ±20% b	W ±20% b	X ±20% b
	Min	Max	Min	Max	Min	Max						
	a	b	a	b	a	b						
234A121-XS	1.14 [29,0]	1.11 [28,2]	.59 [15,0]	.42 [10,7]	.45 [11,5]	.21 [5,3]	1.38 [35,1]	.74 [18,8]	.50 [12,7]	.19 [5,0]	.04 [1,0]	.12 [18,0]

Raychem

RAYCHEM CORPORATION
 300 CONSTITUTION DRIVE
 MENLO PARK, CALIFORNIA 94025


Revision : C
 Date : 4/28/93

Part Number : 234A121-XS
 Description : Boot, Rectangular
 D-Subminiature, 90°, Side Entry,
 with Heat Recoverable Screen

Thermofit[®] Molded Parts
 Specification Control Drawing
 Limited Distribution

Part Number : 234A121-XS
 Description : Boot, Rectangular
 D-Subminiature, 90°, Side Entry,
 with Heat Recoverable Screen

MATERIAL DASH NO.	MATERIAL DESCRIPTION	RT SPEC	COATING SLASH NO.	COATING S NO.	COATING DESCRIPTION
-3S	Polyolefin/Copper Composite	RT-1370	/200	N/A	Adhesives

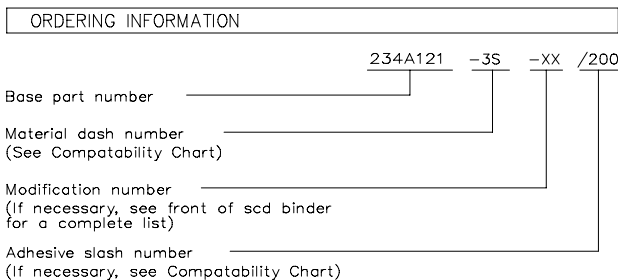

THIS DRAWING IS SUBJECT TO CHANGE WITHOUT NOTICE; CONSULT YOUR
 NEAREST FIELD REPRESENTATIVE FOR CURRENT REVISION

If this document is printed it becomes uncontrolled.
 Check for the latest revision.

Raychem

RAYCHEM CORPORATION
 300 CONSTITUTION DRIVE
 MENLO PARK, CALIFORNIA 94025

Revision : C
 Date : 4/28/94

Part Number : 234A121-XS
 Description : Boot, Rectangular
 D-Subminiature, 90°, Side Entry,
 with Heat Recoverable Screen

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[234A121-3S/200-0](#)