




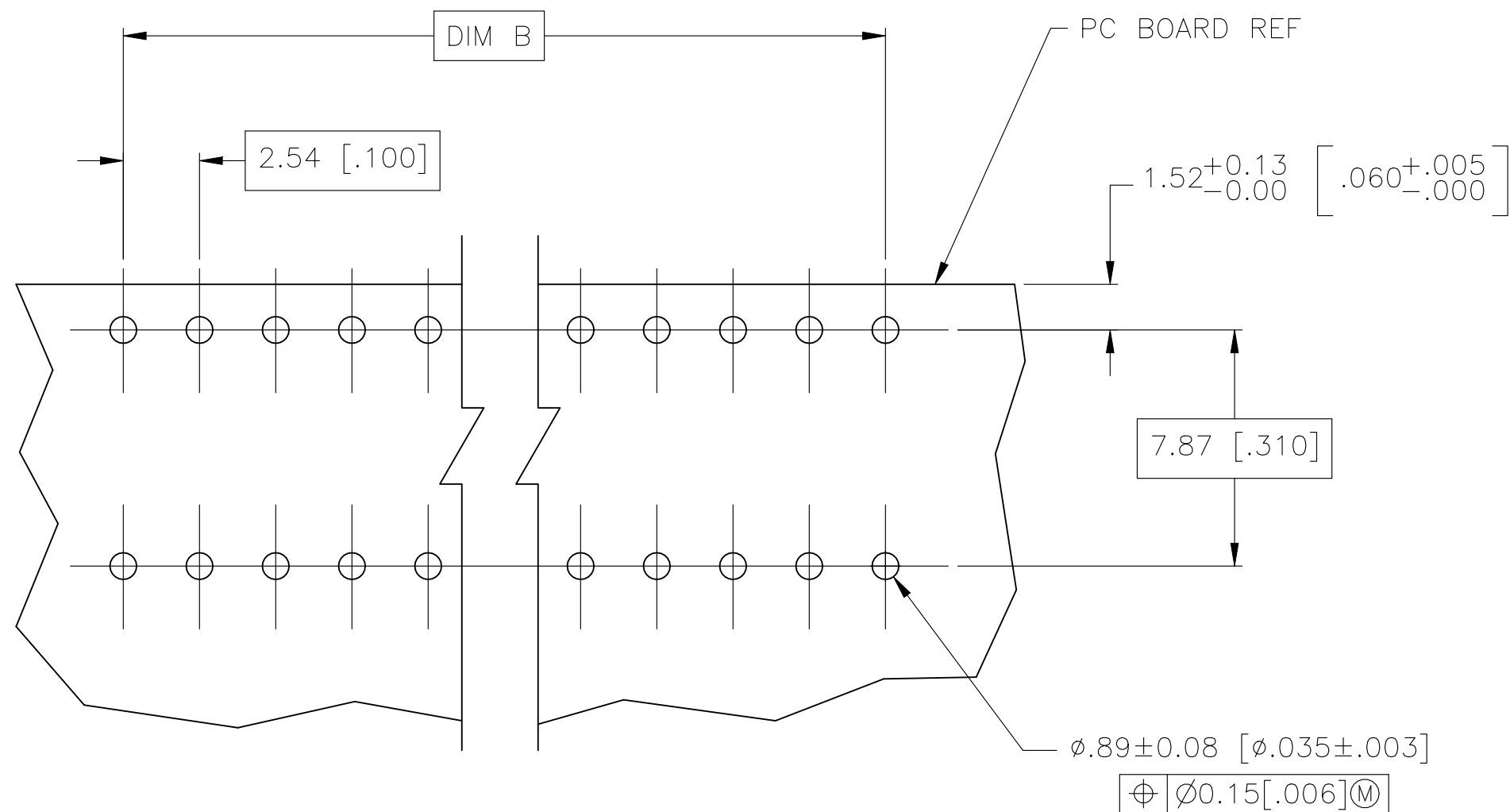

12	30.48[1.200]	33.02[1.300]	13	7-5535676-2
	162.56[6.400]	165.10[6.500]	65	6-5535676-4
	160.02[6.300]	162.56[6.400]	64	6-5535676-3
	157.48[6.200]	160.02[6.300]	63	6-5535676-2
	154.94[6.100]	157.48[6.200]	62	6-5535676-1
	152.40[6.000]	154.94[6.100]	61	6-5535676-0
	149.86[5.900]	152.40[6.000]	60	5-5535676-9
	147.32[5.800]	149.86[5.900]	59	5-5535676-8
	144.78[5.700]	147.32[5.800]	58	5-5535676-7
	139.70[5.500]	144.78[5.700]	57	5-5535676-6
	139.70[5.500]	142.24[5.600]	56	5-5535676-5
	137.16[5.400]	139.70[5.500]	55	5-5535676-4
134.62[5.300]	137.16[5.400]	54	5-5535676-3	
132.08[5.200]	134.62[5.300]	53	5-5535676-2	
129.54[5.100]	132.08[5.200]	52	5-5535676-1	
127.00[5.000]	129.54[5.100]	51	5-5535676-0	
124.46[4.900]	127.00[5.000]	50	4-5535676-9	
121.92[4.800]	124.46[4.900]	49	4-5535676-8	
119.38[4.700]	121.92[4.800]	48	4-5535676-7	
116.84[4.600]	119.38[4.700]	47	4-5535676-6	
114.30[4.500]	116.84[4.600]	46	4-5535676-5	
111.76[4.400]	114.30[4.500]	45	4-5535676-4	
109.22[4.300]	111.76[4.400]	44	4-5535676-3	
106.68[4.200]	109.22[4.300]	43	4-5535676-2	
104.14[4.100]	106.68[4.200]	42	4-5535676-1	
101.16[4.000]	104.14[4.100]	41	4-5535676-0	
99.06[3.900]	101.16[4.000]	40	3-5535676-9	
96.52[3.800]	99.06[3.900]	39	3-5535676-8	
93.98[3.700]	96.52[3.800]	38	3-5535676-7	
91.44[3.600]	93.98[3.700]	37	3-5535676-6	
88.90[3.500]	91.44[3.600]	36	3-5535676-5	
86.36[3.400]	88.90[3.500]	35	3-5535676-4	
83.82[3.300]	86.36[3.400]	34	3-5535676-3	
81.28[3.200]	83.82[3.300]	33	3-5535676-2	
78.74[3.100]	81.28[3.200]	32	3-5535676-1	
76.20[3.000]	78.74[3.100]	31	3-5535676-0	
73.66[2.900]	76.20[3.000]	30	2-5535676-9	
71.12[2.800]	73.66[2.900]	29	2-5535676-8	
68.58[2.700]	71.12[2.800]	28	2-5535676-7	
66.04[2.600]	68.58[2.700]	27	2-5535676-6	
63.50[2.500]	66.04[2.600]	26	2-5535676-5	
60.96[2.400]	63.50[2.500]	25	2-5535676-4	
58.42[2.300]	60.96[2.400]	24	2-5535676-3	
55.88[2.200]	58.42[2.300]	23	2-5535676-2	
53.34[2.100]	55.88[2.200]	22	2-5535676-1	
50.80[2.000]	53.34[2.100]	21	2-5535676-0	
48.26[1.900]	50.80[2.000]	20	1-5535676-9	
45.72[1.800]	48.26[1.900]	19	1-5535676-8	
43.18[1.700]	45.72[1.800]	18	1-5535676-7	
40.64[1.600]	43.18[1.700]	17	1-5535676-6	
38.10[1.500]	40.64[1.600]	16	1-5535676-5	
35.56[1.400]	38.10[1.500]	15	1-5535676-4	
33.02[1.300]	35.56[1.400]	14	1-5535676-3	
30.48[1.200]	33.02[1.300]	13	1-5535676-2	
27.94[1.100]	30.48[1.200]	12	1-5535676-1	
25.40[1.000]	27.94[1.100]	11	1-5535676-0	
22.86[.900]	25.40[1.000]	10	5535676-9	
17.78[.700]	22.86[.900]	9	5535676-8	
17.78[.700]	20.32[.800]	8	5535676-7	
15.24[.600]	17.78[.700]	7	5535676-6	
12.70[.500]	15.24[.600]	6	5535676-5	
10.16[.400]	12.70[.500]	5	5535676-4	
7.62[.300]	10.16[.400]	4	5535676-3	
5.08[.200]	7.62[.300]	3	5535676-2	
2.54[.100]	5.08[.200]	2	5535676-1	



1	HOUSING MATERIAL: GLASS FILLED POLYESTER, COLOR- BLACK
2	CONTACT MATERIAL: PHOSPHOR BRONZE
3	CONTACT FINISH: 0.00076[.000030] THK DUPLEX PLATED GOLD ON CONTACT AREA, 3.81-7.62(.000150-.000300) MATTE TIN ALL OVER 0.00127[.000050] MIN NICKEL
4	MOLDED IN ARROW DESIGNATES THE MATING FACE OF THE CONNECTOR
5	POINT OF MEASUREMENT FOR PLATING THICKNESS OF CONTACT AREA
6	DIMENSIONS PERTAIN TO HOUSING CAVITY CENTERLINES
7	PART NUMBER AND DATE CODE MARKED IN APPROXIMATE LOCATION SHOWN,EITHER END
8	ALTERNATE LOCATION FOR DATE CODE FOR 2 AND 3 POSITION.
9	NO PART NUMBER MARKING REQUIRED FOR THIS PART.
10	ROHS 2002/95/EC COMPLIANT.
11	TE LOGO AND CSA LOGO ARE MOLDED INTO HOUSING, THIS LOCATION
12	CON

THIS DRAWING IS A CONTROLLED DOCUMENT.						DWG BSV	05N0V64	 TE Connectivity	
DIMENSIONS:		TOLERANCES UNLESS OTHERWISE SPECIFIED:		CHEG J OLSON	REV J OLSON	NAME			
mm				PRODUCT SPEC		AMPMODU MODII RECP. ASSY., HORIZ., .100CL, 1 ROW CLOSED ENTRY, SPOC, END STACK			
	0 PL/C ± 1 PL/C ± 2 PL/C ± 3 PL/C ± 0.1% [.005] ANGLES ±	±		APPLICATION SPEC		SIZE		CAGE CODE	DRAWING NO
MATERIAL	FINISH		WEIGHT		A1 00779 C=5535676		RESTRICTED TO		-
 1 2	 3		CUSTOMER DRAWING		SCALE 5:1		SHEET 1 OF 1	REV B	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[5535676-2](#)