


REV. 1 9/25/98

COIL: @ 25°C	
RESISTANCE	100 OHMS ± 10%
NOMINAL VOLTAGE	5.0 VDC
MUST OPERATE VOLTAGE	2.8 VDC
TURN-ON BASE CURRENT	0.37 mADC
MUST RELEASE	0.22 VDC

CUSTOMER DATA SHEET

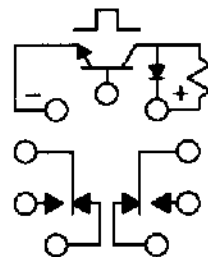

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

CONTACT RATING: LOW LEVEL TO 1A  
28 VDC RESISTIVE 100,000 OPERATIONS

NOTES:	TURN-ON TIME 4.0 MS MAX
	TURN-OFF TIME 7.5 MS MAX
	CONTACT BOUNCE 1.5 MS MAX

DR. R.B. 12/4/97 *OK* *ERRY* 9/28/98

 COMMUNICATIONS  
INSTRUMENTS, INC.

CUST. C. I. I. STD.  
 CUST. NO. \_\_\_\_\_

TYPE 'MST' RELAY

MSCT-5

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[6-1617547-9](#)