
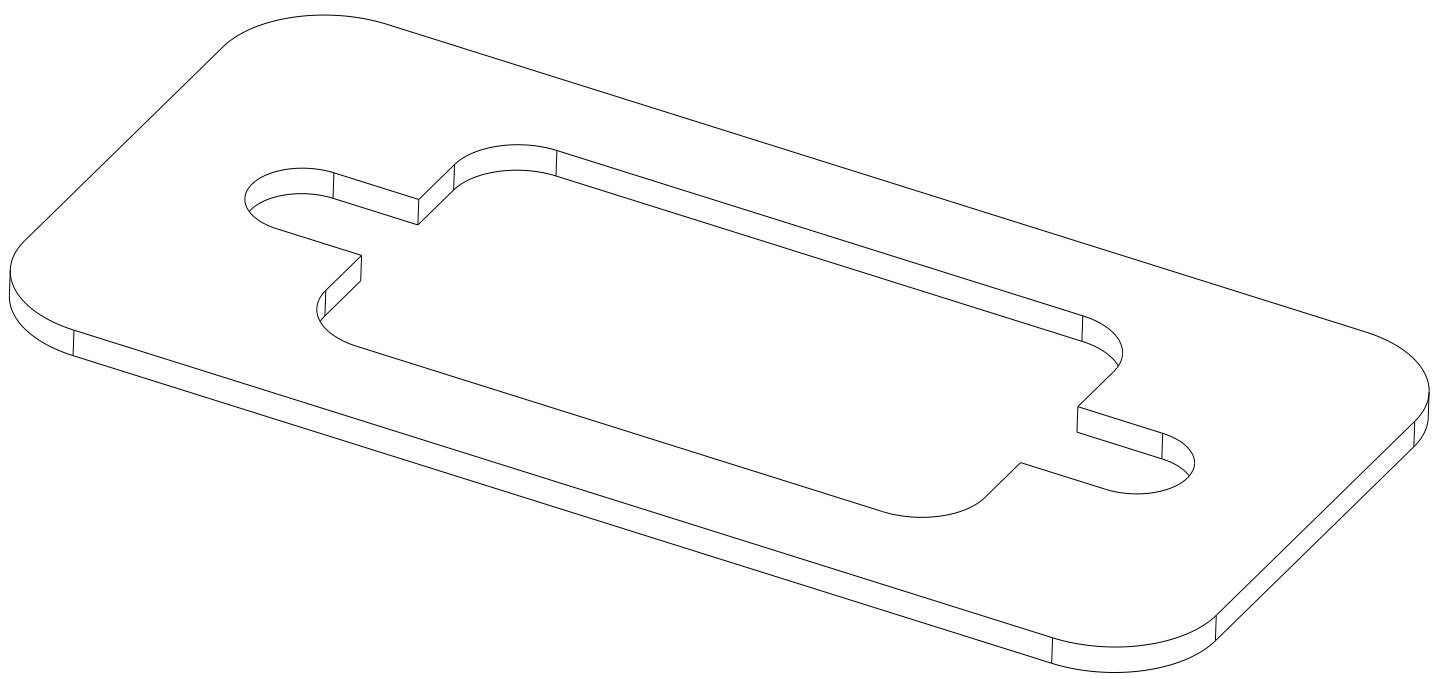
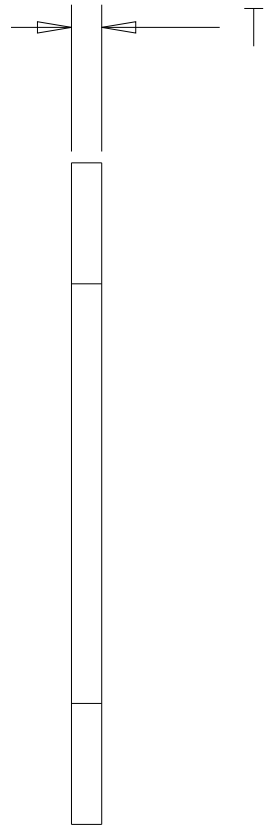


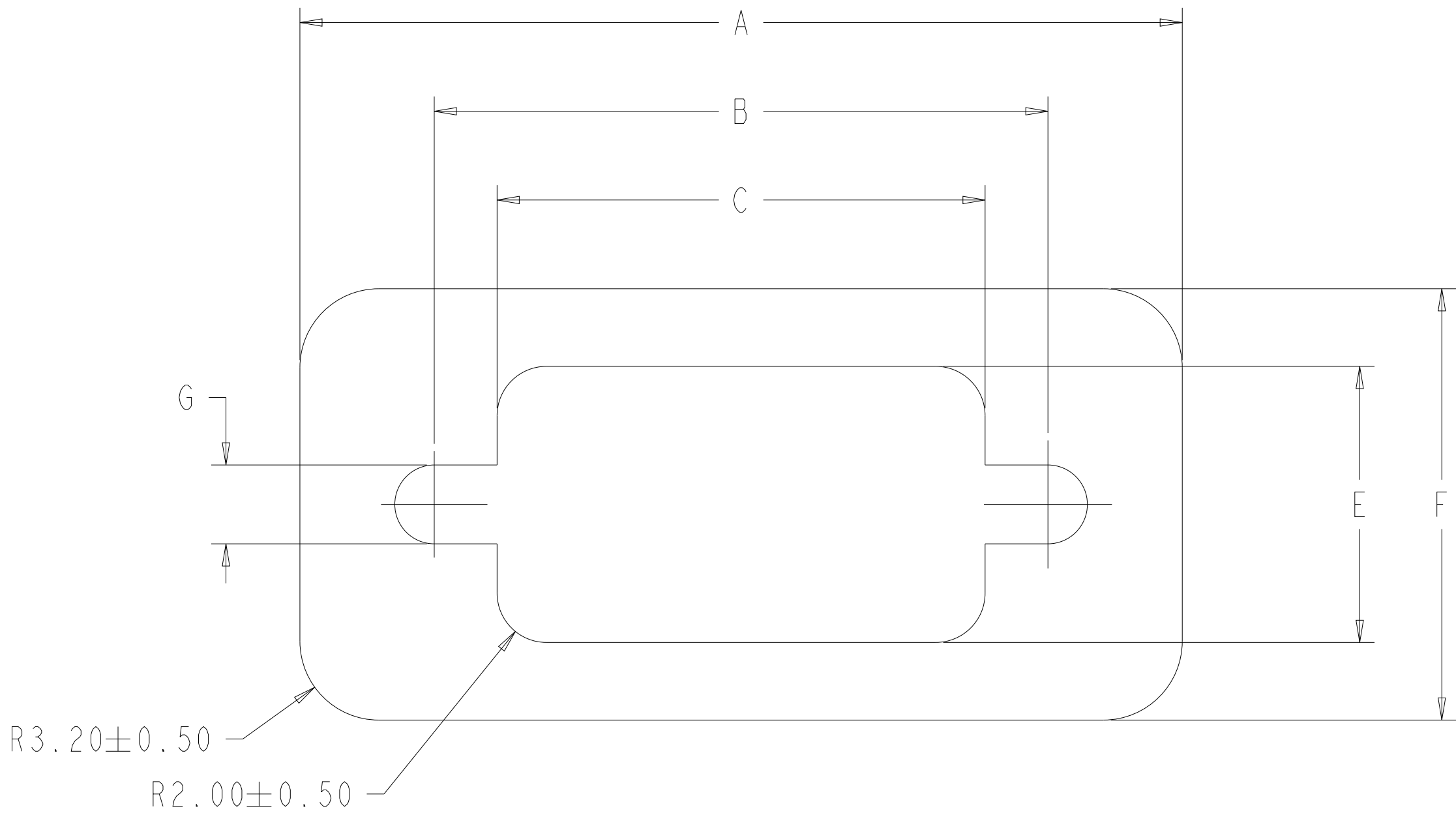

ISOMETRIC VIEW (NTS)

MATERIAL SPECIFIC DATA TABLE

TEST SPECIFICATION / MATERIAL CODE	SILICONE NICKEL ALUMINIUM (SNA)	FLUOROSILICONE NICKEL ALUMINIUM (FNA)
RECOMMENDED OPERATING TEMPERATURE RANGE (°C)	-55 to 125	-55 to 125
SPECIFIC GRAVITY ± 13%	2.000	2.300
SHORE A HARDNESS ± 7	70	70
MAXIMUM VOLUME RESISTIVITY (Ω.CM)	0.100	0.100

FNA	50	DARK GREEN	72.10	61.20	56.50	13.90	20.30	6.10	1.60	95-24020-1	2488723-1	95-24020-10	2488703-1
FNA	37	DARK GREEN	74.40	63.50	58.20	11.20	17.50	3.20	1.60	95-24019-1	2488722-1	95-24019-10	2488702-1
FNA	25	DARK GREEN	57.90	47.00	41.90	11.20	17.50	3.20	1.60	95-24018-1	2488721-1	95-24018-10	2488701-1
FNA	15	DARK GREEN	44.20	33.30	28.20	11.20	17.50	3.20	1.60	95-24017-1	2488720-1	95-24017-10	2488700-1
FNA	9	DARK GREEN	35.80	24.90	19.80	11.20	17.50	3.20	1.60	95-24016-1	2488719-1	95-24016-10	2488699-1
FNA	50	DARK GREEN	72.10	61.20	56.50	13.90	20.30	6.10	0.80	95-24015-1	2488718-1	95-24015-10	2488698-1
FNA	37	DARK GREEN	74.40	63.50	58.20	11.20	17.50	3.20	0.80	95-24014-1	2488717-1	95-24014-10	2488697-1
FNA	25	DARK GREEN	57.90	47.00	41.90	11.20	17.50	3.20	0.80	95-24013-1	2488716-1	95-24013-10	2488696-1
FNA	15	DARK GREEN	44.20	33.30	28.20	11.20	17.50	3.20	0.80	95-24012-1	2488715-1	95-24012-10	2488695-1
FNA	9	DARK GREEN	35.80	24.90	19.80	11.20	17.50	3.20	0.80	95-24011-1	2488714-1	95-24011-10	2488694-1
SNA	50	DARK GREY	72.10	61.20	56.50	13.90	20.30	6.10	1.60	95-24010-1	2488713-1	95-24010-10	2488693-1
SNA	37	DARK GREY	74.40	63.50	58.20	11.20	17.50	3.20	1.60	95-24009-1	2488712-1	95-24009-10	2488692-1
SNA	25	DARK GREY	57.90	47.00	41.90	11.20	17.50	3.20	1.60	95-24008-1	2488711-1	95-24008-10	2488691-1
SNA	15	DARK GREY	44.20	33.30	28.20	11.20	17.50	3.20	1.60	95-24007-1	2488710-1	95-24007-10	2488690-1
SNA	9	DARK GREY	35.80	24.90	19.80	11.20	17.50	3.20	1.60	95-24006-1	2488709-1	95-24006-10	2488689-1
SNA	50	DARK GREY	72.10	61.20	56.50	13.90	20.30	6.10	0.80	95-24005-1	2488708-1	95-24005-10	2488688-1
SNA	37	DARK GREY	74.40	63.50	58.20	11.20	17.50	3.20	0.80	95-24004-1	2488707-1	95-24004-10	2488687-1
SNA	25	DARK GREY	57.90	47.00	41.90	11.20	17.50	3.20	0.80	95-24003-1	2488706-1	95-24003-10	2488686-1
SNA	15	DARK GREY	44.20	33.30	28.20	11.20	17.50	3.20	0.80	95-24002-1	2488705-1	95-24002-10	2488685-1
SNA	9	DARK GREY	35.80	24.90	19.80	11.20	17.50	3.20	0.80	95-24001-1	2488704-1	95-24001-10	2488684-1
MATERIAL	PINS	COLOUR	A±0.5	B±0.4	C±0.2	E±0.2	F±0.5	G±0.2	T±0.15	IPK QTY	IPK QTY	IPK QTY	IPK QTY
										ALIAS PART NUMBER	ALIAS PART NUMBER	ALIAS PART NUMBER	ALIAS PART NUMBER

THIS DRAWING IS A CONTROLLED DOCUMENT.

DIMENSIONS: mm

0 PLC

1 PLC

2 PLC

3 PLC

4 PLC

ANGLES

FINISH

±

±

±

±

±

±

±

DWN: AYESHABANU N

CHK: BASAVARAJA D A

APVD: J MARTIN

PRODUCT SPEC

APPLICATION SPEC

WEIGHT

CUSTOMER DRAWING

27MAY2024

27MAY2024

27MAY2024

108-120068

114-120007

-

NAME

95-NA-ELASTOMER-D-SUB-RANGE

SIZE

CAGE CODE

DRAWING NO

RESTRICTED TO

TE Connectivity

95-NA-D-CONNECTOR-GASKETS

00779

SCALE 5:1

SHEET 1 OF 1

REV A

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[95-24002-1](#) [95-24010-10](#) [95-24007-10](#) [95-24008-10](#) [95-24007-1](#) [95-24002-10](#) [95-24008-1](#) [95-24003-10](#) [95-24001-10](#) [95-24009-1](#) [95-24009-10](#) [95-24005-1](#) [95-24006-1](#) [95-24003-1](#) [95-24001-1](#) [95-24010-1](#) [95-24004-1](#) [95-24004-10](#) [95-24005-10](#) [95-24006-10](#)