


REV. 1  
DCO 143744

COIL: @ 25°C  
 RESISTANCE 1560 OHMS ± 10%  
 NOMINAL VOLTAGE 26.5 VDC  
 MUST OPERATE 14.2 VDC  
 TURN-ON BASE CURRENT 0.13 mADC  
 MUST RELEASE 8.0 VDC MAX., 1.37 VDC MIN.

ENVIRONMENT:  
 VIBRATION 10 Hz TO 3000 Hz @ 30 g's  
 SHOCK 75 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: TURN-ON TIME 2.0 MS MAX.  
 TURN-OFF TIME 7.5 MS MAX.  
 CONTACT BOUNCE 1.5 MS MAX.

# CUSTOMER DATA SHEET

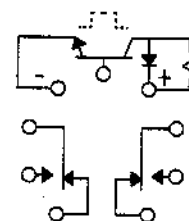

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A  
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 15APR03

CK. *[Signature]* 4/21/03

**CII Technologies**  
 advanced control electronic solutions

CUST. GPL  
 CUST. NO. M28776/1-024L REV.

"JMAT" RELAY

JMAPT-26XL

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMAPT-26XL](#)