


REV. 0
DCO 143304

COIL: @ 25 $^\circ$ C
 RESISTANCE 2000 OHMS \pm 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 14.2 VDC
 MUST RELEASE 8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 $^\circ$ C TO +125 $^\circ$ C

NOTES: OPERATE TIME 2.0 MS MAX.
 RELEASE TIME 4.0 MS MAX.
 CONTACT STABILIZATION TIME 2.0 MS MAX.

CUSTOMER DATA SHEET

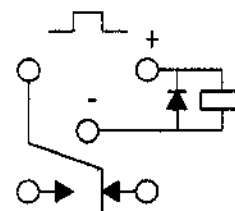

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. ASB 11/13/01

11/13/01

CII Technologies
 advanced control electronic solutions

CUST. OPL
 CUST. NO. M39016/23-024P REV.

"JIMAD" RELAY

J1MAPD-26XP

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[J1MAPD-26XP](#)