




RAST 5

TE Internal #: 2355812-3

TE Internal Description: 3P, RAST 5 HEADER, DIN, SILVER, SHROUDED

[View on TE.com >](#)

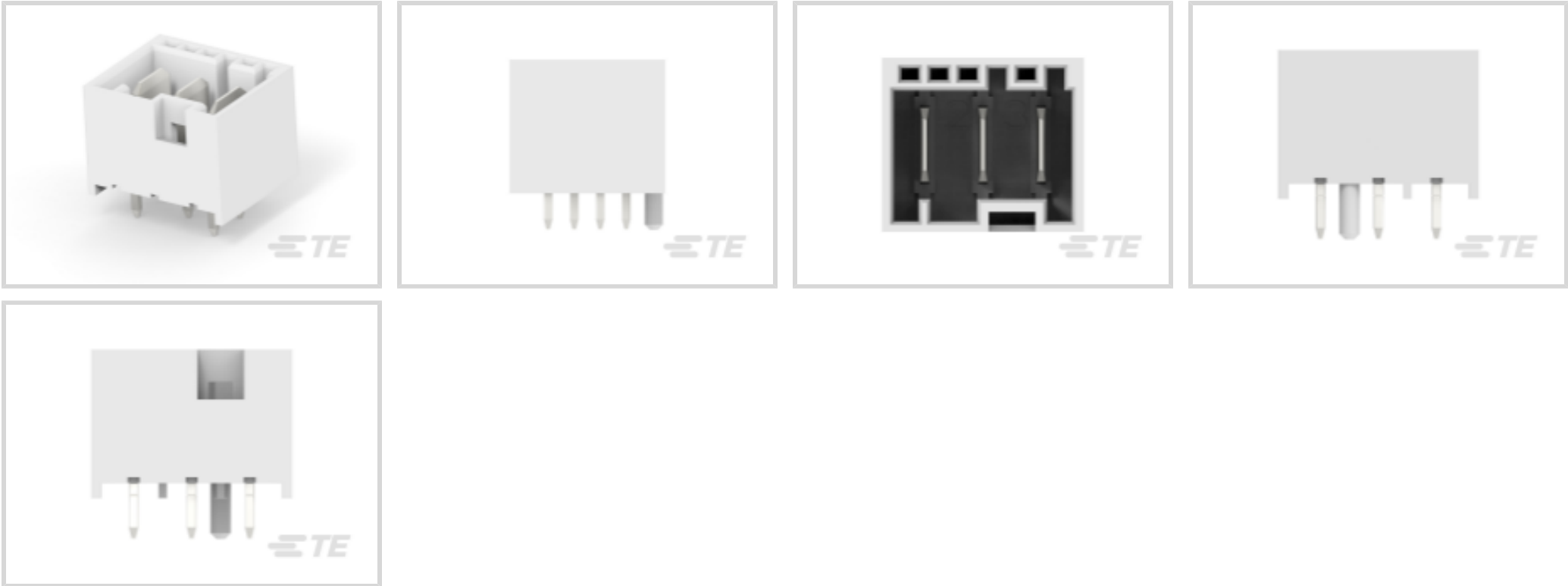

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 2532387-3
3P, RAST 5 HEADER, DIN, SILVER, SHROUDED

TE Part # 1-2407487-3
3POS STD TIMER HSG W.INTER. LOCK. GW-V0

Also in the Series | RAST 5

Connector Contacts(1)

Connector Hardware(3)

PCB Headers & Receptacles(130)

Rectangular Power Connectors(134)

Standard Edge Connectors(8)

Wire-to-Board Connector Assemblies & Housings(19)

Wire-to-Board Headers & Receptacles (130)

Customers Also Bought

TE Part #2132230-5
EP2.5 Shrouded HDR ASSY 5P VER

TE Part #2404280-5
EP 2.5 HDR, GLOW WIRE, 5P

TE Part #2407489-3
3P, RAST 5 HEADER, DIN, SILVER, SHROUDED

TE Part #6-2338245-4
EP2.5 HDR 4P VERT BOSS,yellow,UL

TE Part #1877285-8
08P EP SHRD HDR ASMY, WHITE

TE Part #2132230-4
EP2.5 Shrouded HDR ASSY 4P VER

TE Part #2238190-1
LOW PROFILE MINI AMP-IN SM

TE Part #1-2355813-3
3P, RAST5 POTTED HEADER DIN, SILVER, SL



TE Part #1-1969543-0
ASSY, HDR, VERT, 10P, DUAL ROW, EP2.5



TE Part #1969498-1
ASSY, TAB HDR, 7MM, 6.35 SERIES, 2 POS

Documents

Product Drawings

3P, RAST 5 HEADER, DIN, SILVER, SHROUDED

English

CAD Files

Customer View Model

ENG_CVM_CVM_2355812-3_B1.3d_stp.zip

English

Customer View Model

ENG_CVM_CVM_2355812-3_B1.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_2355812-3_B1.3d_igs.zip

English

3D PDF

3D

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

RAST Connector System Catalog

English

Agency Approvals

VDE Certificate

English

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[2355812-3](#)