



Application Tooling > Hand Crimping Tools



Die Sets Type: **Fixed In Tool**

Tooling Type: **Head Assembly**

### Features

#### Other

Die Sets Type	Fixed In Tool
Tooling Type	Head Assembly

### Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2024 (240) Candidate List Declared Against: JUL 2021 (219) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


#### Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

## Compatible Parts



TE Part # 36954  
PIDG SLTD 22-16COMM 22-18MIL 8



TE Part # CAT-P592-R472A  
PIDG Ring Tongue Terminals


TE Part # 1490567-1  
HAND NON-LOGIC SHORT POWER UNI

TE Part # 1673611-1  
SHORT TOOL HOLDER W/RATCHET UNI


## Customers Also Bought



TE Part #2-1617037-2  
HFW5A1230K00 = HFW5A RELAY

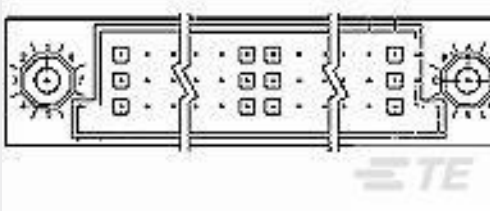


TE Part #532447-8  
HDI PIN ASSY 3 ROW 165 POS

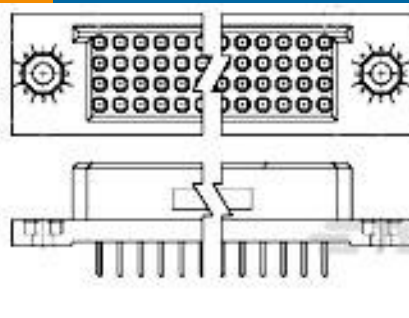

TE Part #533285-2  
BOX II 4 ROW 120 POS RCPT ASSY



TE Part #448140-6  
CONTACT,PIN,SZ 12,POSTED

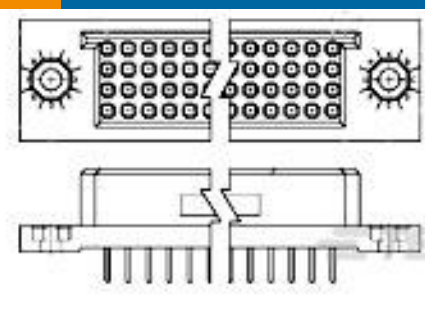

TE Part #533492-1  
BOX II 4 ROW RECP ASSY 160 POS



TE Part #7-1617805-4  
PRMGSTE-5YW=PR COTS MOSFET GRID RELAY

TE Part #1-582591-1  
AMP TAB ASSY 31 POS 100 C/L

TE Part #39208  
RING

TE Part #447613-1  
3510 SW,DUAL-CONC,4 LAYER

## Documents

[Datasheets & Catalog Pages](#)

[Bottoming Dies](#)

English

[Instruction Sheets](#)

[Instruction Sheet \(U.S.\)](#)



English

[Instruction Sheet \(U.S.\)](#)

English

[Instruction Sheet \(U.S.\)](#)

English

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[314270-3](#)