



Identification & Labeling > Labels > Standard Labels > SP Self Laminating Polyester Labels



Label Type: **Self-Laminating**
Label Style: **Die-Cut**
Label Adhesive Type: **Permanent Acrylic Adhesive**
Product Width: **25.4 mm [1 in]**
Length of Label Roll: **84.66 m [277.75 ft]**

[All SP Self Laminating Polyester Labels \(10\)](#)

Features

Product Type Features

Printable Label Height	25.4 mm[1 in]
Label Type	Self-Laminating

Body Features

Primary Product Material	Polyester
--------------------------	-----------

Dimensions

Product Width	25.4 mm[1 in]
Product Height	95.3 mm[3.75 in]
Compatible Cable Diameter Range	8.1 – 22.2 mm[.318 – .875 in]

Usage Conditions

Operating Temperature Range	-40 – 150 °C[-40 – 302 °F]
-----------------------------	----------------------------

Printer/Label Features

Number of Labels Across	3
Label Style	Die-Cut
Length of Label Roll	84.66 m[277.75 ft]
Label Thickness	45 Micron



Packaging Features

Packaging Quantity	2500
Packaging Method	Roll

Other

Label Adhesive Type	Permanent Acrylic Adhesive
---------------------	----------------------------

Product Compliance

For compliance documentation, visit the product page on [TE.com](#)>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2024 (240) Candidate List Declared Against: JUNE 2023 (235) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1-2186500-1
T3212-PRINTER

TE Part # 1-2186502-1
T3224-PRINTER

TE Part # 1-2186503-1
T3224-SWARE-PRINTER

TE Part # 1-2186501-1
T3212-SWARE-PRINTER

TE Part # 1-2186527-1
T2212-PRINTER

TE Part # 1-2186528-1
T2212-SWARE-PRINTER

TE Part # 1-2186576-1
T7112DS-PRINTER

TE Part # 1-2186577-1
T7112DS-SWARE-PRINTER

Also in the Series | CGS SP

Primary Wire(4)

RJ45 Connectors(9)

Standard Circular Connectors(4)

Standard Labels(10)

Surface Mount Resistors(40)

Through-Hole Resistors(1)

Twisted Pair Cable(1)

Customers Also Bought

TE Part #C95061-000
202K111-25-01-0

TE Part #1-2308272-2
CABLE CLAMP2 (CASE RAW)

TE Part #4-640427-2
12P MTA156 CONN ASSY 20AWG YEL

TE Part #350570-2
UMNLSOK 24-18 AUBR


SP100375WE2.5

Standard Labels, Width 25.4 mm [1 in], Height 95.3 mm [3.75 in], Compatible Cable Diameter Range 8.1 – 22.2 mm [.318 – .875 in], Polyester, CGS SP






TE Part #170360-4
MINI UNIVERSAL M-N-L PIN

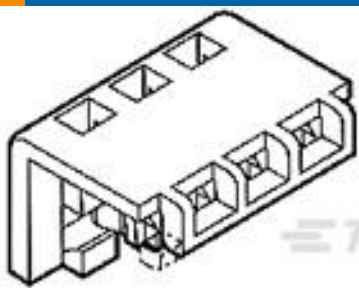

TE Part #643067-5
05P MTA156 MOLDED COVER

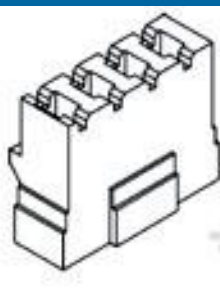

TE Part #1609140-3
PA105 J0=F6806



TE Part #1028-024-0305
BKSHL, 3P, BLK, REC, ST, NW 8.5



TE Part #323751
DIAMOND GRIP 12-10 HT R 1/4



TE Part #1-66109-6
III+ SKT,26-24,30AU/FL,SMPACK

Documents

Product Drawings

SP100375WE2.5

English

Datasheets & Catalog Pages

IDENTIFICATION SELECTION GUIDE

English

Self Laminating Polyester (SP) Technical Datasheet

English

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[SP100375WE2.5](#)