



A range of panel mounting audio and video connectors

Features include.

- . A simple press down release clip
- . Generous solder buckets for easy cable assembly
- . Available in two finishes satin nickel or Black
- . Available with Silver or Gold contacts

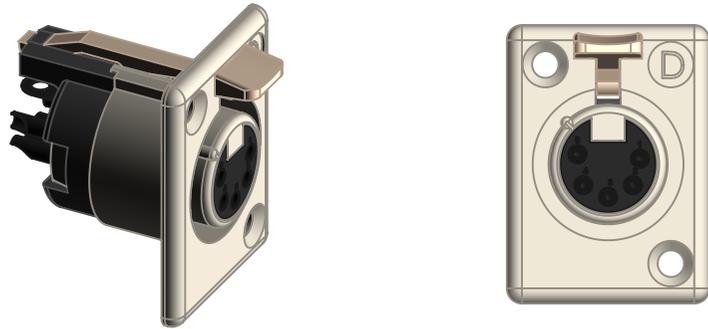

DIMENSIONS

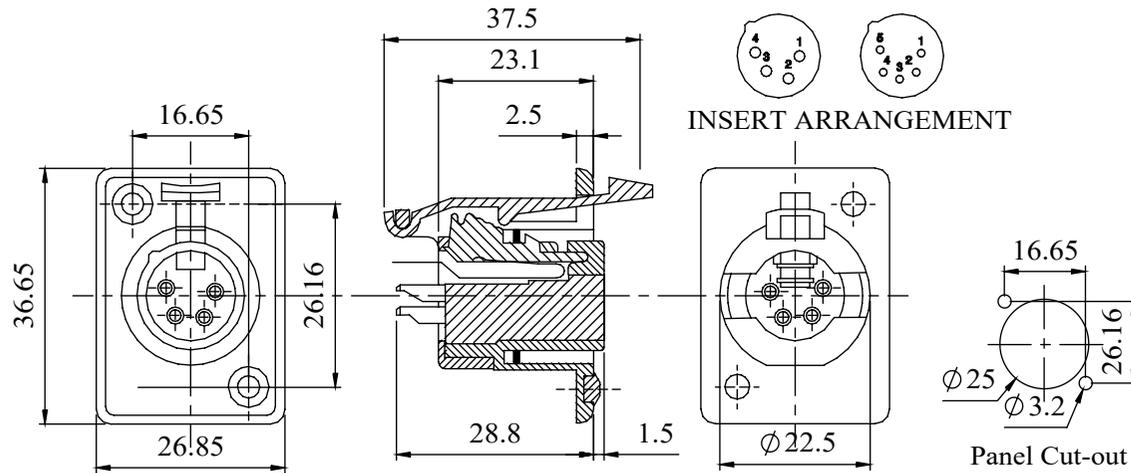

Mechanical Properties

	Material	Finish
Housing	Zinc high pressure die-casting	Satin nickel or black chrome
Contact base	Valox DR48	Black
Contacts	Brass	Silver or Gold Plated
Collar	Valox DR48	Black
Inner Latch	Zinc high pressure die-casting	Bright Nickel plated
Chuck	Acetal (UL 94 HB)	Black
Earth Tag Spring	Spring Steel	Silver Plated
Sealing Ring	PVC	Black
Housing Latch	Zinc high pressure die-casting	Bright Nickel plated

Electrical Properties

Rated Voltage	50 V a.c	
Test Voltage	1000 V r.m.s	
Insulation Resistance	103 MΩ	
After Damp Heat	500MΩ	
Contact Resistance	10mΩ max	
Current rating at 40 °C	4 pin, 10 amp	5 pin, 7.5 amp
Current rating at 70 °C	4 pin, 5 amp	5 PIN, 3 amp
Terminal Wire Size	4 pin 1.5 mm ² / 16 AWG	5 pin 1.0 mm ² / 18 AWG

Climatic Properties

Climatic category	25/070/04	
Temperature Range	-25 °C to +70 °C	
Damp heat, Steady state	4 days	

DELTRON PART NUMBERS	Silver contacts		Gold contacts	
	Nickel	Black	Nickel	Black
4 WAY	702-0400	710-0400	OBS	714-0400
5 WAY	702-0500	710-0500	706-0500	714-0500

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Deltron:](#)

[702-0400](#)