



0906 UTP 301-Y




DeviceNet T-Connectors / Taps

7/8" Male to 2 x 7/8" Female

Splitter/T-connector, with one 7/8" female, one 7/8" male, and one 7/8" female connectors, 5-poles - overmold color yellow.

– especially suitable for DeviceNet modules with 7/8" bus connection –


0906 UTP 301-Y

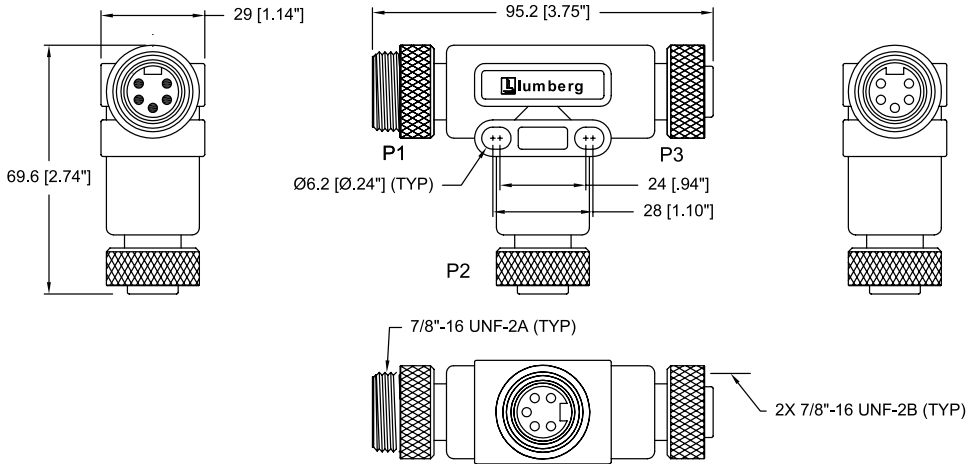


Pin Assignments

Face Views

7/8" - 5 poles

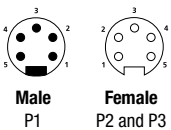

Wiring Diagrams

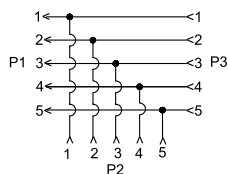



Be Certain with Belden

DeviceNet T-Connectors / Taps

0906 UTP 301-Y

Technical Data

Environmental

Degree of protection IP 68 / NEMA 6P
 Operating temperature range -40°C (-40°F) / +90°C (+194°F)

Mechanical

Housing / Molded body PUR, yellow
 Insert PUR, yellow
 Contact Solid-machined brass, gold over nickel plated
 Coupling nut Aluminum, black anodized

Electrical

Current rating
 P1 and P3: 8A (trunk)
 P2: 4A (drop)
 Voltage rating 300 V

Part Number	Pins	Characteristics
-------------	------	-----------------

0906 UTP 301-Y

5



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Lumberg Automation:](#)

[0906 UTP 301-Y](#)