

**FEATURES:**

- Semi-Diffused
- Instant On
- Directional Efficiency
- Mercury Free
- Low Profile
- Lead Free
- Long Life
- No UV

The Peninsula's durable plastic construction makes it an economical lightweight luminaire delivering a wide range of semi-diffused light output.

**SPECIFICATIONS**

Color Temperature	Lumen Output	Efficacy (lm/W)	Color Rendering Index (CRI)
Cool (C) - 6500K	190	95	80
Neutral (N) - 4500K	180	90	75
Warm (W) - 3000K	170	85	70
Soft (S) - 2700K	160	85	66


Rated Life:	50,000 hours
Beam Angle:	120°
Power Consumption:	2 Watts
Operating Temperature:	0° C ~+ 40° C
Voltage Input:	24VDC, Constant Voltage
Controls:	See Accessory SW-1001
Housing:	Extruded Plastic, Black Polycarbonate Lens, Clear
Weight:	53
Dimensions:	W .83" (21.1mm) H .60" (15.2mm) L 12" (304.8mm) ** **not including mounts

Compliance:



Restriction of Hazardous Substances Directive (RoHS) implements EU Directive 2002 / 95 which bans placing electrical and hazardous equipment that contains more than agreed levels of hazardous substances on the EU market. For a list of these substances, visit [www.rohs.gov.uk](http://www.rohs.gov.uk).

**DIMENSIONS**

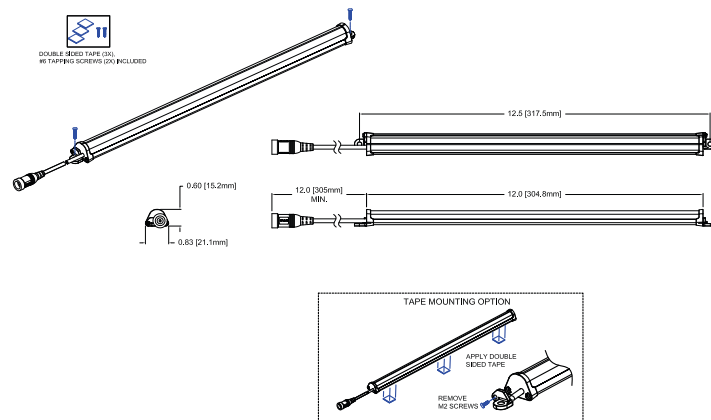

# PENINSULA SERIES

## P3100 STANDARD (S)

### ORDERING INFORMATION

Choose the option that best suits your needs and write its corresponding code on the appropriate line to form product code.

Model	Color	Type	Example
P3100	C - 6500K N - 4500K W - 3000K S - 2700K	S-Standard	P3100-C-S

All luminaires are easily customizable. Please contact us to inquire about customizing a luminaires to fill your needs.

Order power accessories as separate catalog numbers from the Accessories section below. (Note: 2 mounting screws and double sided tape included for mounting of Standard luminaires.)

### ACCESSORIES

Universal Regulated Quick Connect Power Supply (North American Plug)

Universal Regulated Quick Connect Power Supply (Euro Plug)




In-line On/Off Switch

Califia Lighting Part #WA-UL-001

Califia Lighting Part #WA-VDE-001

Califia Lighting Part #SW-1001

### PHOTOMETRY CHARACTERISTICS

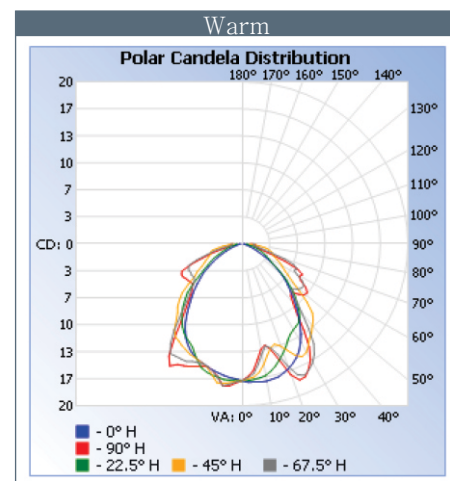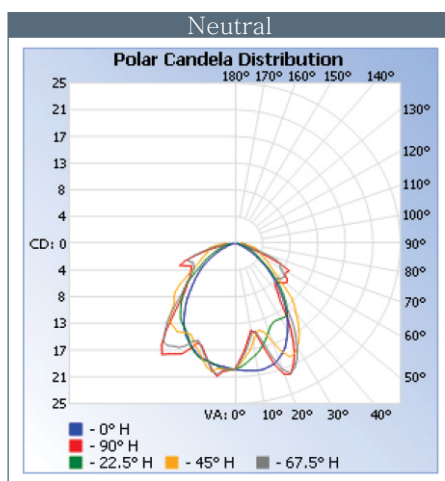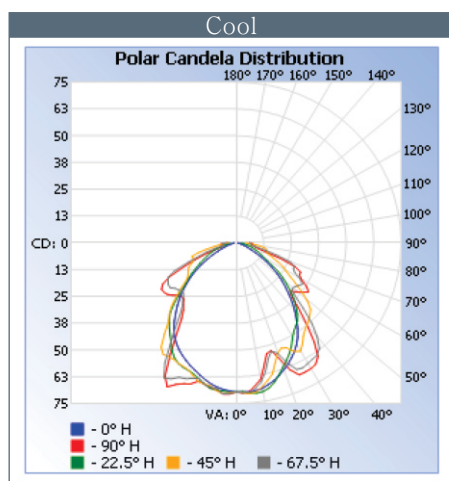

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Califia:](#)

[P3100-W-S](#) [P3100-N-S](#) [P3100-S-S](#) [P3100-C-S](#)