
 


PAGE 1/2	ISSUE 21-09-16A	SERIES SPLITTER	PART NUMBER R434414002
----------	-----------------	---------------------------	-------------------------------

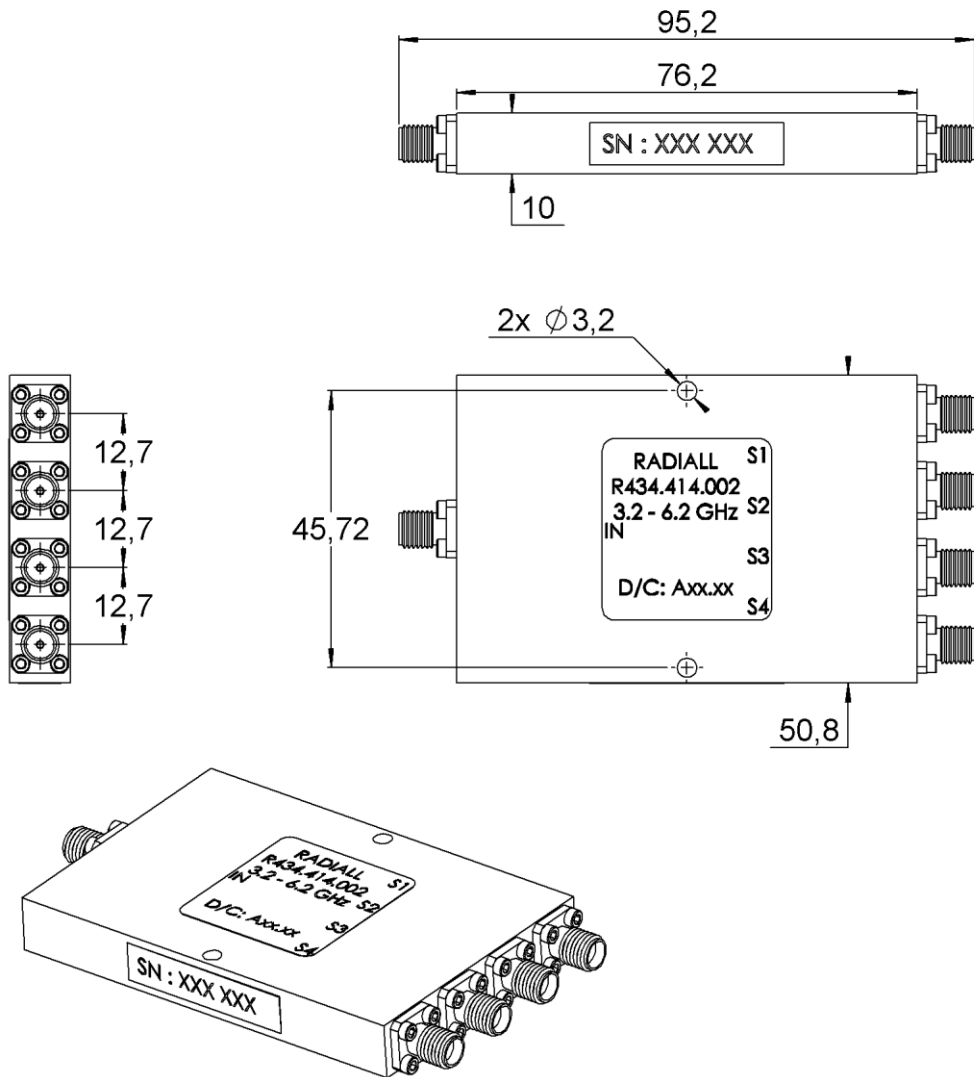

All dimensions are in mm.

Weight **111,2310** g
Specification



PAGE 2/2	ISSUE 21-09-16A	SERIES SPLITTER	PART NUMBER R434414002
----------	-----------------	---------------------------	-------------------------------

ELECTICAL CHARACTERISTICS

Frequency range :	3.2 – 6.2 GHz
Number of ways	4
Phase	0°
VSWR	
Input	1.5
Output	1.5
Impedance	50 Ohms
Insertion loss	0.9 dB max
Isolation	20 dB mini
Amplitude balance	± 0.4 dB
Phase Balance	± 6°
Average Power	
VSWR load < 1.2	30W
VSWR load : inf	1W

MECHANICAL CHARACTERISTICS

Connectors :	
Input	SMA female
Output	SMA female
Body	Aluminium
Finish	Blue Paint

ENVIRONMENTAL CHARACTERISTICS

Operating temperature	-40 / +85 °C
Storage temperature	-55 / +125 °C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Radial:](#)

[R434414002](#)