




ACCLIMATE™

MCRK-8-S

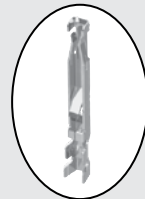

CC393-2830-L-S

MCRK, CC393 SERIES

# 8 SERIES IP67 FIELD TERMINATION KIT

Mates with:  
MCP(K)

## SPECIFICATIONS

For complete specifications see [www.samtec.com?MCRK](http://www.samtec.com?MCRK)

**Insulator Material:**  
PPS

**Contact Material:**  
Phosphor Bronze

**Operating Temp Range:**  
-20 °C to +80 °C


**Gasket Material:**  
Neoprene Rubber

**Lock Washer:**  
Phosphor Bronze, Ni plated

**Hex Nut:**  
Brass, Ni plated

**RoHS Compliant:**  
Yes

## PANEL OPENING

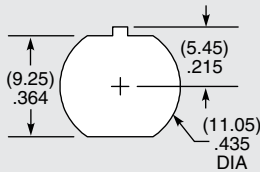


**Note:** Samtec's MCRK Series is dual sourced by Hirose Electric Co., LTD.



## DUST CAPS

- DCA-MCR-8

Visit [sealedio.samtec.com](http://sealedio.samtec.com) for a complete list of sealed systems

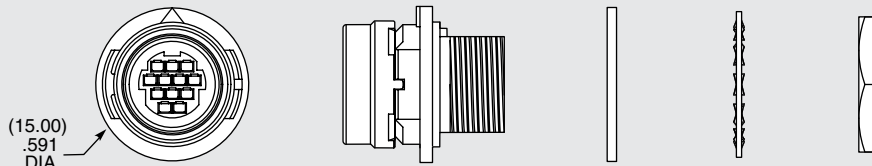




## SPECIFICATIONS

For complete specifications see [www.samtec.com?CC393](http://www.samtec.com?CC393)

**Plating:**  
10 μm (0.25 μm) Gold on contact

## TOOLING

 - Hand Tool:  
CAT-HT-393-2430-13
- Mini Applicator  
(28-30 AWG):  
CAT-MC-393-2830-XX-01
- Extraction Tool:  
CAT-EX-MCX-8-01

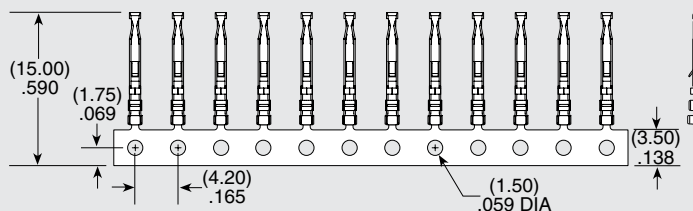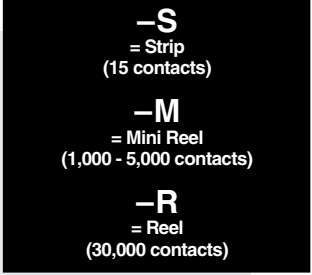

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[CC393-2830-L-M](#)