




(2,00 mm) .0787"

(2,54 mm) .100"

BTMM, BSW SERIES

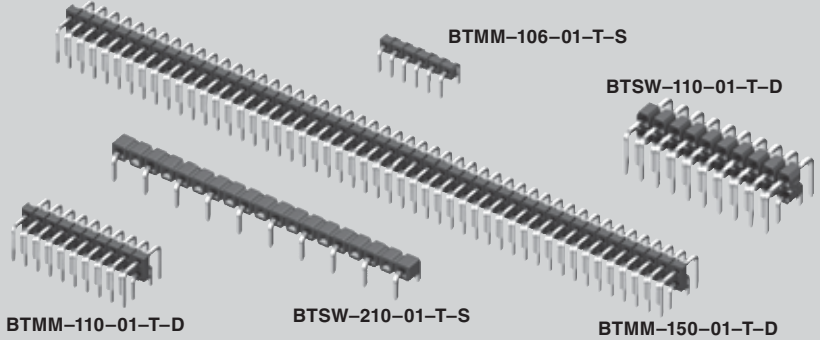

LOW PROFILE SQUARE POST JUMPER

SPECIFICATIONS

For complete specifications see www.samtec.com?BTMM

Insulator Material:

Black Liquid Crystal Polymer

Terminal Material:

Phosphor Bronze

Plating:

Sn over 50µ" (1,27 µm) Ni

Operating Temp Range:


-55°C to +105°C

RoHS Compliant:

Yes

Lead-Free Solderable:

Yes

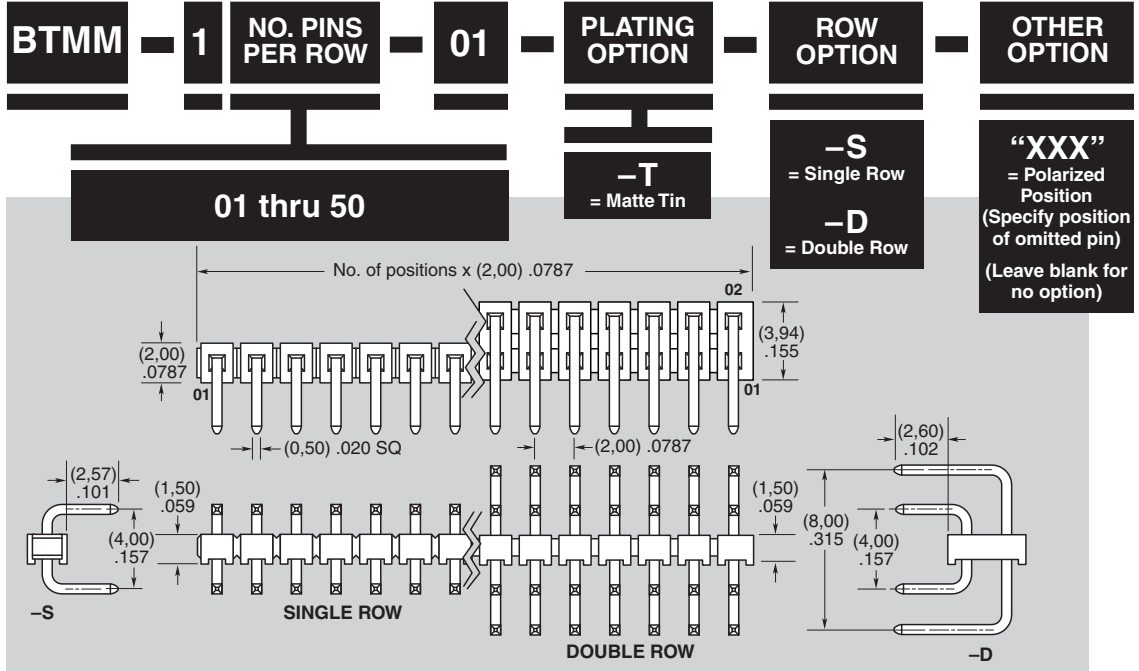

Note: Some sizes, styles and options are non-standard, non-returnable.

SPECIFICATIONS

For complete specifications see www.samtec.com?BSW

Insulator Material:

Black Glass Filled Polyester

Terminal Material:

Phosphor Bronze

Plating:

Sn over 50µ" (1,27 µm) Ni

Operating Temp Range:


-55°C to +105°C

RoHS Compliant:


Yes

Lead-Free Solderable:

Wave Only

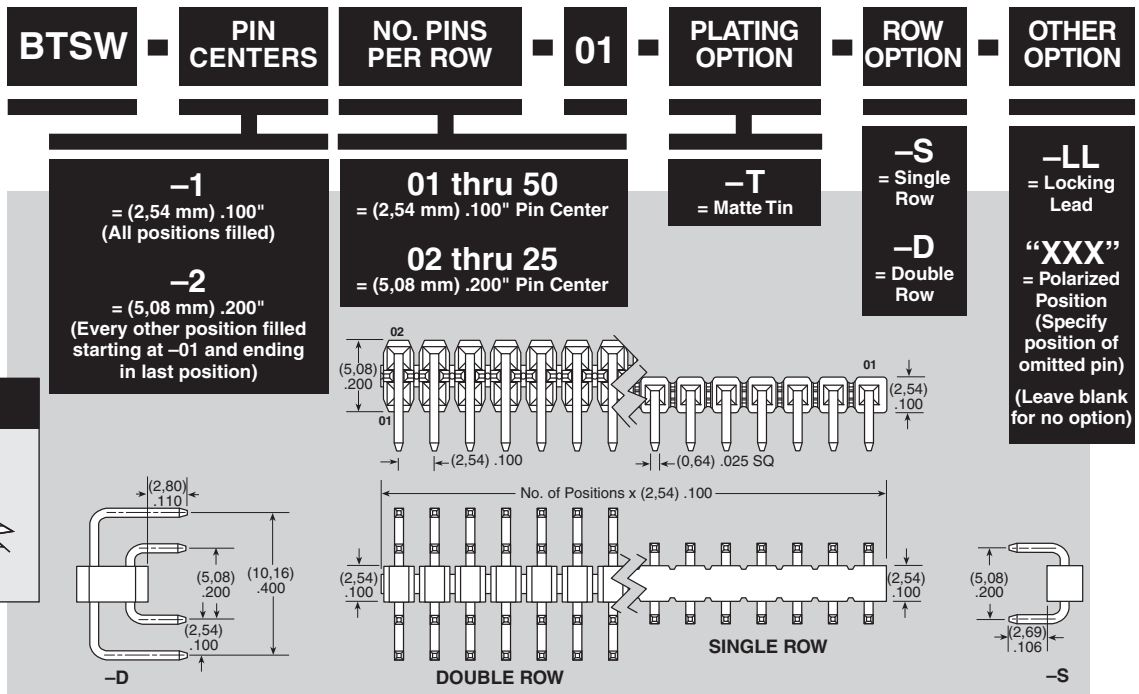

APPLICATION

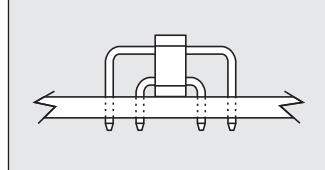

Note: Some sizes, styles and options are non-standard, non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[BTSW-122-01-T-D](#)