


(1.00 mm) .0394" • SINGLE ROW DISCRETE WIRE TERMINAL

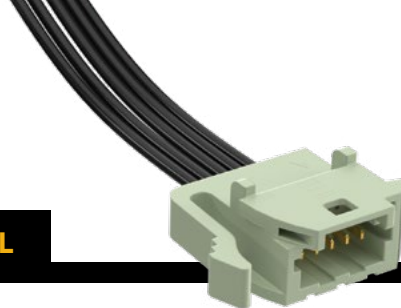

SERIES	NO. OF POSITIONS	WIRE GAUGE	PLATING OPTION	ASSEMBLED LENGTH	PANEL OPTION	PINOUT
T1SS = Single Row Non-Panel Mount PVC Cable T1PS = Single Row Panel Mount PVC Cable T1SST = Single Row Non-Panel Mount Blue *Teflon™ Fluoropolymer Cable T1PST = Double Row Panel Mount Blue *Teflon™ Fluoropolymer Cable T1SS(T), T1PS(T) Cable Mates: S1SS, S1SST	-02 positions not available with T1PS or T1PST) -02 thru -10 (Per Row)	-28 = 28 AWG -28C = 28 AWG Color Coded Cable (T1SS & T1PS only) -30 = 30 AWG -30C = 30 AWG Color Coded Cable (T1SS & T1PS only)	-GF = 3 μ" (0.07 μm) Gold on contact and tail	-"XX.X" = Assembled Length in Inches (45.7 mm) 01.8" min.	(Leave blank for non-panel mount) -A = Fits .033" (0.84 mm), .062" (1.57 mm) and .090" (2.29 mm) Thick Panels	(Leave blank for single ended assembly) -D1 = Double Ended down (Not available with T1PS or T1PST) -D3 = Double Ended up (Not available with T1PS or T1PST) -T1 = Transfer to socket down -T3 = Transfer to socket up

-28C, -30C CABLE COLOR CODING

PIN	COLOR
1	BROWN
2	RED
3	ORANGE
4	YELLOW
5	GREEN
6	BLUE
7	VIOLET
8	GRAY
9	WHITE
10	BLACK
ETC	REPEAT

*Teflon™ is a trademark of The Chemours Company FC, LLC used under license by Samtec.



Note: Teflon™ Fluoropolymer cable is intended for crimp only. Contact Samtec for solderable cable applications.

SPECIFICATIONS


Insulator Material: Nylon, Light Green
Contact Material: Phosphor Bronze
Plating: Au over 50 μ" (1.27 μm) Ni
Operating Temp Range: -10 °C to +80 °C (PVC)
 -40 °C to +125 °C (*Teflon™ Fluoropolymer)
Wire: 28 or 30 AWG

View complete specifications at: samtec.com?T1SS, samtec.com?T1SST, samtec.com?T1PS & samtec.com?T1PST


SERIES	NO. OF POSITIONS	PANEL THICKNESS	SERIES	01	PLATING
IST1 = Single Row Body ISP1 = Single Row Panel Mount Body	-02 thru -10 (IST1 Body) -03 thru -10 (ISP1 Body)	(Leave blank for IST1) -A = Fits 0.84 mm, 1.57 mm & 2.29 mm Thick Panels	TC37R = Contact, Full Reel (25,000 Parts per Reel) TC37M = Contact, Mini Reel (1,000 - 5,000 Parts per Reel)		-GF = 3 μ" (0.07 μm) Gold contact and tail

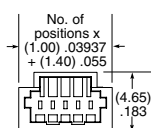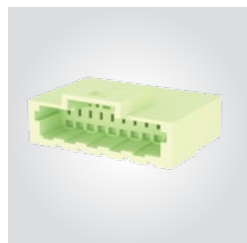

IST1

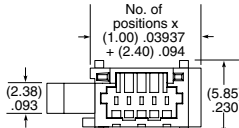

ISP1

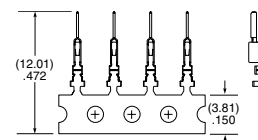

TOOLING

Hand Tool: CAT-HT-1137-2830-12

Mini Applicator: CAT-MC-309-2830-XX-01

Note: Some lengths, styles and options are non-standard, non-returnable.

View complete specifications at: samtec.com?IST1, samtec.com?ISP1, samtec.com?TC37R & samtec.com?TC37M

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[T1PST-03-28-GF-05.0-A](#) [T1PST-03-28-GF-15.00-A](#) [T1PST-05-28-GF-28.00-A-T3](#) [T1PST-05-28-GF-10.00-A-T3](#)
[T1PST-04-28-GF-05.0-A](#) [T1PST-08-28-GF-05.0-A](#) [T1PST-03-28-GF-30.00-A](#) [T1PST-03-28-GF-06.00-A](#) [T1PST-08-](#)
[28-GF-18.00-A-T3](#) [T1PST-05-28-GF-14.00-A-T3](#)