
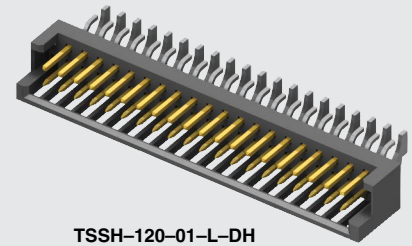


TSSH-115-01-L-D

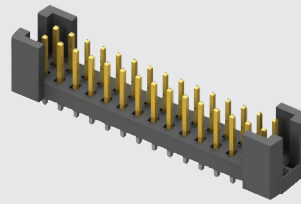

TSSH-120-01-L-DH

TSSH SERIES

(2.54 mm) .100"

SHROUDED .025" SQ POST HEADERS

Board Mates:
SSW, SSQ, SSM

Important Note:
This Series will only mate with SSW, SSQ & SSM Series

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com/TSSH

Insulator Material:

Black Liquid Crystal Polymer

Terminal Material:

Phosphor Bronze

Plating:

Au or Sn over 50 μm (1.27 μm) Ni

Operating Temp Range:

-55 °C to +105 °C with Tin;
-55 °C to +125 °C with Gold

RoHS Compliant:

Yes

PROCESSING

Lead-Free Solderable:

Yes

SMT Lead Coplanarity (-DV):

(0.10 mm) .004" max (05-10)

(0.15 mm) .006" max (15-20)*

(0.20 mm) .008" max (25-36)*

SMT Lead Coplanarity (-DH):

(0.15 mm) .006" max*

*(.004" stencil solution may be available; contact IPG@samtec.com)

RECOGNITIONS

For complete scope of recognitions see www.samtec.com/quality



APPLICATIONS




HORIZONTAL

ALSO AVAILABLE (MOQ Required)

- Other platings

Note:
Some lengths, styles and options are non-standard, non-returnable.

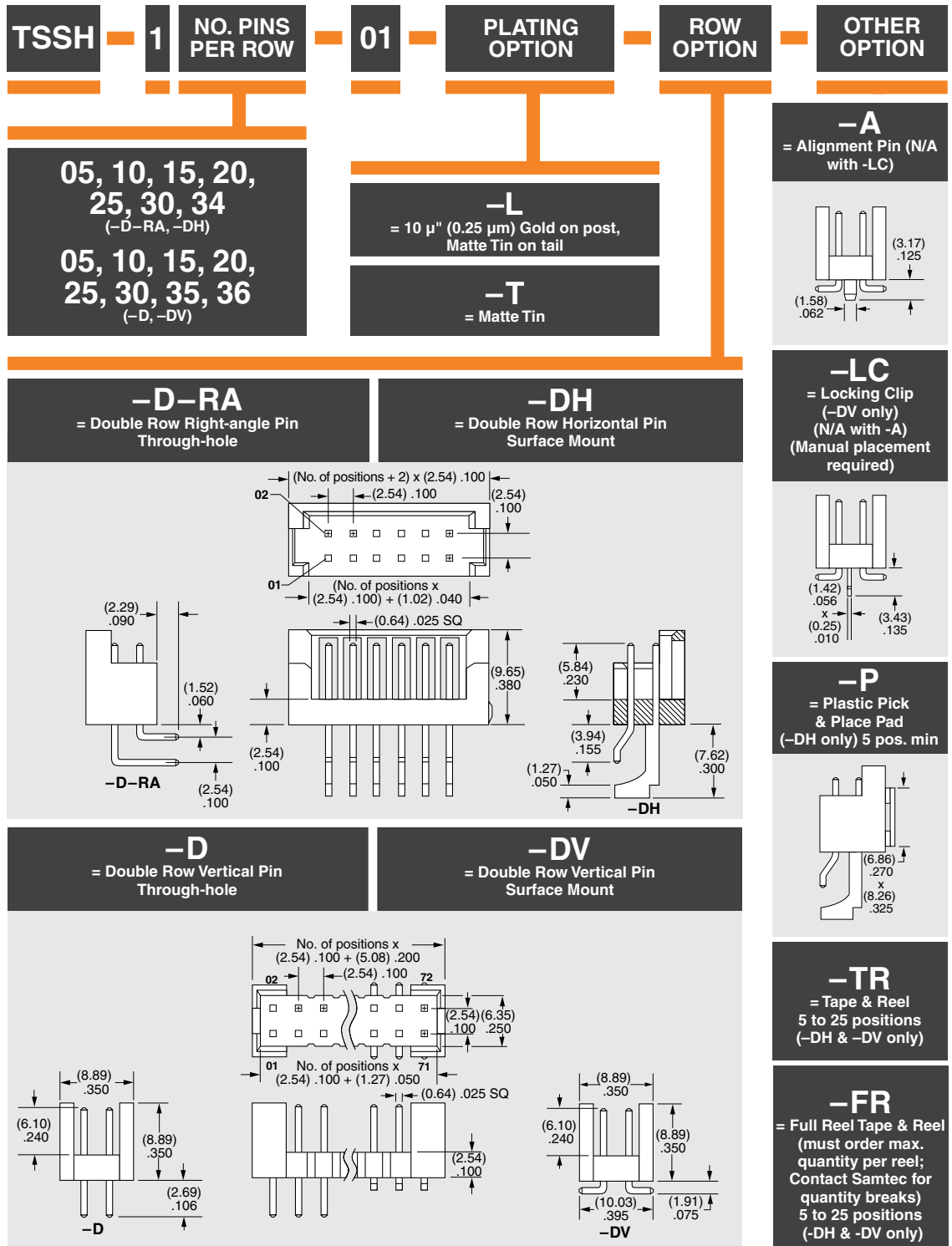

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[TSSH-110-01-L-D](#)