

THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO J.S.T. AND SHALL NOT BE USED OR SHOWN WITHOUT WRITTEN PERMISSION.

Item No.	Part No.	Description
1	SPSM-41T-M1.1	PSI Connector - Male Contact
2	SPSI-41T-M1.1	PSI Connector - Female Contact
3	UL1007, 16 AWG	Black


Electrical Specifications

Current: 12.0A AC/DC

Voltage: 300V AC/DC

APPLICABLE HOUSINGS

NO. OF CIRCUITS	KEYING	FEMALE CONTACT HOUSING PART NO.	MALE CONTACT HOUSING PART NO.	HOUSING COLOR
2	A	PSIP-02V-LE-A	PSIR-02V-LE-A	LIGHT BLUE
	B	PSIP-02V-Y-B	PSIR-02V-Y-B	YELLOW
3	A	PSIP-03V-LE-A	PSIR-03V-LE-A	LIGHT BLUE
	B	PSIP-03V-Y-B	PSIR-03V-Y-B	YELLOW

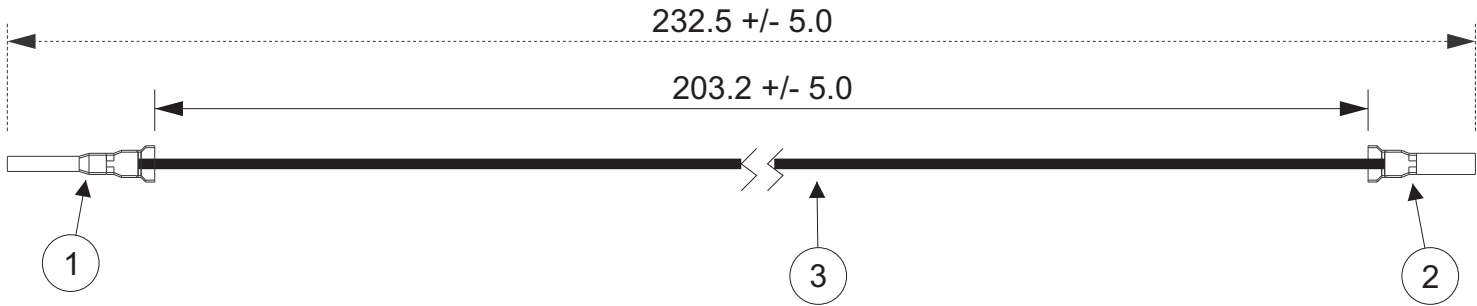

**JST**

All dimensions are in millimeters with a default tolerance of +/- 5.0 unless otherwise specified.

CUSTOMER NAME

DESCRIPTION

4.0mm Pitch PSI Series Standard Leads - 8" Inside Length  
DOUBLE END LEADS, F-M

Drawn By:  
Larissa Mosley  
Checked By:  
Steven Pilkington

SIZE

CUSTOMER PART NO.

PART NO.

REV

SCALE

1:1

DRAWING NO.  
GAM-416

DATE

5/23/2018

ZONE	REV	DESCRIPTION	DATE	APPROVED
1	1	Add Electrical Specifications	7/02/2018	LM

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[JST:](#)

[ASPSISPSM16K203](#)