


THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO J.S.T. AND SHALL NOT BE USED OR SHOWN WITHOUT WRITTEN PERMISSION.

Item No.	Part No.	Description
1	SVM-61T-P2.0	VL Connector Male Contact
2	UL1015, 14 AWG	Black

Electrical Specifications
Current: 20.0A AC/DC
Voltage: 600V AC/DC

APPLICABLE HOUSINGS		
NO. OF CIRCUITS	HOUSING PART NO. WITH PANEL LOCKS	HOUSING PART NO. WITHOUT PANEL LOCKS
1	-	VLR-01VF
2	VLR-02V	VLR-02VF
3	VLR-03V	-
4	VLR-04V	VLR-04VF
4	VLR-04VN	-
6	VLR-06V	-
8	VLR-08V	-
12	VLR-12V	-

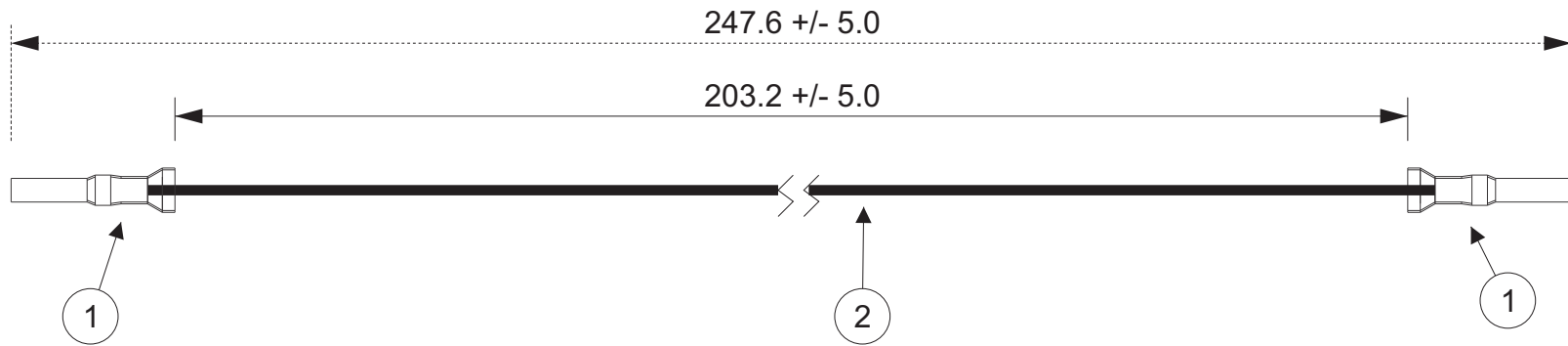

JST

					All dimensions are in millimeters with a default tolerance of +/- 5.0 unless otherwise specified.	CUSTOMER NAME									
						DESCRIPTION 6.2mm Pitch VL Series Standard Leads - 8" Inside Length DOUBLE END LEADS, M-M									
ZONE	REV	DESCRIPTION			DATE	APPROVED			Drawn By: Larissa Mosley	SIZE	CUSTOMER PART NO.		PART NO.	REV	
										Checked By: Steven Pilkington	SCALE	1:1		DRAWING NO. GAM-443	DATE 6/5/2018
1		Add Electrical Specifications			7/03/2018	LM									
1		2		3		4		5		6		7		8	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[JST:](#)

[ASVMSVM14K203](#)