


THIS DRAWING CONTAINS INFORMATION THAT IS PROPRIETARY TO J.S.T. AND SHALL NOT BE USED OR SHOWN WITHOUT WRITTEN PERMISSION.

| | | | |
|----------|-----------------|-----------------------|---|
| 1 | 2 | 3 | 4 |
| Item No. | Part No. | Description | |
| 1 | SGVHSF-002T-0.2 | GVH Connector Contact | |
| 2 | UL1061, 26 AWG | Black | |

| |
|---------------------------|
| Electrical Specifications |
| Current: 1AAC/DC |
| Voltage: 50V AC/DC |

| APPLICABLE HOUSINGS | |
|---------------------|------------------|
| NO. OF CIRCUITS | HOUSING PART NO. |
| 2 | GVHRSF-02V-S |
| 3 | GVHRSF-03V-S |
| 4 | GVHRSF-04V-S |
| 5 | GVHRSF-05V-S |
| 6 | GVHRSF-06V-S |
| 7 | GVHRSF-07V-S |
| 8 | GVHRSF-08V-S |
| 9 | GVHRSF-09V-S |
| 10 | GVHRSF-10V-S |
| 11 | GVHRSF-11V-S |
| 12 | GVHRSF-12V-S |
| 13 | GVHRSF-13V-S |
| 14 | GVHRSF-14V-S |
| 15 | GVHRSF-15V-S |

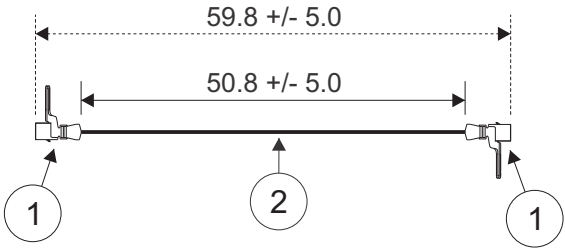

All dimensions are in millimeters with a default tolerance of +/- 5.0 unless otherwise specified.

| | | | |
|---|-------------------|------------------------|-------------------|
| CUSTOMER NAME | | | |
| DESCRIPTION | | | |
| 1.25mm Pitch GVH Series Standard Leads - 2" Inside Length DOUBLE END LEADS, SIDE FEED TYPE | | | |
| SIZE | CUSTOMER PART NO. | PART NO. | REV |
| | | AGVHGVH26K51 | |
| SCALE | 1:1 | DRAWING NO. GAM-699 | DATE 1/25/2019 |

| ZONE | REV | DESCRIPTION | DATE | APPROVED |
|------|-----|-------------|------|----------|
| 1 | | | | |
| 2 | | | | |
| 3 | | | | |
| 4 | | | | |
| 5 | | | | |
| 6 | | | | |
| 7 | | | | |
| 8 | | | | |

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[JST:](#)

[AGVHGVH26K203](#)