


DIN terminals / splices



PIN Non-insulated / Insulated

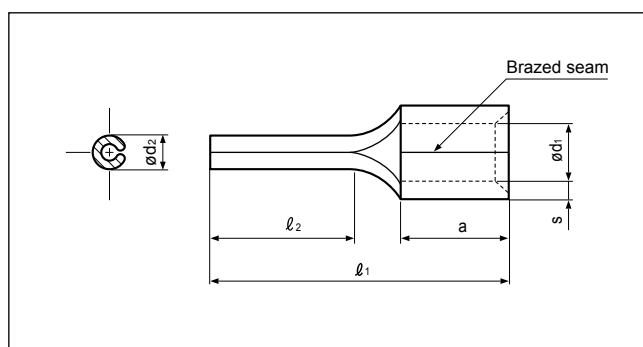


Non-insulated

Applicable Wire mm ²	Part No.	Nominal Size	Dimensions mm (in.)						Tool No.	Qty/box	
			ø d ₂	ℓ ₁	ℓ ₂	a	ø d ₁	s			
0.5 to 1	PC-1.25	1	1.9 (.075)	17.0 (.669)	10.0 (.394)	5.0 (.197)	1.6 (.063)	0.8 (.031)	WC-0510DIN	1,000	
	PC-1.25 F-10			15.0 (.591)	8.0 (.315)						
	PC-1.25 F-7			12.0 (.472)	5.0 (.197)						
>1 to 2.5	PC-2	2.5	1.9 (.075)	17.0 (.669)	10.0 (.394)	5.0 (.197)	2.3 (.091)	0.8 (.031)			1,000
	PC-2 F-17			22.0 (.866)	15.0 (.591)						500
	PC-2 F-7			12.0 (.472)	5.0 (.197)						1,000
>2.5 to 6	PC-5.5	6	2.7 (.106)	20.0 (.787)	10.0 (.394)	6.0 (.236)	3.6 (.142)	1.0 (.039)		500	

Note:1) Contact J.S.T.(U.K.) Ltd for the above tools.

2) Reference: DIN46230 Contact J.S.T. DEUTSCHLAND GMBH for details.

3) Delivery lead times may vary depending on the product. Contact JST for details.

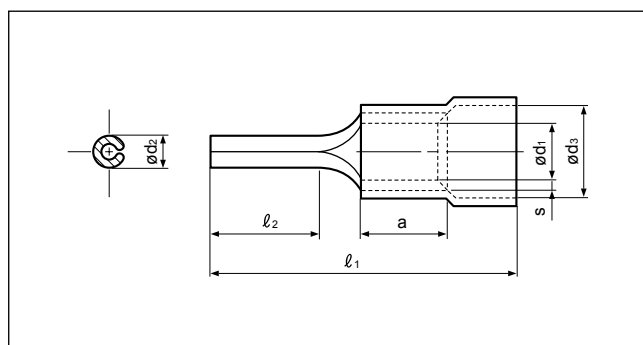

Vinyl-insulated

Applicable Wire mm ²	Part No.	Nominal Size	Dimensions mm (in.)							Color	Tool No.	Qty/box
			ø d2	ℓ ₁	ℓ ₂	a	ø d1	ø d3	s			
0.5 to 1	FVGSPC-1	1	1.9 (.075)	22.0 (.866)	10.0 (.394)	5.0 (.197)	1.6 (.063)	3.4 (.134)	0.8 (.031)	Red	WC-2210DIN	1,000
	FVGSPC-1 F-7			17.0 (.669)	5.0 (.197)							
>1 to 2.5	FVGSPC-2.5	2.5	1.9 (.075)	23.0 (.906)	10.0 (.394)	5.0 (.197)	2.3 (.091)	4.3 (.169)	0.8 (.031)	Blue		1,000
	FVGSPC-2.5 F-17			28.0(1.102)	15.0 (.591)							
>2.5 to 6	FVGSPC-6	6	2.7 (.106)	26.0(1.024)	10.0 (.394)	6.0 (.236)	3.6 (.142)	6.4 (.252)	1.0 (.039)	Yellow	1,000	

Note:1) Contact J.S.T.(U.K.) Ltd for the above tools.

2) Reference: DIN46231 Contact J.S.T. DEUTSCHLAND GMBH for details.

3) Delivery lead times may vary depending on the product. Contact JST for details.

Nylon-insulated

Applicable Wire mm ²	Part No.	Nominal Size	Dimensions mm (in.)							Color	Tool No.	Qty/box
			ø d2	ℓ ₁	ℓ ₂	a	ø d1	ø d3	s			
0.1 to <0.5	FNGSPC-0.5		1.2 (.047)	18.0 (.709)	8.0 (.315)	4.0 (.157)	1.0 (.039)	2.2 (.087)	0.6 (.024)	Yellow	—	2,000
0.5 to 1	FNGSPC-1	1	1.9 (.075)	22.0 (.866)	10.0 (.394)	5.0 (.197)	1.6 (.063)	3.4 (.134)	0.8 (.031)	Red		1,000
	FNGSPC-1 F-10			20.0 (.787)	8.0 (.315)							
>1 to 2.5	FNGSPC-2.5	2.5	1.9 (.075)	23.0 (.906)	10.0 (.394)	5.0 (.197)	2.3 (.091)	4.3 (.169)	0.8 (.031)	Blue		1,000
	FNGSPC-2.5 F-17			28.0(1.102)	15.0 (.591)							
>2.5 to 6	FNGSPC-6	6	2.7 (.106)	26.0(1.024)	10.0 (.394)	6.0 (.236)	3.6 (.142)	6.4 (.252)	1.0 (.039)	Yellow	1,000	

Note:1) Contact J.S.T.(U.K.) Ltd for the above tools.

2) Reference: DIN46231 Contact J.S.T. DEUTSCHLAND GMBH for details.

3) Delivery lead times may vary depending on the product. Contact JST for details.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[JST:](#)

[PC-1.25](#) [PC-2](#) [PC-5.5](#) [PC-2F-7](#)