


SDHK CONNECTOR



1.1 mm pitch/ Micro SD card Flip cover type

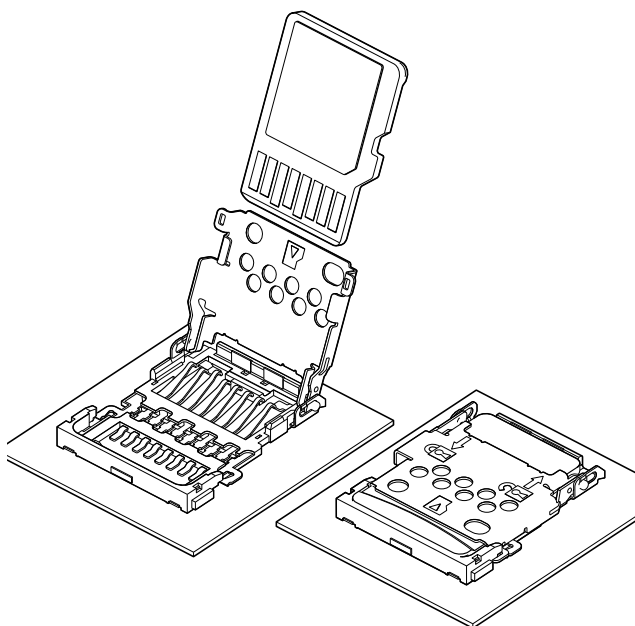


This is micro SD card connector of flip cover type that can approach from above the PC board surface.


Specifications

- Current rating: 0.5 A AC/DC
 - Voltage rating: 15 V AC/DC
 - Temperature range: -25°C to +85°C
(including temperature rise in applying electrical current)
 - Contact resistance: Initial value/ 80 mΩ max.
After environmental tests/ 160 mΩ max.
 - Insulation resistance: 100 MΩ min.
 - Withstanding voltage: 500 VAC/minute
 - Applicable card: Micro SD card
- * In using the products, refer to "Handling Precaution for Terminal and Connector" described on our website (Technical documents of Product information page).
- * Contact JST for details.
- * RoHS2 compliance

Connector

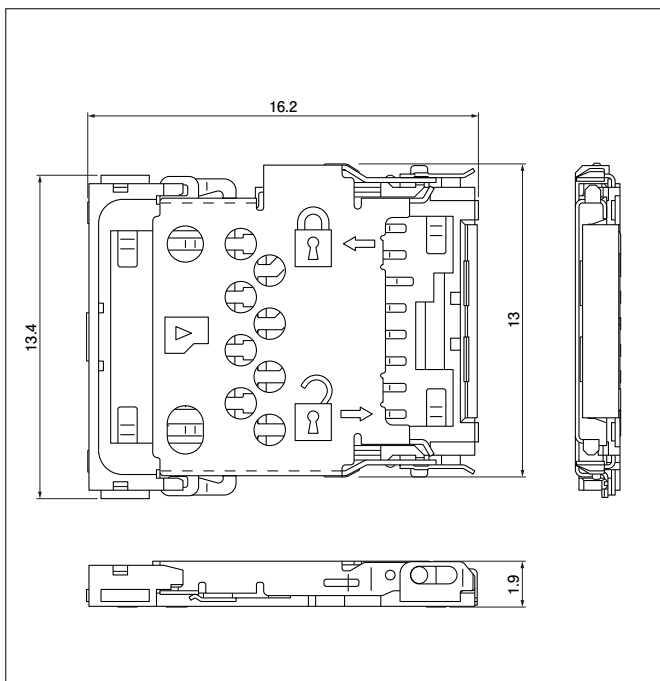

PC board layout

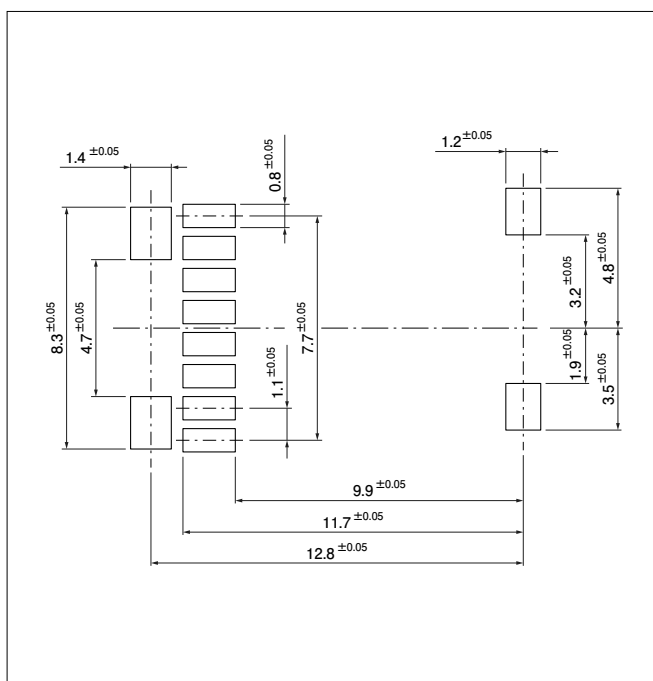

Model No.	Q'ty/reel
SDHK-8BNS-K-303-TB(HF)	1,400

Material and Finish

Contact: Copper alloy, nickel-undercoated, gold-plated
Housing: Heat resisting resin, black
Cover: Stainless

RoHS2 compliance

The product listed above are supplied on embossed-tape.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[JST:](#)

[SDHK-8BNS-K-303-TB\(HF\)](#)