

H6,0/12**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



- For conductors from 0.25 to 6,0 mm² (AWG 24 - 10)
tin-plated copper
dimensional tolerances to DIN 46228 part 1
- supplied loose in polybag

General ordering data

Version	Wire-end ferrule, Standard, 12 mm, 12 mm, No
Order No.	0191900000
Type	H6,0/12
GTIN (EAN)	4008 19002685 1
Qty.	500 pc(s).
Packaging	loose

Creation date January 11, 2022 4:50:44 PM CET

Catalogue status 17.12.2021 / We reserve the right to make technical changes.

H6,0/12

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight 0.21 g

Technical data

Description of article	Wire end ferrule without plastic collar	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Collar diameter (D2)	4.7 mm	Conductor cross-section	6 mm ²
Contact surface diameter (D1)	3.5 mm	Contact surface length (L2)	12 mm
L1 in mm	12 mm	Stripping length	12 mm
Wire connection cross section AWG, max.	AWG 10		

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01		

Approvals

Approvals



ROHS	Conform
UL File Number Search	E499744

Downloads

Engineering Data	CAD data – STEP
Engineering Data	EPLAN, WSCAD, Zuken E3.S
Catalogues	Catalogues in PDF-format
Brochures	


Data sheet

H6,0/12

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

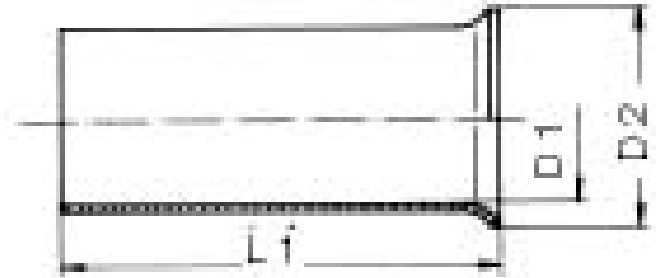

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[0191900000](#)