

## IE-PI-SCRJ-POF

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)



FO SC inserts for plug-in connectors ver.1 / 4 / 14

### General ordering data

Version	SC insert, Plug SCRJ, POF
Order No.	<a href="#">1067410000</a>
Type	IE-PI-SCRJ-POF
GTIN (EAN)	4032248820870
Qty.	10 pc(s).

Creation date September 15, 2022 11:10:36 PM CEST

Catalogue status 09.09.2022 / We reserve the right to make technical changes.

## IE-PI-SCRJ-POF

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	56 mm	Depth (inches)	2.205 inch
Height	10.5 mm	Height (inches)	0.413 inch
Width	13.2 mm	Width (inches)	0.52 inch
Net weight	18.7 g		

## Temperatures

Operating temperature	-40 °C...70 °C
-----------------------	----------------

## Environmental Product Compliance

REACH SVHC	SCIP	67cf1078-beca-4687-860b-dc475a6ec24a
	Lead 7439-92-1	

## General data

Colour	Miscellaneous	Configuration	Connector and flange insert for variant 1, 4 and 14 housings
Connection 1	SCRJ	Connection 2	Crimp
Description of article	Plug SCRJ, POF	Ferrule material	Arcap
Fibre type	POF	Housing main material	Zinc diecast, PA
Insertion loss	≤ 1.0 dB	Plugging cycles	1000
Protection degree	IP67 with housing		

## General standards

Certificate No. (UL)	E477798	Connector standard	IEC 61754-24
----------------------	---------	--------------------	--------------

## Classifications

ETIM 6.0	EC001122	ETIM 7.0	EC001122
ETIM 8.0	EC001122	ECLASS 9.0	19-17-01-22
ECLASS 9.1	19-17-01-22	ECLASS 10.0	19-17-01-22
ECLASS 11.0	19-17-01-22	ECLASS 12.0	19-17-01-22

## Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (UL)	E477798

**IE-PI-SCRJ-POF****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Downloads**

---

Approval/Certificate/Document of Conformity	<a href="#">PROFINET Manufacturer's Declaration</a>
Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Designation key / Type key</a> <a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>

---

**Data sheet**


**IE-PI-SCRJ-POF**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

**Dimensioned drawing**

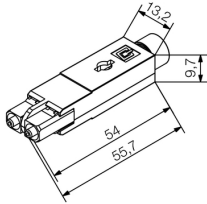

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1067410000](#)