

**SAIE-7/8S-5-0.2-PG11****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Similar to illustration**

Various build-in connectors are required for the connections on the device side of the sensor/actuator cabling. These are available in the versions M12, M8 and M5.

**General ordering data**

Version	Built-in plugs, 7/8", PG 11, Number of poles: 5, 0.2 m
Order No.	<a href="#">1292470000</a>
Type	SAIE-7/8S-5-0.2-PG11
GTIN (EAN)	4050118088526
Qty.	1 pc(s).

Creation date January 22, 2022 11:21:36 AM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

## SAIE-7/8S-5-0.2-PG11

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Dimensions and weights

Net weight 47 g

### Environmental Product Compliance

REACH SVHC Lead 7439-92-1

### Technical data customisable plug-in connectors

Cable glands	PG 11	Coding	none
Contact surface	Gold-plated	Housing main material	Zinc diecast, nickel-plated
Number of poles	5	Plugging cycles	≥ 100
Protection degree	IP67, when screwed in	Rated current	8 A
Rated current	8 A (4- and 5-pole), 10 A (3-pole)	Rated voltage	300 V
Temperature range of housing	-25...+85 °C	Type of connection	Pin

### General data

Cable glands	PG 11
Cable length	0.2 m
Coding	none
Conductor O.D.	-
Connection thread	7/8"
Contact material	CuZn
Contact surface	Gold-plated
Core cross-section	0.75 mm <sup>2</sup>
Housing main material	Zinc diecast, nickel-plated
Material	PUR/ PUR
Mounting thread	PG 11
Mounting torque	min. 6 Nm max. 6.25 Nm
Mounting torque range	6 ... 6.25 Nm
Number of poles	5
Plugging cycles	≥ 100
Protection degree	IP67, when screwed in
Rated current	8 A
Rated current	8 A (4- and 5-pole), 10 A (3-pole)
Rated voltage	300 V
Strand / cable length	0.2 m
Temperature range of housing	-25...+85 °C
Tightening torque	1.5 Nm
Type of connection	Pin

### Classifications

ETIM 6.0	EC002635	ETIM 7.0	EC003570
ETIM 8.0	EC003570	ECLASS 9.0	27-44-01-03
ECLASS 9.1	27-44-01-03	ECLASS 10.0	27-44-01-03
ECLASS 11.0	27-44-01-03		

**Data sheet****SAIE-7/8S-5-0.2-PG11****Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

**Technical data****Approvals**

Approvals



ROHS	Conform
UL File Number Search	E307231

**Downloads**

Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a> <a href="#">FL FIELDWIRING EN</a>

**Data sheet**



**SAIE-7/8S-5-0.2-PG11**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany


www.weidmueller.com

**Drawings**

**Wiring diagram**

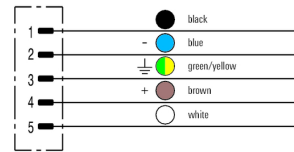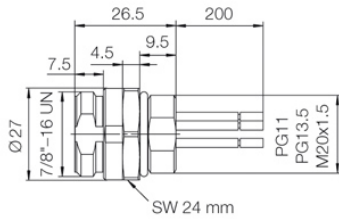

**Pole scheme**

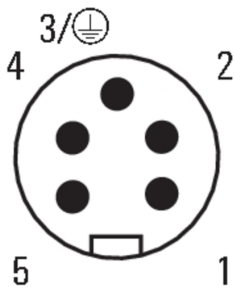

**SAIE-7/8S-5-0.2-PG11**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Accessories****Brass lock nuts, nickel-plated**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

**General ordering data**

Type	SKMU PG11-MS	Version
Order No.	<a href="#">1694090000</a>	SKMU MS (brass locknut), Locknut, PG 11, 3 mm, Brass, nickel-plated
GTIN (EAN)	4008190872250	
Qty.	100 pc(s).	

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1292470000](#)