

SAIE-M12S-5-0.2U P9 .75**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



Your peripheral devices should be supplied with greater power. With our new M12 plug-in connector, more than 250 V and 2 A is possible without problems. The compact S- and T-coded M12 plug-in connectors are designed for the transmission of up to 630 V AC or 60 V DC and 12 A.

General ordering data

Version	Built-in plugs, M12, pin, straight, PG 9, Number of poles: 5, 0.2 m, Front mounting
Order No.	1353790000
Type	SAIE-M12S-5-0.2U P9 .75
GTIN (EAN)	4050118156522
Qty.	1 pc(s).

Creation date January 23, 2022 5:35:29 PM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

SAIE-M12S-5-0.2U P9 .75

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight 23 g

Environmental Product Compliance

REACH SVHC Lead 7439-92-1

Technical data customisable plug-in connectors

Cable glands	PG 9	Coding	A
Contact surface	Gold-plated	Housing main material	Brass, nickel-plated
Number of poles	5	Plugging cycles	≥ 100
Protection degree	IP67, when screwed in	Rated current	Contacts 1-4 8A, contact 5 2A
Rated voltage	60 V	Rated voltage	250 V (4-pole) / 60 V (5-pole)
Temperature range of housing	-40 ... +85 °C		

Standards

Connector standard IEC 61076-2-101

General data

Cable glands	PG 9	Cable length	0.2 m
Coding	A	Conductor O.D.	-
Connection thread	M12	Contact surface	Gold-plated
Housing main material	Brass, nickel-plated	Mounting thread	PG 9
Number of poles	5	Plugging cycles	≥ 100
Protection degree	IP67, when screwed in	Rated current	Contacts 1-4 8A, contact 5 2A
Rated voltage	60 V	Rated voltage	250 V (4-pole) / 60 V (5-pole)
Strand / cable length	0.2 m	Temperature range of housing	-40 ... +85 °C
Type of mounting	Front mounting	Wire cross section (Print/Online)	AWG 18

Classifications

ETIM 6.0	EC002635	ETIM 7.0	EC003570
ETIM 8.0	EC003570	ECLASS 9.0	27-44-01-03
ECLASS 9.1	27-44-01-03	ECLASS 10.0	27-44-01-03
ECLASS 11.0	27-44-01-03		

Approvals

Approvals



ROHS

Conform

Data sheet**SAIE-M12S-5-0.2U P9 .75****Weidmüller Interface GmbH & Co. KG**
Klingenbergstraße 26
D-32758 Detmold
Germanywww.weidmueller.com**Technical data****Downloads**


Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN FL FIELDWIRING EN

SAIE-M12S-5-0.2U P9 .75

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Pole scheme

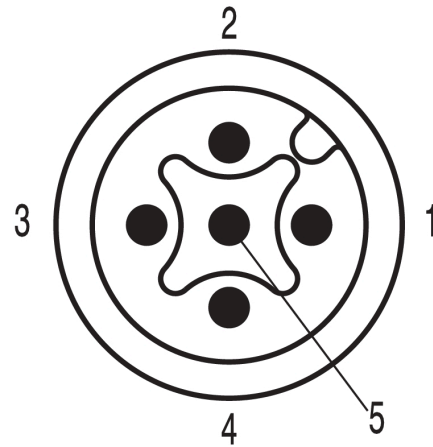

SAIE-M12S-5-0.2U P9 .75

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories**Brass lock nuts, nickel-plated**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	SKMU PG9-MS	Version
Order No.	1694080000	SKMU MS (brass locknut), Locknut, PG 9, 2.8 mm, Brass, nickel-plated
GTIN (EAN)	4008190872243	
Qty.	100 pc(s).	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1353790000](#)