

**HSS-HF 1.6-3.2 EL W13M****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

**General ordering data**

Version	Conductor and cable markers, 1.6 - 3.2 mm, white
Order No.	<a href="#">1423340000</a>
Type	HSS-HF 1.6-3.2 EL W13M
GTIN (EAN)	4050118227581
Qty.	1 pc(s).
compatible printer	<a href="#">2599430000</a> <a href="#">2599440000</a> <a href="#">1140490000</a>

Creation date January 23, 2022 11:17:28 PM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

## HSS-HF 1.6-3.2 EL W13M

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	0.7 mm	Depth (inches)	0.028 inch
Width	5.6 mm	Width (inches)	0.22 inch
Length	13,000 mm	Length (inches)	511.81 inch
Net weight	110 g		

## Temperatures

Operating temperature range	-55...105 °C
-----------------------------	--------------

## General data

Colour	white	Halogen	No
Length	13,000 mm	Material	Polyolefine
Number per roll	1	Operating temperature range	-55...105 °C
Operating temperature range, max.	105 °C	Operating temperature range, min.	-55 °C
Printed characters	without	Type of printing	neutral
Width	5.6 mm		

## Conductor and cable markers

Conductor O.D.	1.6 - 3.2 mm	Conductor O.D., max.	3.2 mm
Conductor O.D., min.	1.6 mm	Conductor cross-section, max.	1.5 mm <sup>2</sup>
Conductor cross-section, min.	0.5 mm <sup>2</sup>	Cross-section for connected wire	0.5 - 1.5 mm <sup>2</sup>
Halogen	No	Rate of shrinkage	2:1
Recommended shrinking temperature	90 °C	Text field height	5.4 mm
Text field width	0 mm		

## Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ECLASS 9.0	27-40-04-01
ECLASS 9.1	27-40-04-01	ECLASS 10.0	27-40-04-01
ECLASS 11.0	27-28-11-02		

## Approvals

ROHS	Conform
------	---------

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">NFX 70-100-1 2006 + NF X 70-100-2 2006</a> <a href="#">BS EN 45545-2 2013+A1 2015</a> <a href="#">BS EN ISO 4589-2 1999</a>
Engineering Data	<a href="#">EPLAN, WSCAD</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>

**Data sheet**

**HSS-HF 1.6-3.2 EL W13M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**




**HSS-HF 1.6-3.2 EL W13M**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**THM MULTIMARK**

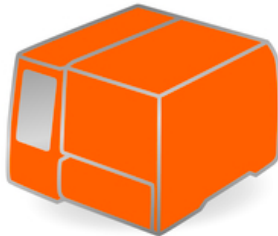

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type THM MMP ROLLER 25  
 Order No. [1357430000](#)  
 GTIN (EAN) 4050118160253  
 Qty. 1 pc(s).

Type THM MMP ROLLER 115  
 Order No. [1357420000](#)  
 GTIN (EAN) 4050118160314  
 Qty. 1 pc(s).

**Ink ribbons**



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.


**General ordering data**

Type	RIBBON HSS HF EL 40/300	Version	
Order No.	<a href="#">1426210000</a>	Ink ribbon	
GTIN (EAN)	4050118228823		
Qty.	1 pc(s).		

**HSS-HF 1.6-3.2 EL W13M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

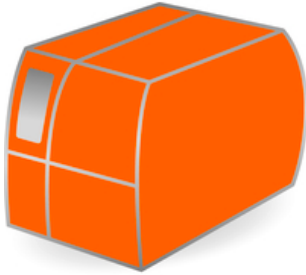**Accessories****THM MULTIMARK PLUS**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	MM PLUS ROLLER 110
Order No.	<a href="#">2672590000</a>
GTIN (EAN)	4050118708097
Qty.	1 pc(s).

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1423340000](#)