

HSS-HF 2.4-4.8 EL W13M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

General ordering data

| | |
|--------------------|--|
| Version | Conductor and cable markers, 2.4 - 4.8 mm, white |
| Order No. | 1423350000 |
| Type | HSS-HF 2.4-4.8 EL W13M |
| GTIN (EAN) | 4050118227741 |
| Qty. | 1 pc(s). |
| compatible printer | 2599430000 2599440000 1140490000 |

Creation date January 23, 2022 11:18:10 PM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

HSS-HF 2.4-4.8 EL W13M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

| | | | |
|------------|-----------|-----------------|-------------|
| Depth | 0.9 mm | Depth (inches) | 0.035 inch |
| Width | 7.6 mm | Width (inches) | 0.299 inch |
| Length | 13,000 mm | Length (inches) | 511.81 inch |
| Net weight | 138 g | | |

Temperatures

| | |
|-----------------------------|--------------|
| Operating temperature range | -55...105 °C |
|-----------------------------|--------------|

General data

| | | | |
|-----------------------------------|-----------|-----------------------------------|--------------|
| Colour | white | Halogen | No |
| Length | 13,000 mm | Material | Polyolefine |
| Number per roll | 1 | Operating temperature range | -55...105 °C |
| Operating temperature range, max. | 105 °C | Operating temperature range, min. | -55 °C |
| Printed characters | without | Type of printing | neutral |
| Width | 7.6 mm | | |

Conductor and cable markers

| | | | |
|-----------------------------------|----------------------|----------------------------------|--------------------------|
| Conductor O.D. | 2.4 - 4.8 mm | Conductor O.D., max. | 4.8 mm |
| Conductor O.D., min. | 2.4 mm | Conductor cross-section, max. | 4 mm ² |
| Conductor cross-section, min. | 0.75 mm ² | Cross-section for connected wire | 0.75 - 4 mm ² |
| Halogen | No | Rate of shrinkage | 2:1 |
| Recommended shrinking temperature | 90 °C | Text field height | 7.4 mm |
| Text field width | 0 mm | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC001530 | ETIM 7.0 | EC001530 |
| ETIM 8.0 | EC001530 | ECLASS 9.0 | 27-40-04-01 |
| ECLASS 9.1 | 27-40-04-01 | ECLASS 10.0 | 27-40-04-01 |
| ECLASS 11.0 | 27-28-11-02 | | |

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads

| | |
|---|---|
| Approval/Certificate/Document of Conformity | NFX 70-100-1 2006 + NF X 70-100-2 2006 BS EN 45545-2 2013+A1 2015 BS EN ISO 4589-2 1999 |
| Engineering Data | CAD data – STEP |
| Engineering Data | EPLAN, WSCAD, Zuken E3.S |
| Catalogues | Catalogues in PDF-format |

Data sheet

HSS-HF 2.4-4.8 EL W13M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings




HSS-HF 2.4-4.8 EL W13M

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

THM MULTIMARK

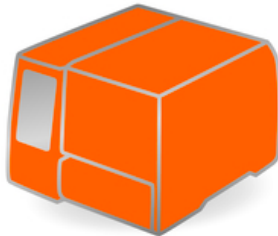

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type THM MMP ROLLER 25
 Order No. [1357430000](#)
 GTIN (EAN) 4050118160253
 Qty. 1 pc(s).

Type THM MMP ROLLER 115
 Order No. [1357420000](#)
 GTIN (EAN) 4050118160314
 Qty. 1 pc(s).

Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.


General ordering data

| | | | |
|------------|----------------------------|------------|--|
| Type | RIBBON HSS HF EL 40/300 | Version | |
| Order No. | 1426210000 | Ink ribbon | |
| GTIN (EAN) | 4050118228823 | | |
| Qty. | 1 pc(s). | | |

HSS-HF 2.4-4.8 EL W13M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

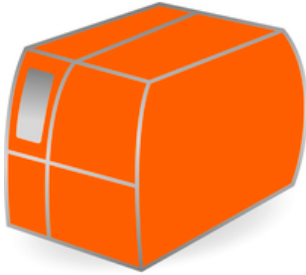Accessories**THM MULTIMARK PLUS**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | |
|------------|----------------------------|
| Type | MM PLUS ROLLER 110 |
| Order No. | 2672590000 |
| GTIN (EAN) | 4050118708097 |
| Qty. | 1 pc(s). |

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1423350000](#)