

HSS 0.8-2.4 EL Y13M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

General ordering data

Version	Conductor and cable markers, 0.8 - 2.4 mm, yellow
Order No.	1489530000
Type	HSS 0.8-2.4 EL Y13M
GTIN (EAN)	4050118299298
Qty.	1 pc(s).
compatible printer	2599430000 2599440000 1140490000

Creation date January 26, 2022 3:59:52 AM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

HSS 0.8-2.4 EL Y13M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Depth	0.77 mm	Depth (inches)	0.03 inch
Width	4.2 mm	Width (inches)	0.165 inch
Length	13,000 mm	Length (inches)	511.81 inch
Net weight	75 g		

Temperatures

Operating temperature range	-55...135 °C
-----------------------------	--------------

General data

Colour	yellow	Halogen	Yes
Length	13,000 mm	Material	Polyolefine
Operating temperature range	-55...135 °C	Operating temperature range, max.	135 °C
Operating temperature range, min.	-55 °C	Printed characters	without
Recommended industries	Plant manufacture, Energy, Device manufacturer, Machinery	Type of printing	neutral
Width	4.2 mm		

Conductor and cable markers

Conductor O.D.	0.8 - 2.4 mm	Conductor O.D., max.	2.4 mm
Conductor O.D., min.	0.8 mm	Conductor cross-section, max.	0.5 mm ²
Conductor cross-section, min.	0.25 mm ²	Cross-section for connected wire	0.25 - 0.5 mm ²
Halogen	Yes	Rate of shrinkage	3:1
Recommended shrinking temperature	90 °C	Text field height	4 mm
Text field width	0 mm		

Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ECLASS 9.0	27-40-04-01
ECLASS 9.1	27-40-04-01	ECLASS 10.0	27-40-04-01
ECLASS 11.0	27-28-11-02		

Approvals

Approvals



ROHS	Conform
UL File Number Search	E366310

Downloads

Engineering Data	EPLAN, WSCAD
Catalogues	Catalogues in PDF-format

Data sheet

HSS 0.8-2.4 EL Y13M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings



Data sheet


HSS 0.8-2.4 EL Y13M

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

THM MULTIMARK

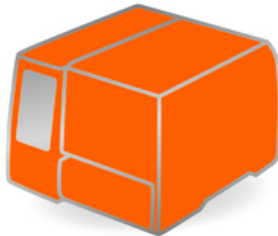

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type THM MMP ROLLER 25
 Order No. [1357430000](#)
 GTIN (EAN) 4050118160253
 Qty. 1 pc(s).

Type THM MMP ROLLER 115
 Order No. [1357420000](#)
 GTIN (EAN) 4050118160314
 Qty. 1 pc(s).

Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON HSS HF EL 40/300	Version	
Order No.	1426210000	Ink ribbon	
GTIN (EAN)	4050118228823		
Qty.	1 pc(s).		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1489530000](#)