

HSS 0.8-2.4 EL W13M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

General ordering data

Version	Conductor and cable markers, 0.8 - 2.4 mm, white
Order No.	1489620000
Type	HSS 0.8-2.4 EL W13M
GTIN (EAN)	4050118299427
Qty.	1 pc(s).
compatible printer	2599430000 2599440000 1140490000

Creation date January 26, 2022 4:26:06 AM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

HSS 0.8-2.4 EL W13M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	0.77 mm	Depth (inches)	0.03 inch
Width	4.2 mm	Width (inches)	0.165 inch
Length	13,000 mm	Length (inches)	511.81 inch
Net weight	73 g		

Temperatures

Operating temperature range	-55...135 °C
-----------------------------	--------------

General data

Colour	white	Halogen	Yes
Length	13,000 mm	Material	Polyolefine
Operating temperature range	-55...135 °C	Operating temperature range, max.	135 °C
Operating temperature range, min.	-55 °C	Printed characters	without
Recommended industries	Plant manufacture, Energy, Device manufacturer, Machinery	Type of printing	neutral
Width	4.2 mm		

Conductor and cable markers

Conductor O.D.	0.8 - 2.4 mm	Conductor O.D., max.	2.4 mm
Conductor O.D., min.	0.8 mm	Conductor cross-section, max.	0.5 mm ²
Conductor cross-section, min.	0.25 mm ²	Cross-section for connected wire	0.25 - 0.5 mm ²
Halogen	Yes	Rate of shrinkage	3:1
Recommended shrinking temperature	90 °C	Text field height	4 mm
Text field width	0 mm		

Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ECLASS 9.0	27-40-04-01
ECLASS 9.1	27-40-04-01	ECLASS 10.0	27-40-04-01
ECLASS 11.0	27-28-11-02		

Approvals

Approvals



ROHS	Conform
UL File Number Search	E366310

Downloads

Engineering Data	EPLAN, WSCAD
Catalogues	Catalogues in PDF-format

Data sheet

HSS 0.8-2.4 EL W13M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings




HSS 0.8-2.4 EL W13M

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

THM MULTIMARK

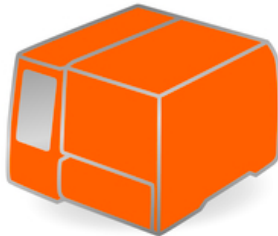

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type THM MMP ROLLER 25
 Order No. [1357430000](#)
 GTIN (EAN) 4050118160253
 Qty. 1 pc(s).

Type THM MMP ROLLER 115
 Order No. [1357420000](#)
 GTIN (EAN) 4050118160314
 Qty. 1 pc(s).

Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON HSS HF EL 40/300	Version	
Order No.	1426210000	Ink ribbon	
GTIN (EAN)	4050118228823		
Qty.	1 pc(s).		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1489620000](#)