

HSS 1.6-4.8 EL W13M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

General ordering data

Version	Conductor and cable markers, 1.6 - 4.8 mm, white
Order No.	1489640000
Type	HSS 1.6-4.8 EL W13M
GTIN (EAN)	4050118299441
Qty.	1 pc(s).
compatible printer	2599430000 2599440000 1140490000

Creation date January 26, 2022 4:20:04 AM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

HSS 1.6-4.8 EL W13M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Depth	0.77 mm	Depth (inches)	0.03 inch
Width	7.6 mm	Width (inches)	0.299 inch
Length	13,000 mm	Length (inches)	511.81 inch
Net weight	106 g		

Temperatures

Operating temperature range	-55...135 °C
-----------------------------	--------------

General data

Colour	white	Halogen	Yes
Length	13,000 mm	Material	Polyolefine
Operating temperature range	-55...135 °C	Operating temperature range, max.	135 °C
Operating temperature range, min.	-55 °C	Printed characters	without
Recommended industries	Plant manufacture, Energy, Device manufacturer, Machinery	Type of printing	neutral
Width	7.6 mm		

Conductor and cable markers

Conductor O.D.	1.6 - 4.8 mm	Conductor O.D., max.	4.8 mm
Conductor O.D., min.	1.6 mm	Conductor cross-section, max.	4 mm ²
Conductor cross-section, min.	0.75 mm ²	Cross-section for connected wire	0.75 - 4 mm ²
Halogen	Yes	Rate of shrinkage	3:1
Recommended shrinking temperature	90 °C	Text field height	7.4 mm
Text field width	0 mm		

Classifications

ETIM 6.0	EC001530	ETIM 7.0	EC001530
ETIM 8.0	EC001530	ECLASS 9.0	27-40-04-01
ECLASS 9.1	27-40-04-01	ECLASS 10.0	27-40-04-01
ECLASS 11.0	27-28-11-02		

Approvals

Approvals



ROHS	Conform
UL File Number Search	E366310

Downloads

Engineering Data	EPLAN, WSCAD
Catalogues	Catalogues in PDF-format

Data sheet

HSS 1.6-4.8 EL W13M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings




HSS 1.6-4.8 EL W13M

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

THM MULTIMARK

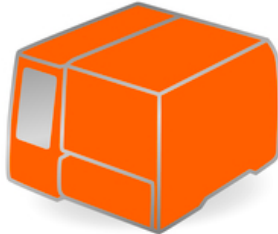

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type THM MMP ROLLER 25
 Order No. [1357430000](#)
 GTIN (EAN) 4050118160253
 Qty. 1 pc(s).

Type THM MMP ROLLER 115
 Order No. [1357420000](#)
 GTIN (EAN) 4050118160314
 Qty. 1 pc(s).

Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON HSS HF EL 40/300	Version	
Order No.	1426210000	Ink ribbon	
GTIN (EAN)	4050118228823		
Qty.	1 pc(s).		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1489640000](#)