

KQIG-M5/-6**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Insulated forked-cable connector made from PVC or PC/PA**

- Conventional designs
- Not soldered
- With conical entry funnel

General ordering data

Version	cable lug, terminal end, Insulated cable connector, 6 mm ² , 4 mm ² - 6 mm ²
Order No.	1491280000
Type	KQIG-M5/-6
GTIN (EAN)	4050118301311
Qty.	100 pc(s).

Creation date September 16, 2022 6:15:40 AM CEST

Catalogue status 09.09.2022 / We reserve the right to make technical changes.

KQIG-M5/-6**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight	1.8 g
------------	-------

Connectors

Conductor cross-section	6 mm ²	Conductor cross-section, max.	6 mm ²
Conductor cross-section, min.	4 mm ²	Connection length (l)	22 mm
Hole	C 5	Identification colour	yellow
Inside diameter of collar (d4)	6.4 mm	Inside diameter of flange (d2)	5.3 mm
Inside diameter of shaft (d1)	3.6 mm	Insulation	Available
Material/plastic	PC	Outside diameter of shaft (d3)	10 mm

Classifications

ETIM 6.0	EC001059	ETIM 7.0	EC001059
ETIM 8.0	EC001059	ECLASS 9.0	27-40-02-92
ECLASS 9.1	27-40-02-12	ECLASS 10.0	27-40-02-92
ECLASS 11.0	27-40-02-92	ECLASS 12.0	27-40-02-92

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	EPLAN
Catalogues	Catalogues in PDF-format
Brochures	


Data sheet

KQIG-M5/-6

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

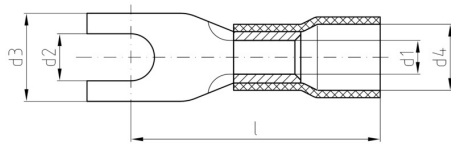

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1491280000](#)