

SKMU PG7-K GR**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Version	SKMU PA (plastic locknut), Locknut, PG 7, 5 mm, Polyamid 6 (PA6 - GF30)
Order No.	1697440000
Type	SKMU PG7-K GR
GTIN (EAN)	4008 190880552
Qty.	100 pc(s).

Creation date January 27, 2022 6:30:16 AM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

SKMU PG7-K GR

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	1.1 g
------------	-------

Temperatures

Operating temperature	-40 °C... 100 °C
-----------------------	------------------

General information

AF size 1	19 mm	Cable glands	PG
External thread	PG 7	Halogen	No
Internal thread	PG 7	Length of thread	5 mm
Material	Polyamid 6 (PA6 - GF30)	O.D.	21.95 mm
Operating temperature range, max.	100 °C	Operating temperature range, min.	-40 °C
Thickness	5 mm	UL 94 flammability rating	HB

Classifications

ETIM 6.0	EC000940	ETIM 7.0	EC000940
ETIM 8.0	EC000940	ECLASS 9.0	27-14-44-24
ECLASS 9.1	27-14-44-24	ECLASS 10.0	27-14-44-24
ECLASS 11.0	27-14-44-24		

Approvals

Approvals



ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
Engineering Data	EPLAN, WSCAD
Catalogues	Catalogues in PDF-format
Brochures	


Data sheet

SKMU PG7-K GR

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

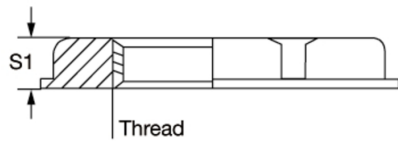

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1697440000](#)