

SKMU M50 - K GR**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Version	SKMU PA (plastic locknut), Locknut, M 50, 8 mm, Polyamid 6 (PA6 - GF30)
Order No.	1772500000
Type	SKMU M50 - K GR
GTIN (EAN)	4032248130245
Qty.	10 pc(s).

Creation date January 27, 2022 9:56:46 PM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

SKMU M50 - K GR**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight 2.66 g

Temperatures

Operating temperature -40 °C... 100 °C

General information

AF size 1	60 mm	Cable glands	metric
External thread	M 50	Halogen	No
Internal thread	M 50	Length of thread	8 mm
Material	Polyamid 6 (PA6 - GF30)	O.D.	69.3 mm
Operating temperature range, max.	100 °C	Operating temperature range, min.	-40 °C
Pitch of thread	1.5 mm	Thickness	8 mm
UL 94 flammability rating	HB		

Classifications

ETIM 6.0	EC000940	ETIM 7.0	EC000940
ETIM 8.0	EC000940	ECLASS 9.0	27-14-44-24
ECLASS 9.1	27-14-44-24	ECLASS 10.0	27-14-44-24
ECLASS 11.0	27-14-44-24		

Approvals

Approvals



ROHS Conform

Downloads

Engineering Data	CAD data – STEP
Engineering Data	EPLAN, WSCAD
Catalogues	Catalogues in PDF-format
Brochures	


Data sheet

SKMU M50 - K GR

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

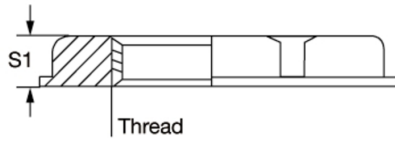

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1772500000](#)