

**IE-BI-RJ45-FJ-B****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

**General ordering data**

Version	RJ45 insert socket, Connector for base, TIA-568B
Order No.	<a href="#">1963840000</a>
Type	IE-BI-RJ45-FJ-B
GTIN (EAN)	4032248651894
Qty.	10 pc(s).

## IE-BI-RJ45-FJ-B

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Net weight	2.5 g
------------	-------

## Temperatures

Operating temperature	-40 °C...70 °C	Humidity	0...93 % rel. humidity
-----------------------	----------------	----------	------------------------

## General data

Insert type	Insert data SteadyTec	Product type	RJ45 insert socket
Protection degree	IP67 with housing		

## General data

Connection 1	RJ45	Connection 2	IDC
Description of article	Connector for base	Wiring	TIA-568B
Colour	Miscellaneous	Shock resistance acc. to IEC 60512-4	250 ms <sup>-2</sup>
Vibration resistance acc. to IEC 60512-4	50 ms <sup>-2</sup> sinusoidal (9...500 Hz)	Humidity	0...93 % rel. humidity
Speed	10 GBit/s	Insulation cross-section, min.	0.85
Insulation cross-section, max.	1.6 mm	Category	Cat.6A / Class E <sub>A</sub> (ISO/IEC 11801 2010)
Contact material	Spring steel, Ni 1.2 µm	Connection diameter, solid	0.4...0.64
Conductor connection cross-section, solid (AWG)	AWG 24...AWG 22	Connection diameter, flexible	0.48...0.76 mm
Conductor connection cross-section, flexible (AWG)	AWG 26...AWG 22	Shielding	360°; all-round enclosure
Protection degree	IP67 with housing	Ability to reconnect	≥ 10 cycles for AWG 23-26, ≥ 4 cycles for AWG 22

## Electrical properties

Contact resistance	≤ 20 mΩ	Current-carrying capacity at 50 °C	1 A
Dielectric strength, contact / contact	≥ 1000 V DC	Dielectric strength, contact / shield	≥ 1500 V DC
PoE / PoE+	conforming to IEEE 802.3af		

## General standards

Application-specific communication cable facilities	PROFINET installation instructions	Certificate No. (DNVGL)	TAA000022B
Certificate no. (cULus)	E316369	Connector standard	IEC 60603-7-51
IP protection classes	IEC 60529	UL standard for communication accessories	UL 1863

## Standards

Connector standard	IEC 60603-7-51	Generic communication cable facilities	ANSI / TIA / EIA-568-B.2-10, DIN EN 61918 Draft 02.2007, EN 50173-1:2007, ISO / IEC 11801:2002, ISO / IEC 24702:2006
IP protection classes	IEC 60529	UL standard for communication accessories	UL 1863

Creation date January 29, 2022 3:01:38 PM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

2

## IE-BI-RJ45-FJ-B

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ECLASS 9.0	27-44-03-90
ECLASS 9.1	27-44-03-90	ECLASS 10.0	27-44-03-90
ECLASS 11.0	27-44-03-90		

## Approvals

Approvals



ROHS	Conform
UL File Number Search	E316369

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">GOST Approval</a> <a href="#">GL FrontCom</a> <a href="#">ISO/IEC EN and TIA/EIA Screened Class EA Category 6A, 4 connector channel</a> <a href="#">ISO/IEC EN and TIA/EIA Screened Class E Category 6, 3 connector permanent link</a> <a href="#">ISO/IEC EN and TIA/EIA Screened Class E Category 6, 4 connector channel</a> <a href="#">ISO/IEC EN and TIA/EIA Screened Class EA Category 6A, 2 connector channel</a> <a href="#">CC-Link IE-BI-RJ45-FJ</a> <a href="#">UL Approval</a> <a href="#">Compliance Statement Screened Category 6 ISO/IEC EN and TIA/EIA Connecting Hardware</a>
Engineering Data	<a href="#">CAD data – STEP</a>
Engineering Data	<a href="#">EPLAN, WSCAD, Zuken E3.S</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Designation key / Type key</a> <a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">MB FREECONTACT EN</a> <a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a>


**IE-BI-RJ45-FJ-B**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

**Dimensioned drawing**

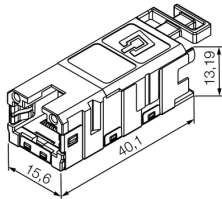

**Printing**



**IE-BI-RJ45-FJ-B**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**Cable-lug sleeves**



**Insulated tab-connector sleeves made from PVC with copper sleeve**

- Commercially available designs
- Not soldered
- With conical entry funnel

**General ordering data**

Type	LIF 1,5F288 R	Version	
Order No.	<a href="#">9200520000</a>		cable lug, terminal end, Insulated cable connector, 1,5 mm <sup>2</sup> , 0,5 mm <sup>2</sup> -
GTIN (EAN)	4032248410361		1,5 mm <sup>2</sup>
Qty.	100 pc(s).		

**Pressing tool**



When working with live voltages, you must follow special guidelines and use special tools - tools which have been specially produced and tested for this purpose. Weidmüller offers a complete line of pliers which comply with national and international testing standards. All pliers are produced and tested according to DIN EN 60900.

The pliers are ergonomically designed to fit to the hand form, and thus feature an improved hand position. The fingers are not pressed together - this results in less fatigue during operation.

**General ordering data**

Type	PWZ RJ45	Version	
Order No.	<a href="#">1118040000</a>		Pressing tools
GTIN (EAN)	4032248899197		
Qty.	1 pc(s).		

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[1963840000](#)