


H10,0/24DS ZH R**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

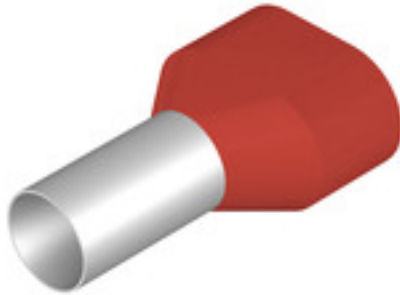

- Polypropylene conical cable entry funnel
- Heat-resistant up to 105°C

For conductors from 0.5 – 10.0 mm² (AWG 20-7)

Material: E-Cu, tin galvanised

Dimensional tolerance acc. to DIN 46228 sect. 4

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 17 mm, 12 mm, red
Order No.	9018880000
Type	H10,0/24DS ZH R
GTIN (EAN)	4032248105830
Qty.	100 pc(s).
Packaging	loose

Creation date January 30, 2022 12:00:41 PM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

H10,0/24DS ZH R**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight 0.83 g

Technical data

Description of article Twin wire end ferrule, red Version Twin wire-end ferrule

Wire-end ferrules

Collar height (A)	13.4 mm	Collar width (B)	7.6 mm
Colour code	DIN	Conductor cross-section	10 mm ²
Contact surface diameter (D1)	6.5 mm	Contact surface length (L2)	12 mm
L1 in mm	24 mm	Metal sleeve thickness (S1)	0.2 mm
Plastic collar thickness (S2)	0.5 mm	Stripping length	17 mm
Wire connection cross section AWG, max.	AWG 8		

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01		

Approvals

Approvals



ROHS Conform

Downloads

Engineering Data	CAD data – STEP
Engineering Data	WSCAD, EPLAN
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format
Brochures	

Data sheet

H10,0/24DS ZH R

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[9018880000](#)