


H10,0/30DS ZH R**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

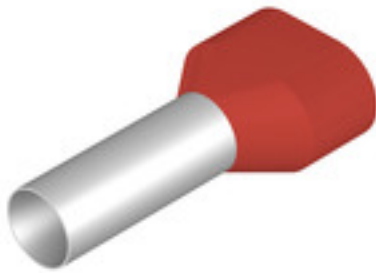

- Polypropylene conical cable entry funnel
- Heat-resistant up to 105°C

For conductors from 0.5 – 10.0 mm² (AWG 20-7)

Material: E-Cu, tin galvanised

Dimensional tolerance acc. to DIN 46228 sect. 4

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 23 mm, 18 mm, red
Order No.	9018890000
Type	H10,0/30DS ZH R
GTIN (EAN)	4032248105847
Qty.	100 pc(s).
Packaging	loose

Creation date January 30, 2022 12:00:58 PM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

H10,0/30DS ZH R**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight 1.03 g

Technical data

Description of article Twin wire end ferrule, red Version Twin wire-end ferrule

Wire-end ferrules

Collar height (A) 13.4 mm Collar width (B) 7.6 mm

Colour code DIN Conductor cross-section 10 mm²

Contact surface diameter (D1) 6.5 mm Contact surface length (L2) 18 mm

L1 in mm 30 mm Metal sleeve thickness (S1) 0.2 mm

Plastic collar thickness (S2) 0.5 mm Stripping length 23 mm

Wire connection cross section AWG, max. AWG 8

Classifications

ETIM 6.0 EC000005 ETIM 7.0 EC000005

ETIM 8.0 EC000005 ECLASS 9.0 27-40-02-01

ECLASS 9.1 27-40-02-01 ECLASS 10.0 27-40-02-01

ECLASS 11.0 27-40-02-01

Approvals

Approvals



ROHS Conform

DownloadsEngineering Data [CAD data – STEP](#)Engineering Data [WSCAD, EPLAN](#)User Documentation [Technical information - EN](#)[Technical information - DE](#)Catalogues [Catalogues in PDF-format](#)

Brochures

H10,0/30DS ZH R

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawing



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[9018890000](#)