


H16,0/28D BL**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

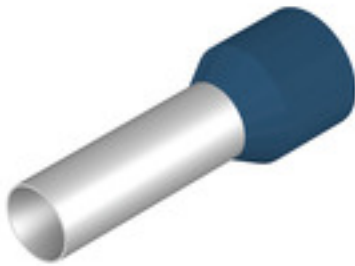

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Standard, 21 mm, 18 mm, blue
Order No.	9019270000
Type	H16,0/28D BL
GTIN (EAN)	4008190100773
Qty.	100 pc(s).
Packaging	loose

Creation date March 26, 2022 8:54:01 AM CET

Catalogue status 11.03.2022 / We reserve the right to make technical changes.

H16,0/28D BL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight 0.83 g

Technical data

Description of article	Wire end ferrule with plastic collar, blue	Version	Standard
------------------------	--	---------	----------

Wire-end ferrules

Collar diameter (D2)	8.8 mm	Colour code	DIN
Conductor cross-section	16 mm ²	Contact surface diameter (D1)	5.8 mm
Contact surface length (L2)	18 mm	L1 in mm	28 mm
Metal sleeve thickness (S1)	0.2 mm	Military designation	T 20A 027 A
Plastic collar thickness (S2)	0.4 mm	Stripping length	21 mm
Wire connection cross section AWG, max.	AWG 6		

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01		

Approvals

Approvals



ROHS	Conform
UL File Number Search	E499744

Downloads

Engineering Data	CAD data – STEP
Engineering Data	EPLAN, WSCAD, Zuken E3.S
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format
Brochures	

Data sheet

H16,0/28D BL

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[9019270000](#)