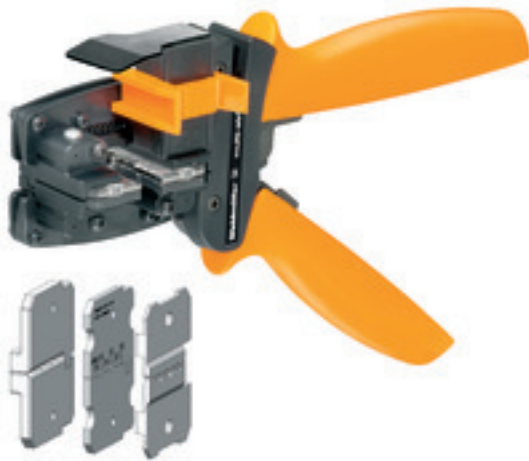


MULTI-STRIPAX AWG**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

- For flexible and solid conductors with special insulating materials
- High-quality stripping for industrial applications (complies with aircraft industry requirements)
- Specially shaped blades enable stripping of special types of insulation and conductor configurations
- Stripping length adjustable via end stop
- Very versatile thanks to interchangeable stripping units
- Stripping results reproduced accurately over and over again
- No damage to the conductor
- A long-lasting, reliable tool thanks to its sturdy design
- Integrated cutting function

General ordering data

Version	Tools, Stripping and cutting tool
Order No.	9202230000
Type	MULTI-STRIPAX AWG
GTIN (EAN)	4032248486168
Qty.	1 pc(s).

Creation date January 30, 2022 4:08:49 PM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

MULTI-STRIPAX AWG**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Depth	40 mm	Depth (inches)	1.575 inch
Height	85 mm	Height (inches)	3.346 inch
Width	250 mm	Width (inches)	9.842 inch
Weight	250 g	Net weight	520.28 g

Environmental Product Compliance

REACH SVHC Lead 7439-92-1

Technical data

Description of article Stripping and cutting tool for AWG conductors with PVC and PTFE etc. insulation

Stripping tools

Cable type	AWG conductor with PTFE and PVC insulation	Conductor cross-section (cutting capacity)	6 mm ²
Copper cable - flexible, max.	6 mm ²	Stripping length, min.	2 mm
Stripping range AWG, max.	16 AWG	Stripping range AWG, min.	26 AWG
max. cutting capacity, fine-strand	6 mm ²	max. cutting capacity, ribbon	10,2 mm x 4 mm
max. cutting capacity, solid	2.5 mm ²		

Classifications

ETIM 6.0	EC002109	ETIM 7.0	EC002109
ETIM 8.0	EC002109	ECLASS 9.0	21-04-37-06
ECLASS 9.1	21-04-37-06	ECLASS 10.0	21-04-37-06
ECLASS 11.0	21-04-37-06		

Approvals

Approvals

**Downloads**

User Documentation	Manual
Catalogues	Catalogues in PDF-format
Brochures	

MULTI-STRIPAX AWG

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Example of use




MULTI-STRIPAX AWG

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Accessories / replacement parts

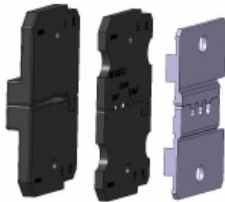

- For flexible and solid conductors with special insulating materials
- High-quality stripping for industrial applications (complies with aircraft industry requirements)
- Specially shaped blades enable stripping of special types of insulation and conductor configurations
- Stripping length adjustable via end stop
- Very versatile thanks to interchangeable stripping units
- Stripping results reproduced accurately over and over again
- No damage to the conductor
- A long-lasting, reliable tool thanks to its sturdy design
- Integrated cutting function

General ordering data

Type	ERAN MULTI-STRIPAX	Version
Order No.	9203100000	Spare stop set
GTIN (EAN)	4032248538102	
Qty.	1 pc(s).	
Type	AIE MULTI-STRIPAX AWG	Version
Order No.	9202280000	Insert
GTIN (EAN)	4032248486236	
Qty.	1 pc(s).	
Type	ERME MULTI-STRIPAX	Version
Order No.	9203070000	Spare cutting blade
GTIN (EAN)	4032248538096	
Qty.	1 pc(s).	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[9202230000](#)