

## MPC 12/17/12 TRSP

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

### Similar to illustration



Abbildung ähnlich

Small and medium-sized polycarbonate enclosures  
The polycarbonate enclosures of the MPC series are ideal for building into electrical, electromechanical and pneumatic devices as well as PCBs. The enclosures are used in situations with extreme mechanical and chemical conditions.

Features:

- 17 sizes in 2 versions
- Grey or transparent cover
- Cover with lead-seal holes
- Mounting holes outside the seal area
- Receptacle threads for rail mounting, mounting plates and circuit board
- Comprehensive accessories
- Weidmüller can manufacture and supply the enclosure to match customer specifications, fitted with all necessary terminals and cable glands.

### General ordering data

Version	MPC (polycarbonate empty enclosure), Empty enclosure, Height: 125 mm, Width: 175 mm, Depth: 125 mm, Material: Polycarbonate, Light Grey, Transparent
Order No.	<a href="#">9535340000</a>
Type	MPC 12/17/12 TRSP
GTIN (EAN)	4032248009237
Qty.	1 pc(s).

## MPC 12/17/12 TRSP

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	125 mm	Depth (inches)	4.921 inch
Height	125 mm	Height (inches)	4.921 inch
Width	175 mm	Width (inches)	6.89 inch
Weight	530 g	Net weight	525 g

## Temperatures

Operating temperature	-50 °C...130 °C
-----------------------	-----------------

## Cable glands, right

M12	6	M16	4
M20	4		

## Cable glands, top/bottom

M12	4	M16	3
M20	3		

## General information

Access opening: height	121.5 mm	Access opening: width	171.5 mm
Areas of use	Building systems and technology, Transportation, Packaging industry, Machine construction	Enclosure attachment	Holes 4.5 mm
Flange plate	No	Halogen	No
Impact resistance	IK06	Integral fixing	thanks to self-tapping screws
Lid	Yes	Lid attachment	4 polyamide crosshead screws
Material	Polycarbonate	Material thickness	3.5 mm
Number of lid screws	4	Operating temperature, max.	130 °C
Operating temperature, min.	-50 °C	Protection degree	IP66, IP67
Seal material	Polyurethane	Torque for lid screws	0.8 Nm

## horizontal assembly

WDU 10 / ZDU 10	1x11	WDU 16 / ZDU 16	1x5
WDU 2,5 / ZDU 2,5 / IDU 2,5	1x22	WDU 35 / ZDU 35	1x4
WDU 4 / ZDU 4	1x19	WDU 6 / ZDU 6	1x14

## vertical assembly

WDU 10 / ZDU 10	1x6	WDU 16 / ZDU 16	1x5
WDU 2,5 / ZDU 2,5 / IDU 2,5	1x13	WDU 35 / ZDU 35	1x4
WDU 4 / ZDU 4	1x11	WDU 6 / ZDU 6	1x8

## Classifications

ETIM 6.0	EC000261	ETIM 7.0	EC000261
ETIM 8.0	EC000261	ECLASS 9.0	27-18-01-01
ECLASS 9.1	27-18-92-90	ECLASS 10.0	27-18-01-01
ECLASS 11.0	27-18-01-01		

Creation date January 30, 2022 8:34:59 PM CET

Catalogue status 14.01.2022 / We reserve the right to make technical changes.

**Data sheet****MPC 12/17/12 TRSP**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Technical data****Approvals**

Approvals



ROHS

Conform

**Downloads**

Engineering Data	<a href="#">CAD data – STEP</a>
Engineering Data	<a href="#">EPLAN, WSCAD</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	


**Data sheet**

**MPC 12/17/12 TRSP**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

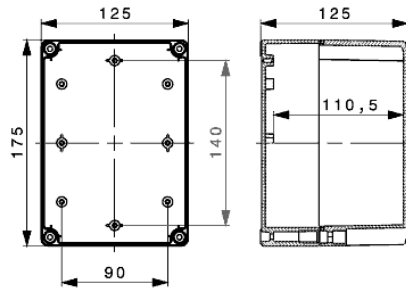

**MPC 12/17/12 TRSP**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**TS 15**

Accessories



**General ordering data**

Type	TS15X5 ST MPC1217 VER	Version
Order No.	<a href="#">8000037598</a>	Rail, TS 15, Width: 60 mm, without slot, Steel, galvanized, chromium-plated
GTIN (EAN)	4050118653106	
Qty.	20 pc(s).	

**Fixing Material**

Accessories



**General ordering data**

Type	SC MPC	Version
Order No.	<a href="#">9535640000</a>	MPC (polycarbonate empty enclosure), Mounting screw, Screws,
GTIN (EAN)	4032248009428	Material: Steel, galvanised
Qty.	100 pc(s).	

**MPC 12/17/12 TRSP**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**
**Hinge**

MPC series, hinges, set of 2


**General ordering data**

Type	HG MPC	Version
Order No.	<a href="#">9535590000</a>	MPC (polycarbonate empty enclosure), External joint, Hinge, Material:
GTIN (EAN)	4032248009329	Plastic
Qty.	1 pc(s).	

**Earthing stud**

Earthing bolts to exchange as a complete component in two versions – brass and stainless steel.


**General ordering data**

Type	PEBZ M10 S4 SET	Version
Order No.	<a href="#">1283440000</a>	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118073362	Miscellaneous, Material: Stainless steel 1.4404 (316L)
Qty.	1 pc(s).	
Type	PEBZ M10 BR SET	Version
Order No.	<a href="#">1277220000</a>	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118067019	Miscellaneous, Material: Brass
Qty.	1 pc(s).	
Type	PEBZ M6 S4 SET	Version
Order No.	<a href="#">1283430000</a>	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118073607	Miscellaneous, Material: Stainless steel 1.4404 (316L)
Qty.	1 pc(s).	
Type	PEBZ M6 BR SET	Version
Order No.	<a href="#">1277250000</a>	Klippon POK (polyester empty enclosure), Earthing stud,
GTIN (EAN)	4050118067149	Miscellaneous, Material: Brass
Qty.	1 pc(s).	

**MPC 12/17/12 TRSP**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**External fixing lugs**

External attachment lugs 4-part set



**General ordering data**

Type	MF MPC	Version
Order No.	<a href="#">953560000</a>	MPC (polycarbonate empty enclosure), Mounting foot, Fixing lugs,
GTIN (EAN)	4032248009381	Material: Plastic
Qty.	1 pc(s).	

**MPC**

Mounting plates, 1.5 mm sheet steel, galvanised



**General ordering data**

Type	MP MPC 12/17	Version
Order No.	<a href="#">953556000</a>	MPC (polycarbonate empty enclosure), Mounting plate, Mounting
GTIN (EAN)	4032248009299	plate, Material: Sheet steel, galvanised
Qty.	1 pc(s).	

**MPC 12/17/12 TRSP**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**TS 35**

Accessories



**General ordering data**

Type	TS35X7.5 ST MPC1725 VER	Version
Order No.	<a href="#">8000037600</a>	Rail, TS 35, TS 35 x 7.5, Width: 90 mm, without slot, Steel, galvanic
GTIN (EAN)	4050118653120	zinc plated and passivated
Qty.	20 pc(s).	

**Ventilation plugs - DAE**



In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

**General ordering data**

Type	DAE M12 PA LONG	Version
Order No.	<a href="#">1868570000</a>	DAE (ventilation element), Compensating element, M 12, 10 mm, IP66, IP68, IP69K, Polyamide 6
GTIN (EAN)	4032248440429	
Qty.	10 pc(s).	
Type	DAE M12 SS	Version
Order No.	<a href="#">1868550000</a>	DAE (ventilation element), Compensating element, M 12, 10 mm, IP66, IP68, IP69K, Stainless steel 1.4305 (303)
GTIN (EAN)	4032248440405	
Qty.	10 pc(s).	



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Weidmuller:](#)

[9535340000](#)